
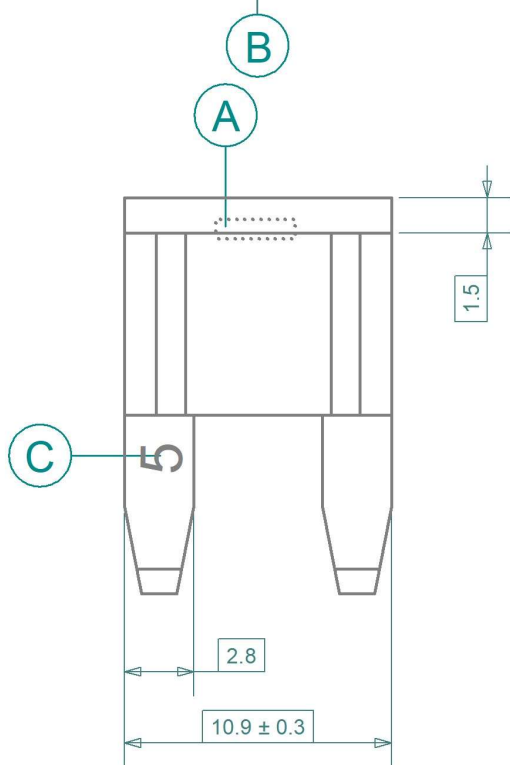
 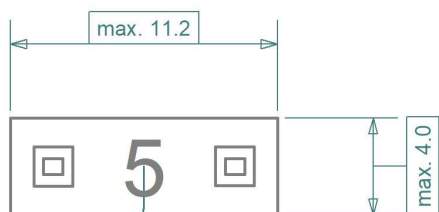


Rating [A]	Color	Volt [V]	iMaXX Reference
2	Gray	32	F7902
3	Violet	32	F7903
4	Pink	32	F7904
5	Tan	32	F7905
7.5	Brown	32	F7975
10	Red	32	F7910
15	Blue	32	F7915
20	Yellow	32	F7920
25	Natural	32	F7925
30	Green	32	F7930

Notes	
A	LED / PCB placement
B	Amperage rating printed on fuse body
C	Amperage rating stamped
*	Fuse series for after market use

Fusing time SAE J-2077 [s]		
Load [%]	Minimum [s]	Maximum [s]
110 %	360,000	-
135 %	0.75	1,800
200 %	0.15	5
350 %	> 0.08	

Revisions				Date	Appr.	
	Date	Type	Drawn	05/09	GRH	
a	08/11	rating print on top added	Checked	04/24	EB	
b	10/12	updated dimensions	Standards			
c	04/24	added note	Approved	04/24	AdH	
			Scale 3 : 1			Title
			Projection	Tolerance ± 0.2 mm unless otherwise noted		Drawing type
						Drawing number
						Sheet
						Layers



F7900 series, miniOTO ShoBlo			
schematic			
F7900 (LED) drawing 1			
1 of 1			
0 1 2 6 9			