
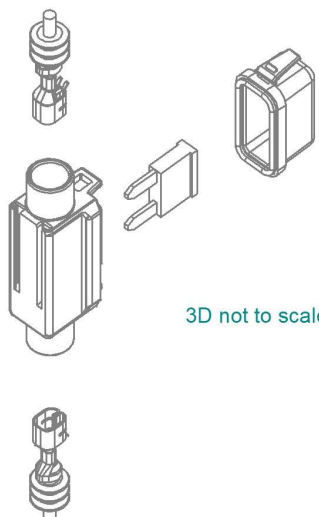


A

A

cover: HLP7305

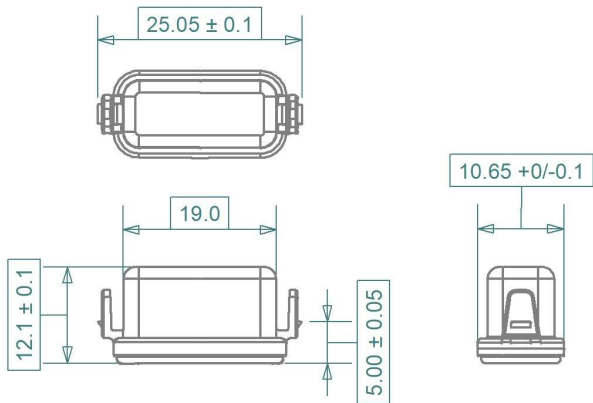


3D not to scale


B

B

body: H7301

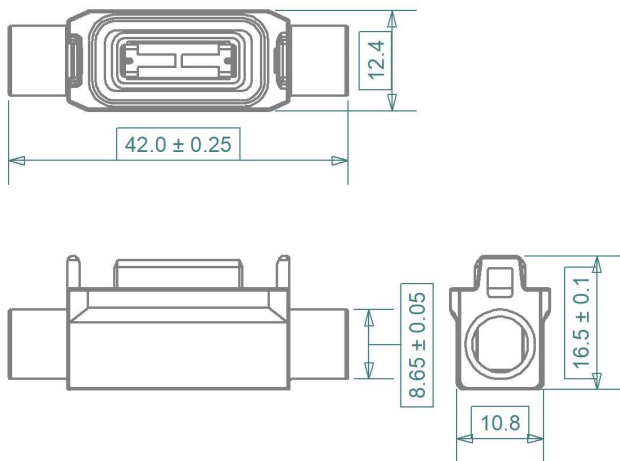

contact

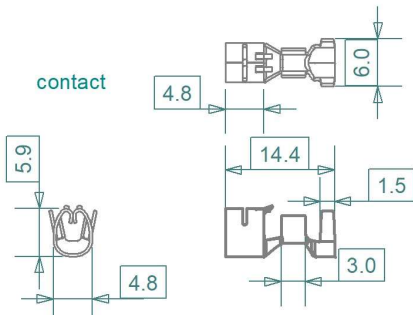


C

C

iMaXX ref.	Description	Material	Note
H7301	single holder	PA 6 GF 30	black
HLP7305	clear cover	PC	transparent
CCS150FR	contact 1.0-2.5mm²	CuZn33	Sn plated, reeled
S681620	cable seal, violet	LSR, 50 shore	HD 6.8mm, ø1.6-2.0mm
S682028	cable seal, green	LSR, 50 shore	HD 6.8mm, ø2.0-2.8mm
S682835	cable seal, gray	LSR, 50 shore	HD 6.8mm, ø2.8-3.5mm
iMaXX ref.	Description		
H7325	assembled fuse holder, 1,5mm² black wire ± 130mm each side		
H7335	assembled fuse holder, 2,5mm² red wire ± 130mm each side		

wire seal

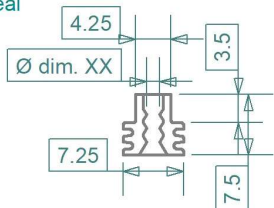

Cable seal details	
iMaXX ref.	dim. XX
S682028	1.60
S682835	2.40
S681620	1.25

Notes: fuse holder suited for iMaXX miniOTO blade fuse series F7000 and F7900(LED) up to 30A
Contact suitable for wire diameters 1.0 - 2.5mm²

E

E

Revisions			Date	Appr.	
	Date	Type	Drawn	05/12	GRH
a	03/13	Updated cable dimensions	Checked	10/24	BE
b	09/21	Updated CCS150FR materials	Standards		
c	10/24	Updated HLP7305 cover	Approved	10/24	SS
			Scale	1 : 1	
			Projection	Tolerance ± 0.2 mm unless otherwise noted	
			Title		
			Drawing type		
			Drawing number		
			Sheet		
			Layers / Sheet		



F

F