
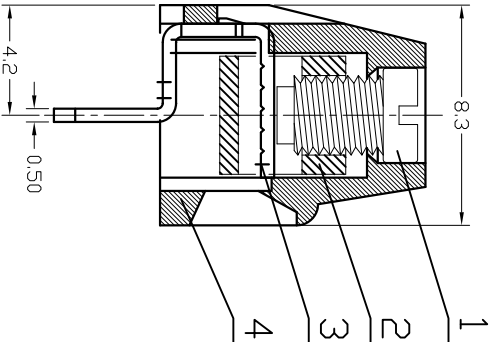



序号/Rev.No.	名称/Title	文件编号/File No.
1	XY304螺丝	QJ/XYT-2150101
2	XY127制万夹 (与XY304端子块共用)	QJ/XYT-2150102
3	XY127V 端子	QJ/XYT-2150401
4	XY127 塑件	QJ/XYT-2139102

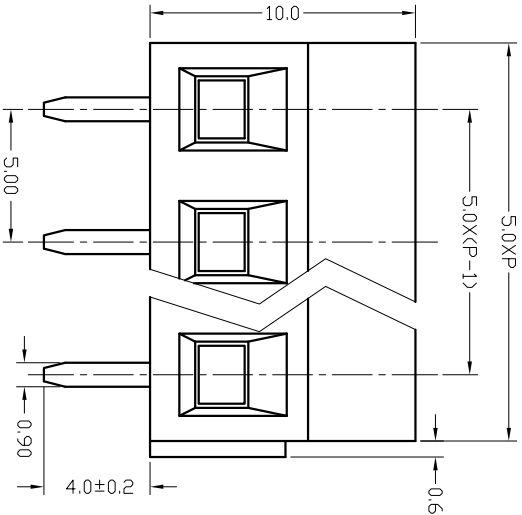

300V 12A 26-14AWG 1.5mm²
Poles: 2P&3P-24P
Pitch: 5.0mm (.197")

Materials

Housing: PA66(UL 94V-0)
Wire Cage: Brass, Nickel plated
Solder Pin: Brass, Tin Plated
Screw: M3, Steel, Zinc Plated
Torque: 0.5N.m

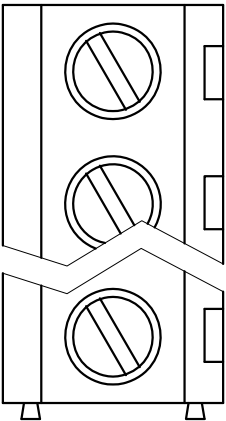

序号/Rev.No.	更改记录/Revision note	签名/Signature	日期/Date
------------	--------------------	--------------	---------

设计/Designed by	绘图/Drawing by	审核/Checked by	批准/Approved by	未注公差 General Tolerance	
 新莱亚电子 XINLAIYA ELECTRONIC CO., LTD		图名/Title	文件编号/File No.	X. ±0.2	X. ° ±0°
		XY127V 产品图	QJ/XYT-2239100	.X. ±0.1	.X. ° ±1°
		页序/Sheet		.XXX ±0.05	.XX' ±0.5°
备注/Remark				单位/Unit: mm	