
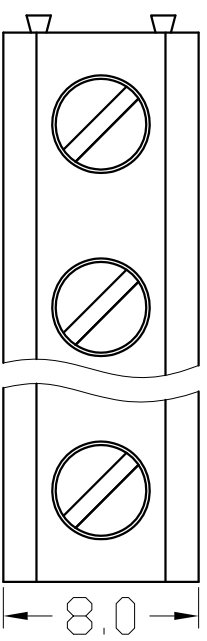


序号/Rev.No.	名称/Title	文件编号/File No.
1	XY305V端子	QJ/XYT-2126101
2	XY705V 塑件	QJ/XYT-2131101
3	XY305簧片	QJ/XYT-2126102
4	XY305螺丝	QJ/XYT-2126103

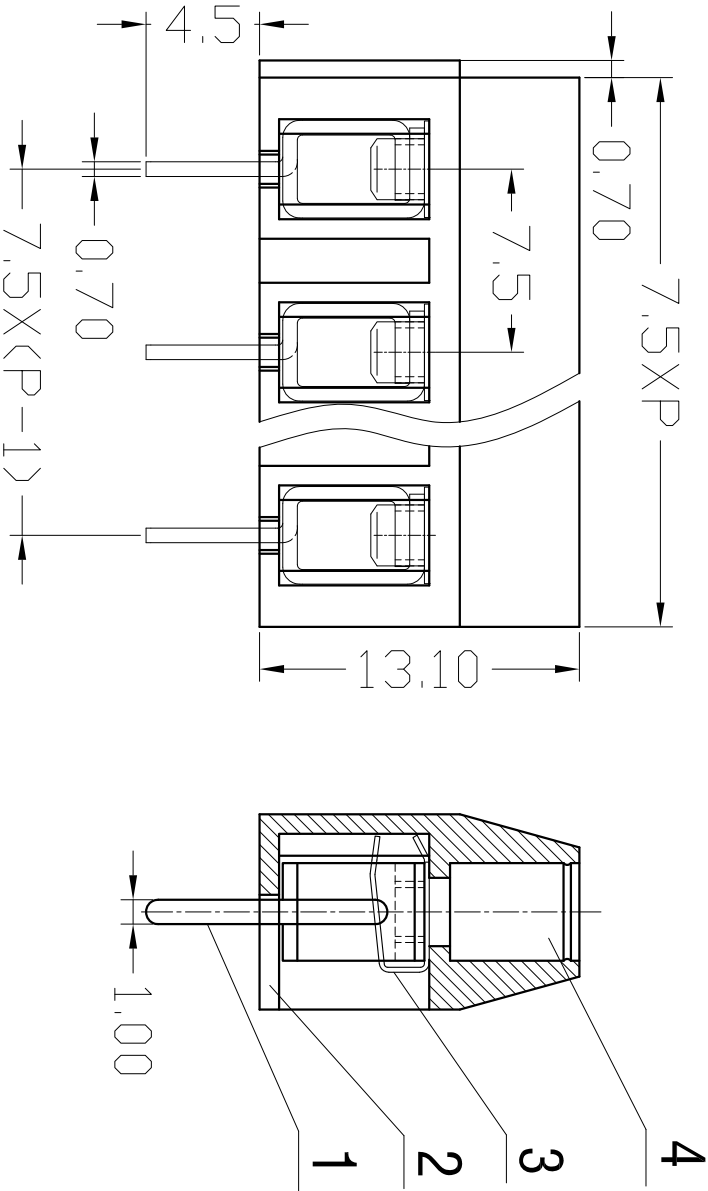

300V 15A 22-14AWG 2.5mm²
Poles: 2P&3P-24P
Pitch: 7.5mm (.295")
Pin Dimension: 0.7X1.0mm

Materials
Housing: PBT (30% Glass filled)
Solder Pin: Brass, Tin Plated.
Wire Protector: Stainless steel.
Screw: M2.5, Steel, Zinc Plated.
Ambient temperature: -40~105℃

设计/Designed by		绘图/Drawing by		审核/Checked by		批准/Approved by		未注公差 General Tolerance	
图名/Title		文件编号/File No.		QJ/XYT-2231100		页序/Sheet		单位/Unit: mm	
X		±0.2		X		±0.1		X	
.XX		±0.05		.XX		±0.05		.XX	
.XXX		±0.01		.XXX		±0.01		.XXX	

序号/Rev.No.

更改记录/Revision note

签名/Signature

日期/Date

X

新莱亚电子

XINLAIYA ELECTRONIC CO., LTD

备注/Remark