

ROCKER SWITCH MODEL MR5 SERIES

RATING:3A 250VAC (cURus)



6A 125VAC (cURus)

3A 250V~ μT100/55 (ENEC15/CQC)


DIELECTRIC VOLTAGE-WITHSTAND:1,500VAC FOR 1 MINUTE

INSULATION RESISTANCE:DC 500V 100MΩ (MIN.)


CONTACT RESISTANCE:20mΩ INITIAL (MAX.)

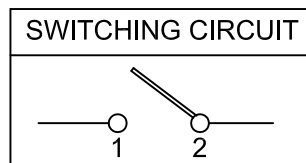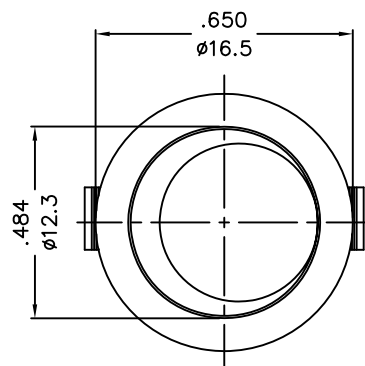


ON-OFF

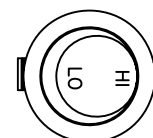


(1)

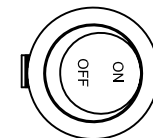


(3)

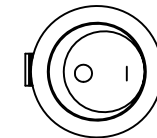





(4)

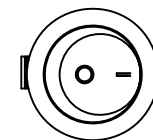

(5)

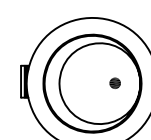

(6)

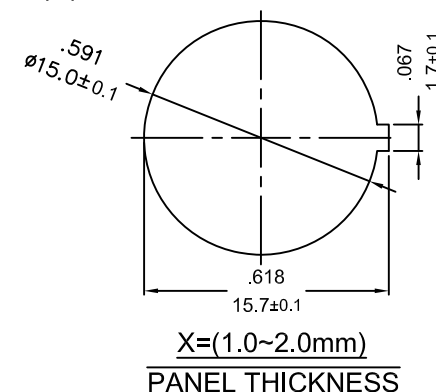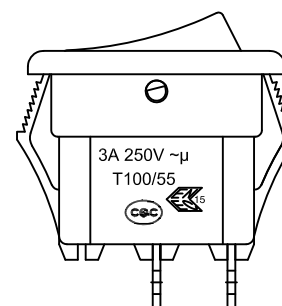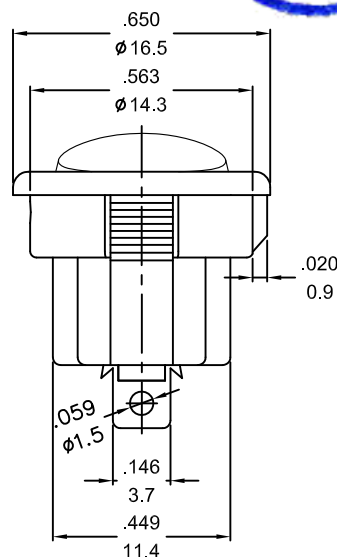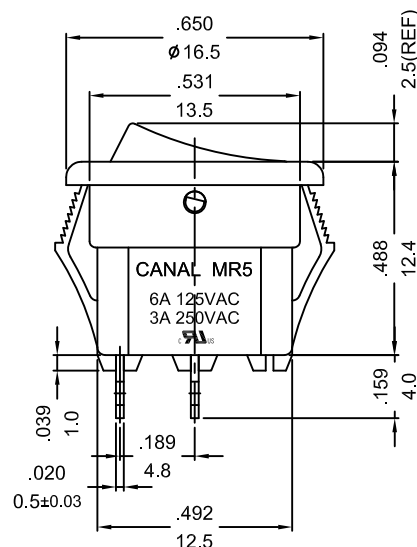

NOTE: TOLERANCES UNLESS OTHERWISE SPECIFIED:±.012/0.3(in/min)

[illegible]