


KOP Claw terminal

for multi-wire Cu cables

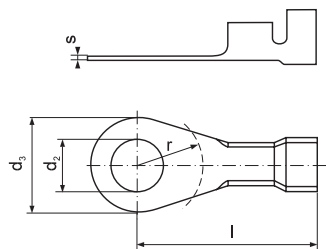

Material: brass
 According to DIN 46225

Cross section [mm ²]	For screw M	d ₂ [mm]	Symbol	s [mm]	d ₃ [mm]	l [mm]	r [mm]	Weight [g/pce]	Unit [pcs]	Crimping tools
0,5 ÷ 1	3	3,2	KOP 3-1	0,6	8	18,3	4,5	0,71	100	
	4	4,3	KOP 4-1		8	18,3	6,5	0,68		
	5	5,3	KOP 5-1		9,5	17,5	6,5	0,71		
	6	6,5	KOP 6-1		12	22	7,5	0,98		S44-2,
1 ÷ 2,5	3	3,2	KOP 3-2,5	0,6	8	18,3	4,5	0,86	100	PP8,
	4	4,3	KOP 4-2,5		8	18,3	6,5	0,82		PP19
	5	5,3	KOP 5-2,5		9,5	17,5	6,5	0,83		
	6	6,5	KOP 6-2,5		12	22	7,5	1,12		

Standard production – non tinned. When ordering tinned add 'Sn' symbol e.g. KOP 3-1 Sn.