





- WT29 Series
- Receptacle: WT29K3Z / WT29K5Z

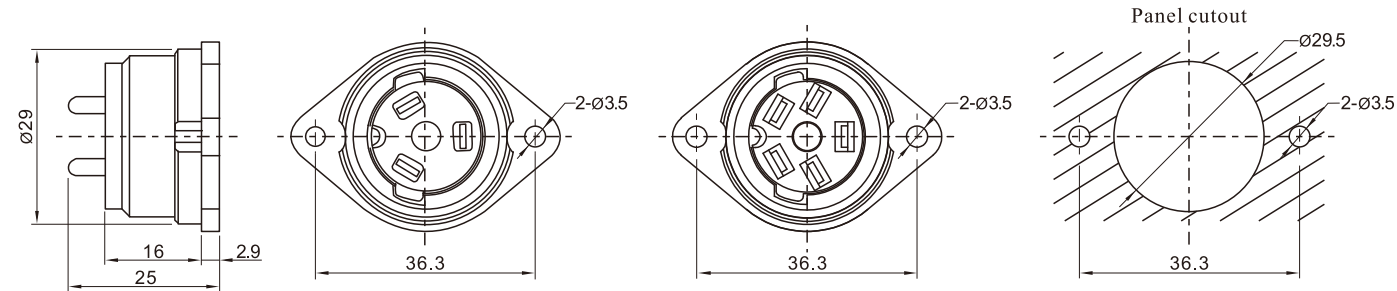

- Plug: WT29J3T / WT29J5T

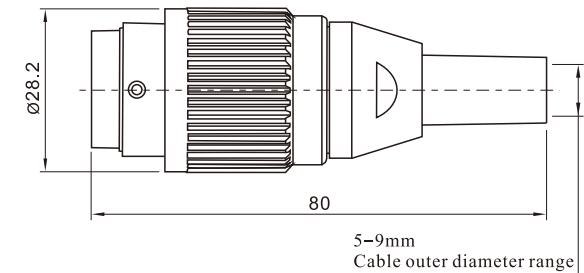

Material and spec

Coupling	Bayonet
Shell	Nylon PA66, Fire resistance V-0
Insert material	N 10yPA66
Contact material	Brass with silver plating
Termination	Solder
Mating cycle	500
Temperature range	-40℃~+85℃
Insulation resistance (MΩ)	2000
Test voltage (AC.V) 1 min	1500
Wire size (mm²/AWG)	2.5 / 16 max
Rated current (A)	10
Rated voltage (AC.V)	400
Contact resistance (mΩ)	2.5

WT29 Series

