



Cat.6A Keystone Jack STP, Slim Type

Art no.: NK4019

Technical Features

PrimeLine Cat.6A Class EA, 500 MHz


22–26 AWG, suitable for cable Ø5–8 mm

180° toolless, width only 14.8 mm

Cat.6A Channel Link certified

Suitable for PoE, PoE+ and PoE++ applications

Technical Drawing

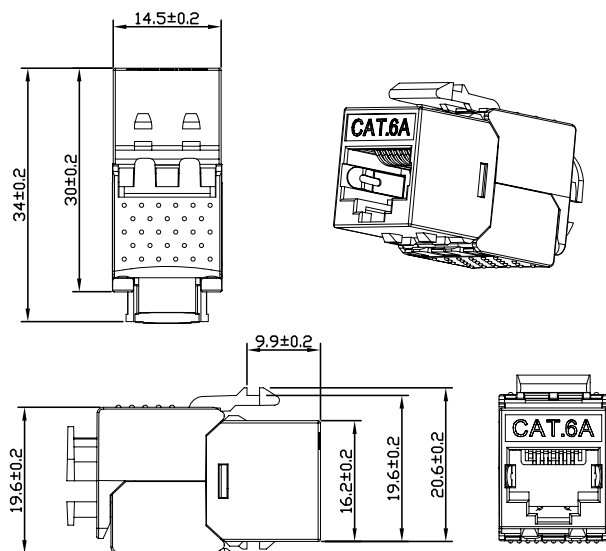

Electrical:

1. Contact resistance: 20mΩ max.
2. Insulation resistance: 500MΩ min. @ 500 V DC
3. Withstand voltage: DC 1000 V AC 700 V RMS 60 Hz, 1 min
4. Compliance with Class EA up to 500 MHz to ISO/IEC 11801 Ed.2.2:2011-06, DIN EN 50173-1:2011-09, TIA/EIA-568.2-D (2009-08), IEC 60603-7 Ed.1 (12/2008)

Environmental:

1. Storage temperature: -40–70°C
2. Operation temperature : -10–60°C

Mechanical:

1. 360° shield connection
2. IDC material: PC Terminal: Phosphor Bronze, Tin Plating
3. RJ45 contact life: 750 Times Min
4. Plug-in force: <30N
5. Solid cable: 1/22 AWG (0.65 mm)-1/26 AWG (0.4 mm) ID: 1.05–1.5 mm
6. Cable OD: 5–8 mm
7. PoE per IEEE 802.3af, PoE+ per IEEE 802.3at, 4PPoe per IEEE 802.3bt

NK4019



4 052792 060256

Made in China

www.2direct.de



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Package Content

- Cat.6A Keystone Jack x 1
- Cable Tie (75 x 1.9 mm) x 1

Packaging Information

Packing Dimension	120 x 80 mm
Packing Weight	0.0185 kg
Carton Dimension	475 x 275 x 200 mm
Carton Q'ty	250 pcs
Carton Weight	6 kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.