


article#	10484-0ws
article description	Safety socket P-NOVA+, 50x50 French/Belgian IP20 side (white)
description long	Safety socket series P-NOVA plus housing material: PA6 color: white flange dimension: 50x50mm connection technology: screw terminal cable entry: side entry system: French/Belgian contacts: nickel plated 250V, 16A, 2P+E protection class: IP20
GTIN (EAN)	9003399938306
country of origin	LK
customs number	85366990
net weight	0.034 kg
packaging quantity	100
minimum order quantity	100

ETIM 9.0	EC001325
Model	Earthing pin
Material	Plastic
Material quality	Thermoplastic
Halogen free	True
Flange size	50x50 mm
With hinged lid	False
For heavy conditions according to VDE	False
Degree of protection (IP)	IP20
Insert direction	Straight
Connection system	Screwed terminal
Colour	White
Number of poles	3
Nominal current	16 A
Nominal voltage	250 V

a	50 mm
b	37,5 mm
c	6 mm
d	29 mm
e	4,3 mm
f	43 mm
wire flexible	1,5-2x2,5 mm ²
wire solid	1,5-2x2,5 mm ²
contact screws	80 Ncm
stripping length	8-10 mm
ambient temperature	-25 – 40 °C

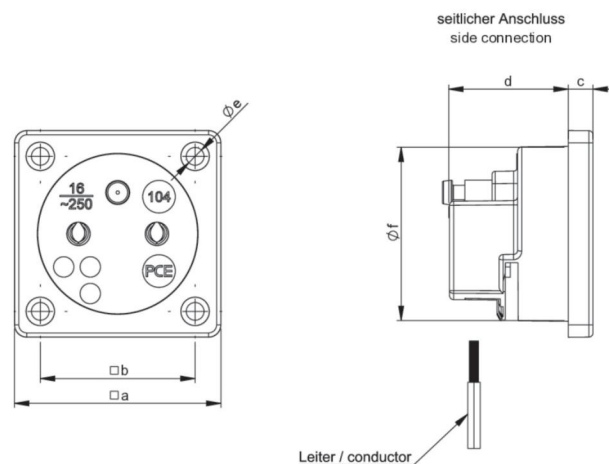

<https://www.pcelectric.at/shop/en/?func=detail&artnr=10484-0ws>