
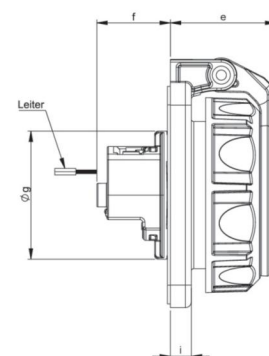


article#	20342-8u
article description	Flanged socket 75x75 fb with hinged lid IP66/68 (bronze-green)
description long	Socket outlet with protective earth contact series NAUTILUS housing material: PA6 color: bronze-green flange size: 75x75 mm with 4-point fastening connection technology: screw terminal, rear entry system: French/Belgian (earth pin) contacts: nickel plated 250V~ / 16A / 2P+E protection rating: IP66/68 watertight (2bar/2h)
GTIN (EAN)	9003399277191
country of origin	AT
customs number	85366990
net weight	0.103 kg
packaging quantity	10
minimum order quantity	10

ETIM 9.0	EC001325
Model	Earthing pin
Material	Plastic
Material quality	Thermoplastic
Flange size	75x75 mm
With hinged lid	True
For heavy conditions according to VDE	True
Degree of protection (IP)	IP68
Insert direction	Straight
Connection system	Screwed terminal
Colour	Green
Number of poles	3
Nominal current	16 A
Nominal voltage	250 V

a	75 mm
b	60 mm
c	84 mm
d	30 mm
e	36 mm
f	25 mm
g	43 mm
h	5,5 mm
i	7 mm
wire flexible	1,5-2x2,5 mm ²
wire solid	1,5-2x2,5 mm ²
contact screws	80 Ncm
stripping length	7 mm
ambient temperature	-25 – 40 °C

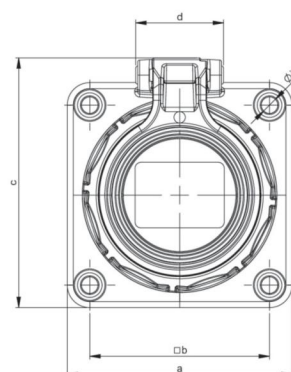

<https://www.pcelectric.at/shop/en/?func=detail&artnr=20342-8u>