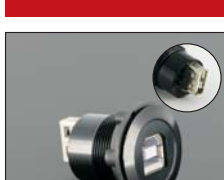


面板安装型转接器/线

Panel Mounting Type Connector

2024目录①

Contents

塑料USB面板接口 (经济型) <i>Plastic USB Panel Jack (Economy type)</i>	 型号/Model: USB-01C P1	 型号/Model: USB-01C-BK P1	 型号/Model: USB-02C P1	 型号/Model: USB-02C-BK P1	 型号/Model: USB-03C P1
 型号/Model: USB-03C-BK P1	 型号/Model: USB-04C P1	 型号/Model: USB-04C-BK P1	 型号/Model: USB-08C P2	 型号/Model: USB-08C-BK P2	 型号/Model: USB-09C P2
 型号/Model: USB-09C-BK P2	 型号/Model: USB-10C P2	 型号/Model: USB-10C-BK P2	 型号/Model: USB-05C P3	 型号/Model: USB-05C-BK P3	 型号/Model: USB-19C P3
 型号/Model: USB-19C-BK P3	 型号/Model: USB-23 P3				
金属USB面板插口 (Metal USB Panel Jack)	 型号/Model: USB-01 P4	 型号/Model: USB-01-BK P4	 型号/Model: USB-02 P4	 型号/Model: USB-02-BK P4	 型号/Model: USB-03 P4
 型号/Model: USB-03-BK P4	 型号/Model: USB-04 P4	 型号/Model: USB-04-BK P4	 型号/Model: USB-06 P5	 型号/Model: USB-06-BK P5	 型号/Model: USB-07 P5
 型号/Model: USB-07-BK P5	 型号/Model: USB-19 P5	 型号/Model: USB-19-BK P5	NEW  型号/Model: USB-26 P6	NEW  型号/Model: USB-26-BK P6	 型号/Model: USB-08 P6

面板安装型转接器/线
 Panel Mounting Type Connector

2024 目录 ②
 Contents

 型号/Model: USB-08-BK	 型号/Model: USB-09	 型号/Model: USB-09-BK	 型号/Model: USB-10	 型号/Model: USB-10-BK	 型号/Model: USB-12
 型号/Model: USB-12-BK	 型号/Model: USB-13	 型号/Model: USB-13-BK	 型号/Model: USB-14	 型号/Model: USB-14-BK	 型号/Model: USB-17
 型号/Model: USB-17-BK	 型号/Model: USB-18	 型号/Model: USB-18-BK	 型号/Model: USBC-01	 型号/Model: USBC-01-BK	 型号/Model: USBC-02
 型号/Model: USBC-02-BK	 型号/Model: USBC-03	 型号/Model: USBC-03-BK	 型号/Model: USBC-04	 型号/Model: USBC-04-BK	 型号/Model: USBC-06
 型号/Model: USBC-06-BK	 型号/Model: USBC-07	 型号/Model: USBC-07-BK	 型号/Model: USBC-08	 型号/Model: USBC-08-BK	 型号/Model: USBC-09
 型号/Model: USBC-09-BK	 型号/Model: USBC-10	 型号/Model: USBC-10-BK	 型号/Model: USBC-11	 型号/Model: USBC-11-BK	 型号/Model: Mini USB-01
 型号/Model: Mini USB-01-BK	 型号/Model: Mini USB-04	 型号/Model: Mini USB-04-BK	 型号/Model: Micro USB-01	 型号/Model: Micro USB-01-BK	 型号/Model: Micro USB-02

面板安装型转接器/线
 Panel Mounting Type Connector

2024目录②
 Contents

 P13 型号/Model: Micro USB-02-BK	 P13 型号/Model: Micro USB-03	 P13 型号/Model: Micro USB-03-BK	 NEW P13 型号/Model : Micro USB-04	 NEW P13 型号/Model : Micro USB-04-BK	
 其它面板插口 (Other Panel Jack)	 P14 型号/Model: STEREO-02	 P14 型号/Model: STEREO-02-BK	 P14 型号/Model: RJ45-01	 P14 型号/Model: RJ45-01-BK	 P14 型号/Model: RJ45-02
 P14 型号/Model: RJ45-02-BK	 NEW P14 型号/Model : RJ45-02C	 NEW P14 型号/Model : RJ45-02C-BK	 NEW P15 型号/Model : Power jack-01	 NEW P15 型号/Model : Power jack-01-BK	 P16 型号/Model: HDMI-01
 P16 型号/Model: HDMI-01-BK	 P16 型号/Model: HDMI-02	 P16 型号/Model: HDMI-02-BK	 NEW P16 型号/Model: HDMI-03	 NEW P16 型号/Model: HDMI-03-BK	 NEW P16 型号/Model : DP-01
 NEW P16 型号/Model : DP-01-BK	 P17 型号/Model: Protective 01	 P17 型号/Model: Protective 02	 P17 型号/Model: Protective 03		



面板安装型 USB2.0转接器/线 Panel Mounting Type USB2.0 Connector

- 工程塑料壳体，有黑色和银白两色可选，其他颜色可定制。
Engineering plastic shell, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 30\text{MB/s}$
Transmission Rate: $\geq 30\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : USB-01C



型号/Model : USB-01C-BK



产品描述 : USB2.0 头部A型母/尾部A型公
Product Description: USB2.0 HEAD MALE A/BACK MALE A

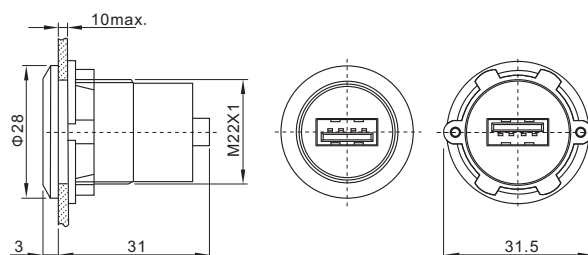


型号/Model : USB-02C



型号/Model : USB-02C-BK



产品描述 : USB2.0 头部A型母/尾部B型母
Product Description: USB2.0 HEAD FEMALE A/BACK FEMALE B

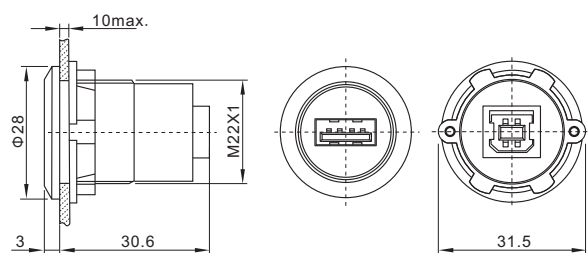


型号/Model : USB-03C



型号/Model : USB-03C-BK



产品描述 : USB2.0 头部B型母/尾部A型公
Product Description: USB2.0 HEAD FEMALE B/BACK MALE A

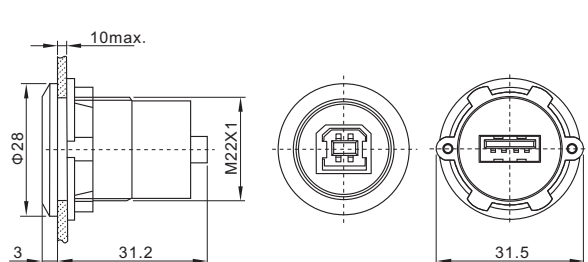


型号/Model : USB-04C



型号/Model : USB-04C-BK



产品描述 : USB2.0 头部B型母/尾部B型母
Product Description: USB2.0 HEAD FEMALE B/BACK FEMALE B

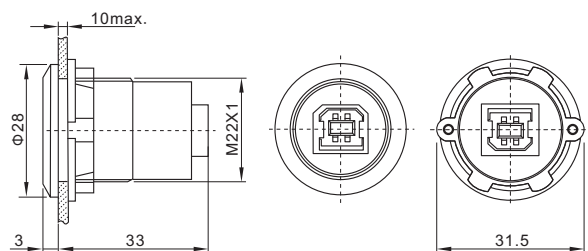



面板安装型 USB3.0转接器/线 Panel Mounting Type USB3.0 Connector

- 工程塑料壳体，有黑色和银白两色可选，其他颜色可定制。
Engineering plastic shell, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: Φ22mm
Pane Cutout: Φ22mm
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: ≥100MB/s
Transmission Rate: ≥100MB/s
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : USB-08C



型号/Model : USB-08C-BK



产品描述 : USB3.0 头部A型母/尾部A型公
Product Description: USB3.0 HEAD FEMALE A/BACK MALE A

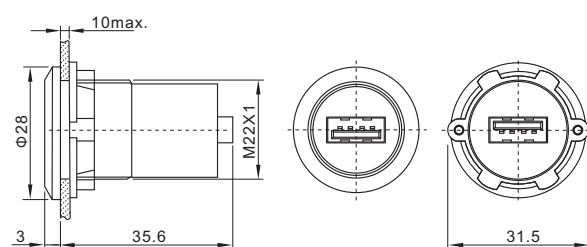


型号/Model : USB-09C



型号/Model : USB-09C-BK



产品描述 : USB3.0 头部A型母/尾部B型母
Product Description: USB3.0 HEAD FEMALE A/BACK FEMALE B

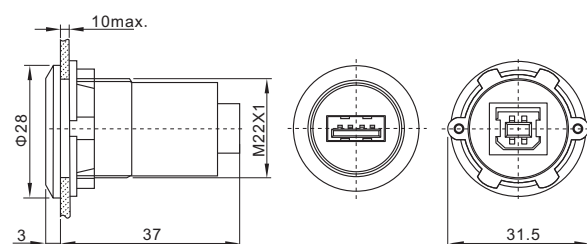


型号/Model : USB-10C



型号/Model : USB-10C-BK



产品描述 : USB3.0 头部B型母/尾部A型公
Product Description: USB3.0 HEAD FEMALE B/BACK MALE A

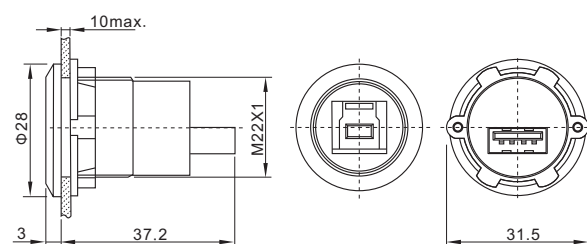



面板安装型 USB2.0转接器/线 Panel Mounting Type USB2.0 Connector

- 工程塑料壳体，有黑色和银白两色可选，其他颜色可定制。
Engineering plastic shell, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Panel Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 30\text{MB/s}$
Transmission Rate: $\geq 30\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : USB-05C



型号/Model : USB-05C-BK



产品描述：带灯USB2.0 头部A型母/尾部A型公
Product Description: Illuminated USB2.0 HEAD FEMALE A/BACK MALE A
线长：约60cm
Wire Length: About 60cm

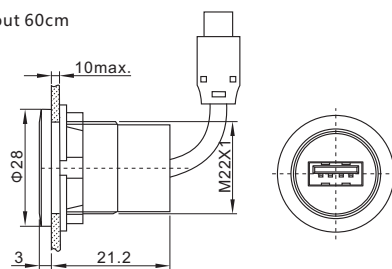


型号/Model : USB-19C



型号/Model : USB-19C-BK




产品描述：USB2.0 头部A型母/尾部A型公
Product Description: USB2.0 FEMALE A/MALE A
线长：约60cm
Wire Length: About 60cm

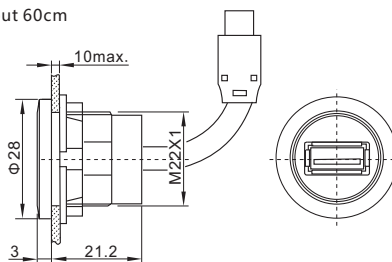

型号/Model : USB-23-BK



产品描述：USB2.0 头部A型母/尾部A型公
Product Description: USB2.0 FEMALE A/MALE A
线长：约60cm
Wire Length: About 60cm

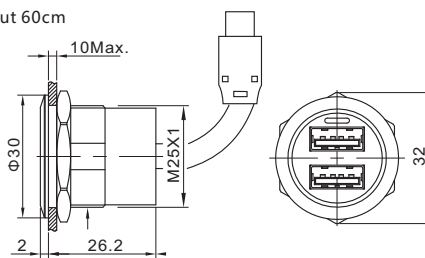




面板安装型 USB2.0转接器/线 Panel Mounting Type USB2.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 30\text{MB/s}$
Transmission Rate: $\geq 30\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)

型号/Model : USB-01

型号/Model : USB-01-BK


产品描述 : USB2.0 头部A型母/尾部A型公
Product Description: USB2.0 HEAD FEMALE A/BACK MALE A

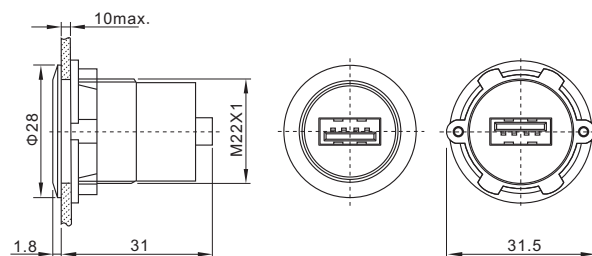

型号/Model : USB-02

型号/Model : USB-02-BK


产品描述 : USB2.0 头部A型母/尾部B型母
Product Description: USB2.0 HEAD FEMALE A/BACK FEMALE B

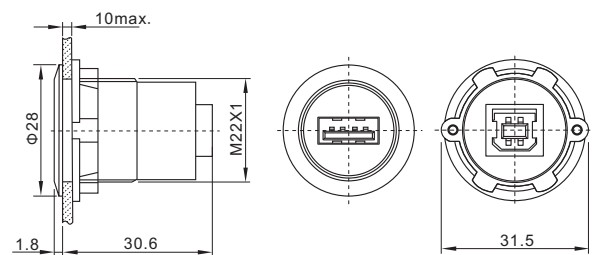

型号/Model : USB-03

型号/Model : USB-03-BK


产品描述 : USB2.0 头部B型母/尾部A型公
Product Description: USB2.0 HEAD FEMALE B/BACK MALE A

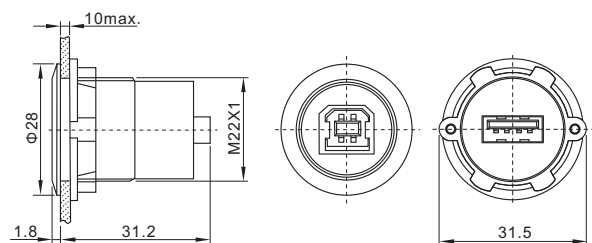

型号/Model : USB-04

型号/Model : USB-04-BK

产品描述 : USB2.0 头部B型母/尾部B型母
Product Description: USB2.0 HEAD FEMALE B/BACK FEMALE B

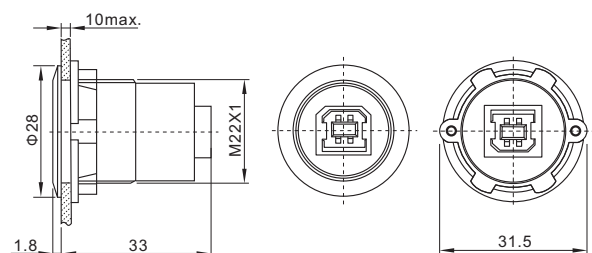



面板安装型 USB2.0转接器/线 Panel Mounting Type USB2.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 30\text{MB/s}$
Transmission Rate: $\geq 30\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : USB-06



型号/Model : USB-06-BK



产品描述: 双层USB2.0 头部A型母/尾部A型公
Product Description: Double USB2.0 HEAD FEMALE A/BACK MALE A
线长: 约60cm
Wire Length: About 60cm

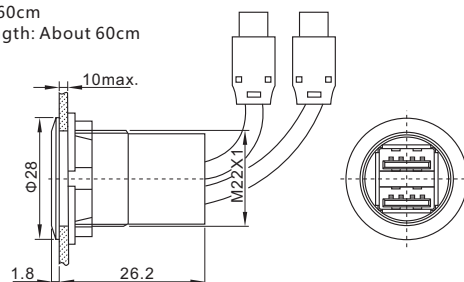


型号/Model : USB-07



型号/Model : USB-07-BK



产品描述: 双层USB2.0 头部A型母/尾部A型母
Product Description: Double USB2.0 HEAD FEMALE A/BACK FEMALE A

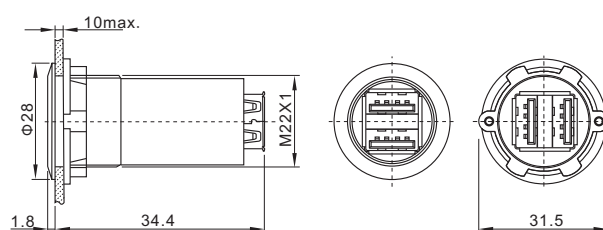


型号/Model : USB-19



型号/Model : USB-19-BK



产品描述: USB2.0 头部A型母/尾部A型公
Product Description: USB2.0 FEMALE A/MALE A
线长: 约60cm
Wire Length: About 60cm

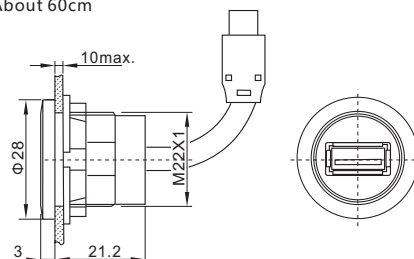


型号/Model : USB-26



型号/Model : USB-26-BK



产品描述: USB2.0 头部A型母/尾部A型公
Product Description: USB2.0 FEMALE A/MALE A
线长: 约60cm
Wire Length: About 60cm

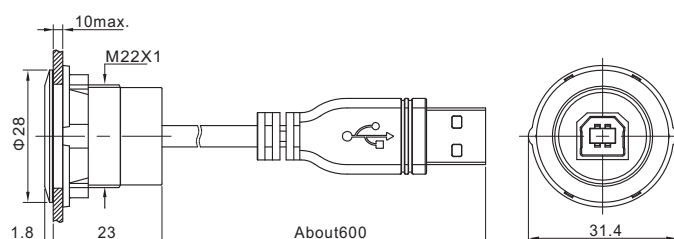



面板安装型 USB3.0转接器/线 Panel Mounting Type USB3.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 100\text{MB/s}$
Transmission Rate: $\geq 100\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : USB-08



型号/Model : USB-08-BK



产品描述 : USB3.0 头部A型母/尾部A型公
Product Description: USB3.0 HEAD FEMALE A/BACK MALE A

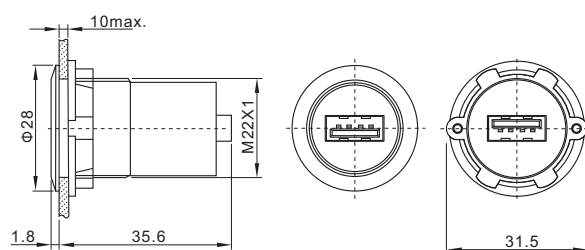


型号/Model : USB-09



型号/Model : USB-09-BK



产品描述 : USB3.0 头部A型母/尾部B型母
Product Description: USB3.0 HEAD FEMALE A/BACK FEMALE B

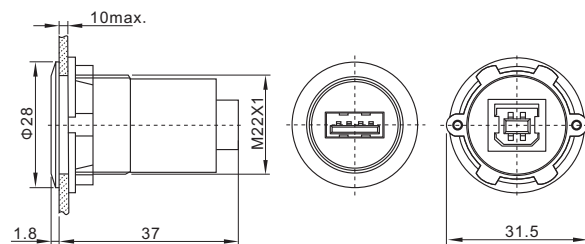


型号/Model : USB-10



型号/Model : USB-10-BK



产品描述 : USB3.0 头部B型母/尾部A型公
Product Description: USB3.0 HEAD FEMALE B/BACK MALE A

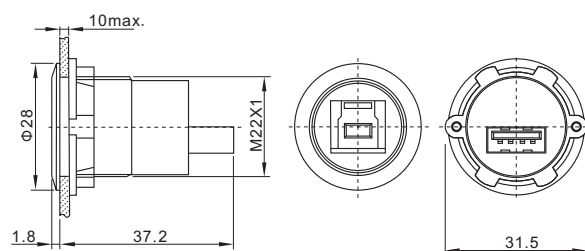



面板安装型 USB3.0转接器/线 Panel Mounting Type USB3.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22,25\text{mm}$
Panel Cutout: $\Phi 22,25\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 100\text{MB/s}$
Transmission Rate: $\geq 100\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : USB-12



型号/Model : USB-12-BK



产品描述 : USB3.0 头部A型母/尾部A型公
Product Description: USB3.0 HEAD FEMALE A/BACK MALE A
线长 : 约60cm
Wire Length: About 60cm

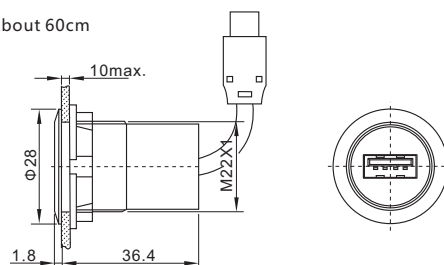


型号/Model : USB-13



型号/Model : USB-13-BK



产品描述 : 双层USB3.0 头部A型母/尾部A型公
Product Description: Double USB3.0 HEAD FEMALE A/BACK MALE A
线长 : 约60cm
Wire Length : About 60cm

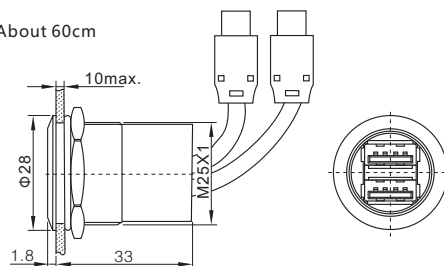


型号/Model : USB-14



型号/Model : USB-14-BK



产品描述 : 双层USB3.0 头部A型母/尾部A型公
Product Description: Double USB3.0 HEAD FEMALE A/BACK MALE A

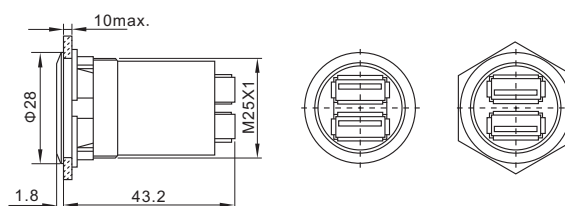



面板安装型 USB3.1转USB-C转接器

Panel Mounting Type
USB3.1 to USB-C Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22,25\text{mm}$
Pane Cutout: $\Phi 22,25\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 100\text{MB/s}$
Transmission Rate: $\geq 100\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : USB-17



型号/Model : USB-17-BK



产品描述: 带灯USB3.1 头部A型母/尾部C型公
Product Description: Illuminated USB3.1 HEAD FEMALE A/BACK MALE C
线长: 约60cm
Wire Length: About 60cm

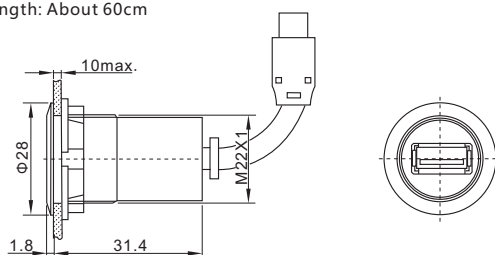


型号/Model : USB-18



型号/Model : USB-18-BK



产品描述: USB3.1 头部A型母/尾部C型公
Product Description: USB3.1 HEAD FEMALE A/BACK MALE C

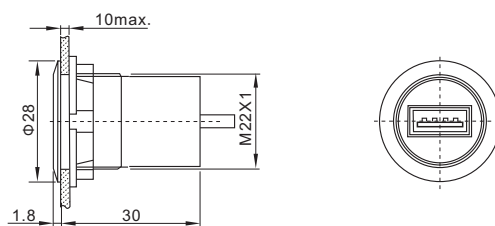



面板安装型 USB3.1转接器/线 Panel Mounting Type USB 3.1 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Black and silver color aluminium alloy housing, other colors can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度：-25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C (NO Freezing)
- 面板开孔尺寸：Φ22,25mm
Panel Cutout: Φ22,25mm
- 面板厚度：1~10mm
Panel Thickness: 1~10mm
- 功能：5A 快速充电，10GBps 速率
Function: 5A fast charging, 10GBps rate
- 应用：充电+数据传输+视频同步传输+延长数据线
Application: MP3 / MP4 player, Video game player, Camera and Mobile phone


型号/Model：USBC-01



型号/Model：USBC-01-BK



产品描述：USB3.1 头部C型母/尾部C型母
Product Description: USB3.1 FEMALE C/ FEMALE C

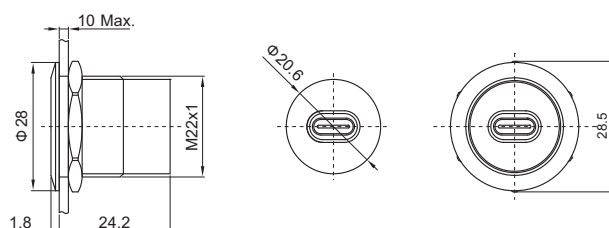


型号/Model：USBC-02



型号/Model：USBC-02-BK



产品描述：USB3.1 头部C型母/尾部C型公
Product Description: USB3.1 FEMALE C/ MALE C

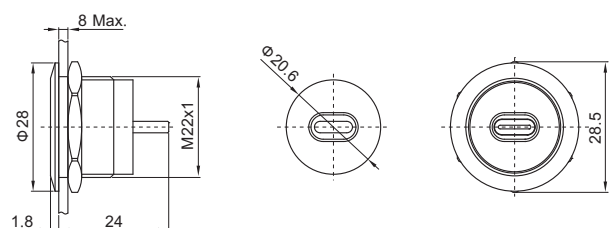


型号/Model：USBC-03



型号/Model：USBC-03-BK



产品描述：USB3.1 头部C型母/尾部A型母
Product Description: USB3.1 FEMALE C/ USB3.0 FEMALE A

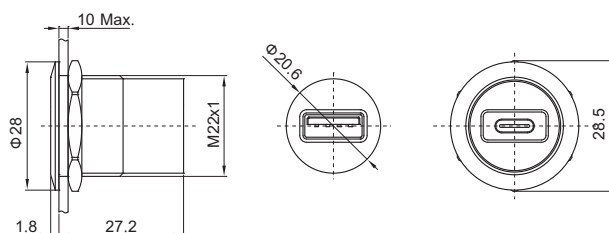


型号/Model：USBC-04



型号/Model：USBC-04-BK



产品描述：USB3.1 头部C型母/尾部C型公 100cm cable
Product Description: USB3.1 FEMALE C/ MALE C 100cm cable

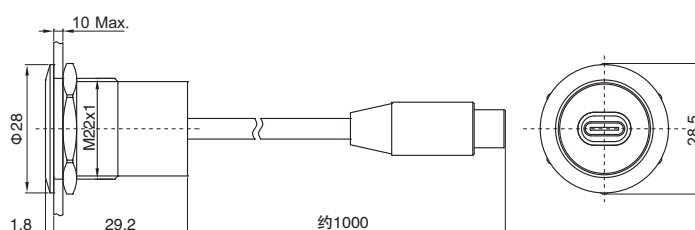



面板安装型 USB3.1转接器/线 Panel Mounting Type USB 3.1 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Black and silver color aluminium alloy housing, other colors can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度：-25℃~+55℃(无冰冻)
Operating Temperature: -25℃~+55℃ (NO Freezing)
- 面板开孔尺寸：Φ22,25mm
Panel Cutout: Φ22,25mm
- 面板厚度：1~10mm
Panel Thickness: 1~10mm
- 功能：5A 快速充电，10GBps 速率
Function: 5A fast charging, 10GBps rate
- 应用：充电+数据传输+视频同步传输+延长数据线
Application: MP3 / MP4 player, Video game player, Camera and Mobile phone


型号/Model：USBC-06



型号/Model：USBC-06-BK



产品描述：USB3.1 头部C型母/尾部C型母 100cm cable
Product Description: USB3.1 FEMALE C/ FEMALE C

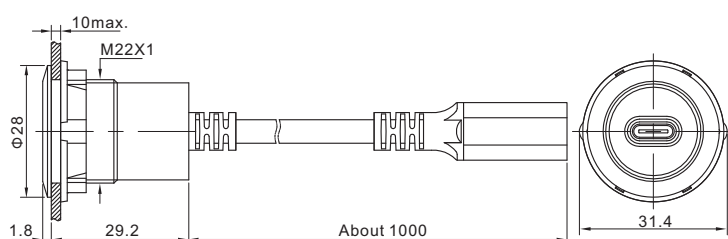


型号/Model：USBC-07



型号/Model：USBC-07-BK



产品描述：USB3.1 头部C型母/尾部USB2.0A型公 100cm cable
Product Description: USB3.1 FEMALE C/ USB2.0 MALE A

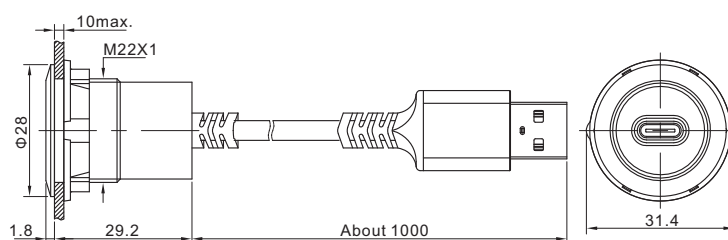


型号/Model：USBC-08



型号/Model：USBC-08-BK



产品描述：USB3.1 头部C型母/尾部B型公 100cm cable
Product Description: USB3.1 FEMALE C/ USB2.0 MALE B

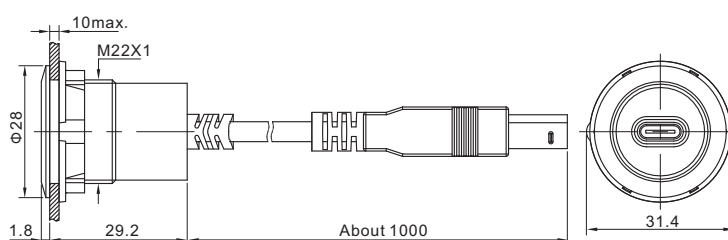


型号/Model：USBC-09



型号/Model：USBC-09-BK



产品描述：USB3.1 头部C型母/尾部USB3.0 A型公 100cm cable
Product Description: USB3.1 FEMALE C/ USB3.0 MALE A 100cm cable

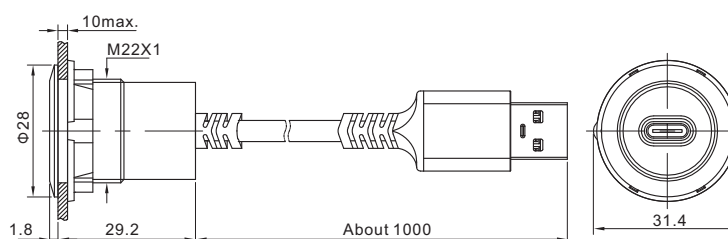



面板安装型 USB3.1转接器/线 Panel Mounting Type USB 3.1 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Black and silver color aluminium alloy housing, other colors can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度：-25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C (NO Freezing)
- 面板开孔尺寸：Φ22,25mm
Panel Cutout: Φ22,25mm
- 面板厚度：1~10mm
Panel Thickness: 1~10mm
- 功能：5A 快速充电，10GBps 速率
Function: 5A fast charging, 10GBps rate
- 应用：充电+数据传输+视频同步传输+延长数据线
Application: MP3 / MP4 player, Video game player, Camera and Mobile phone


型号/Model：USBC-10



型号/Model：USBC-10-BK



产品描述：USB3.1 头部C型母/尾部C型公
Product Description: USB3.1 FEMALE C/ MALE C

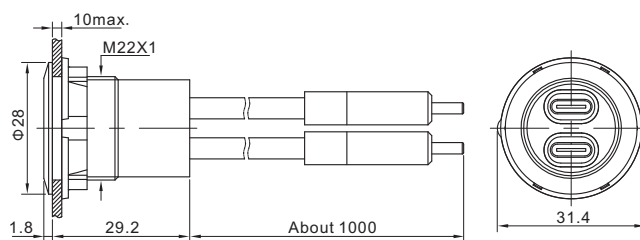


型号/Model：USBC-11



型号/Model：USBC-11-BK



产品描述：USB3.1 头部C型母/尾部C型公
Product Description: USB3.1 FEMALE C/ MALE C

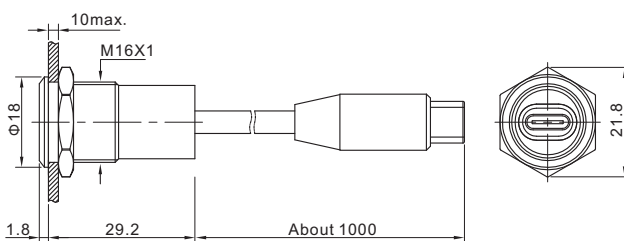



面板安装型 迷你USB2.0转接器/线 Panel Mounting Type Mini USB2.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Black and silver color aluminium alloy housing, other colors can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度：-25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C (NO Freezing)
- 面板开孔尺寸：Φ22mm
Panel Cutout: Φ22mm
- 面板厚度：1~10mm
Panel Thickness: 1~10mm
- 传输速率：≥30MB/s
Transmission Rate: ≥30MB/s
- 操作环境湿度：45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : Mini USB-01



型号/Model : Mini USB-01-BK



产品描述：Mini USB2.0 头部B型母/尾部B型公
Product Description: Mini USB2.0 FEMALE B/ MALE B

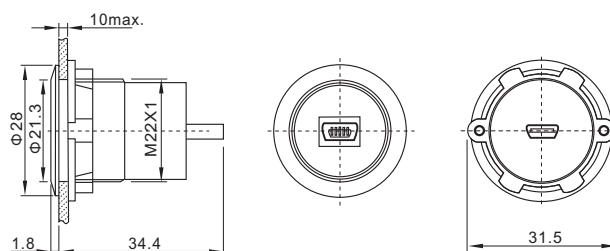


型号/Model : Mini USB-04



型号/Model : Mini USB-04-BK



产品描述：Mini USB2.0 头部2 B型母/尾部B型公
Product Description: Mini USB2.0 2 FEMALE B/ MALE B

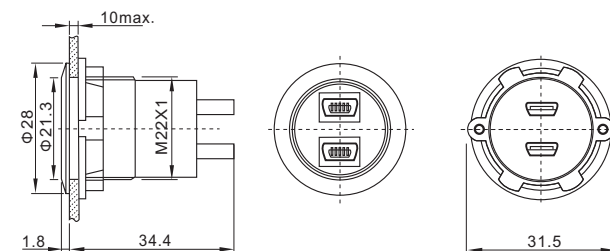



面板安装型 微型USB2.0转接器/线 Panel Mounting Type Micro USB2.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 传输速率: $\geq 30\text{MB/s}$
Transmission Rate: $\geq 30\text{MB/s}$
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : Micro USB-01



型号/Model : Micro USB-01-BK



产品描述 : Micro USB2.0 头部B型母/尾部B型公
Product Description: Micro USB2.0 FEMALE B/ MALE B

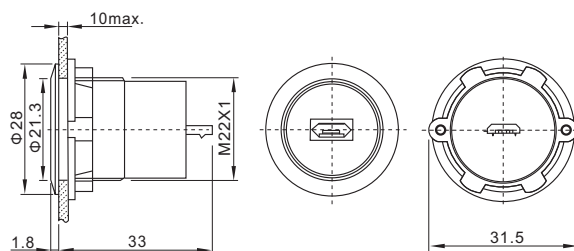


型号/Model : Micro USB-02



型号/Model : Micro USB-02-BK



产品描述 : Micro USB2.0 头部2 B型母/尾部B型公
Product Description: Micro USB2.0 2 FEMALE B/ MALE B
线长 : 约60cm
Wire Length : About 60cm

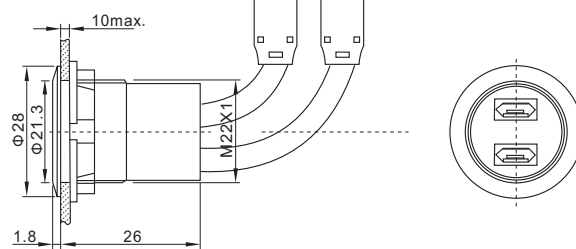


型号/Model : Micro USB-03



型号/Model : Micro USB-03-BK



产品描述 : Micro USB2.0 头部2 B型母/尾部B型公
Product Description: Micro USB2.0 2 FEMALE B/ MALE B

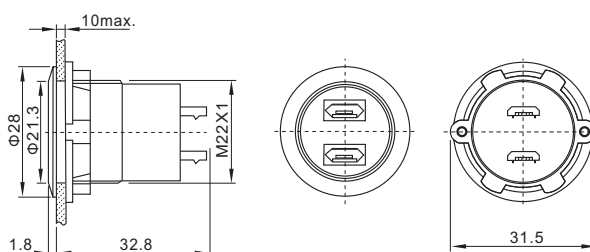


型号/Model : Micro USB-04



型号/Model : Micro USB-04-BK



产品描述 : Micro USB2.0 头部B型母/尾部B型公
Product Description: Micro USB2.0 FEMALE B/ MALE B

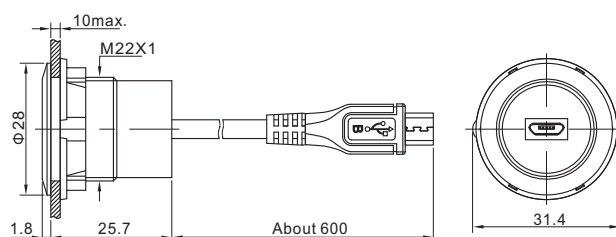



面板安装型 其它转接器/线 Panel Mounting Type USB2.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)



型号/Model : STEREO-02



型号/Model : STEREO-02-BK



产品描述 : 头部STEREO母/尾部STEREO公
Product Description: STEREO FEMALE/STEREO MALE
线长 : 约60cm
Wire Length : About 60cm

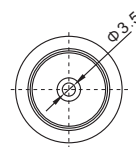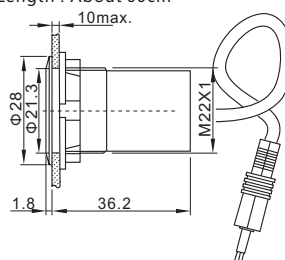



型号/Model : RJ45-01



型号/Model : RJ45-01-BK



产品描述 : 头部RJ45母/尾部RJ45公
Product Description: RJ45 FEMALE/RJ45 MALE
线长 : 约60cm
Wire Length : About 60cm

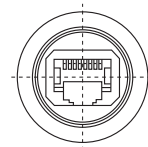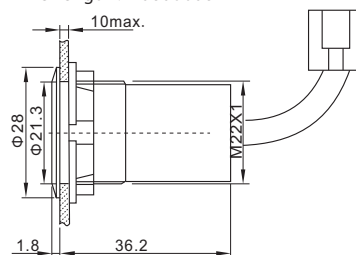




型号/Model : RJ45-02



型号/Model : RJ45-02-BK



产品描述 : 头部RJ45母/尾部RJ45母
Product Description: RJ45 FEMALE/RJ45 FEMALE

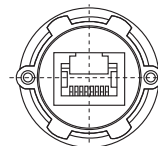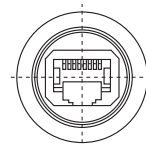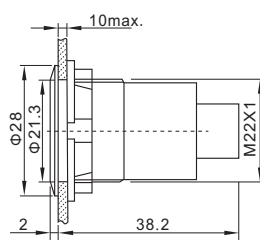




型号/Model : RJ45-02C



型号/Model : RJ45-02C-BK



产品描述 : 头部RJ45母/尾部RJ45母
Product Description: RJ45 FEMALE/RJ45 FEMALE

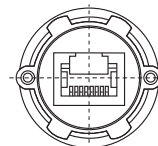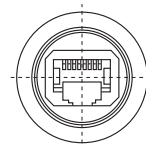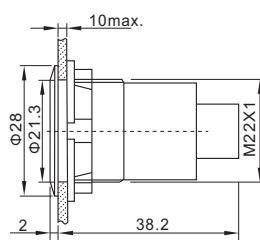



面板安装型 其它转接器/线 Panel Mounting Type USB2.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : Power jack-01



型号/Model : Power jack-01-BK



产品描述：头部电源插孔/尾部电源插头
Product Description: Power jack FEMALE/Power jack MALE
线长：约150cm
Wire Length : About 150cm

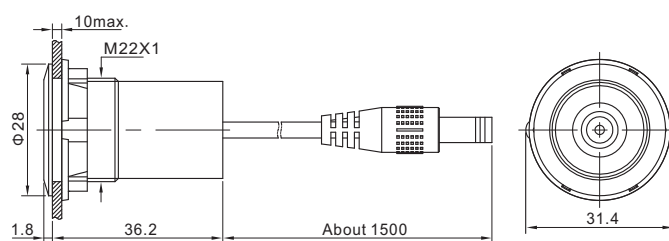



面板安装型 其它转接器/线 Panel Mounting Type USB2.0 Connector

- 金属外壳采用铝合金材质，有黑色和银白两色可选，其他颜色可定制。
Metal crust made of Aluminium Alloy, have black and silver for your choose, other color can be customized.
- 使用螺母固定，安装简便。
Fixed by nut, easy to install.
- 操作环境温度: -25°C~+55°C(无冰冻)
Operating Temperature: -25°C~+55°C(NO Freezing)
- 面板开孔尺寸: $\Phi 22\text{mm}$
Pane Cutout: $\Phi 22\text{mm}$
- 面板厚度: 1~10mm
Panel Thickness: 1~10mm
- 操作环境湿度: 45~85%RH(无结露)
Operating Humidity: 45~85%RH(NO Condensation)


型号/Model : HDMI-01



型号/Model : HDMI-01-BK



产品描述 : 头部HDMI母/尾部HDMI公
Product Description: HDMI FEMALE/HDMI MALE

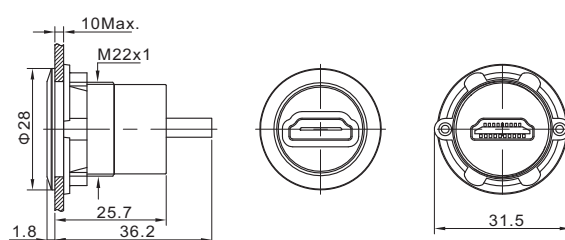


型号/Model : HDMI-02



型号/Model : HDMI-02-BK



产品描述 : 头部HDMI母/尾部HDMI母
Product Description: HDMI FEMALE/HDMI FEMALE

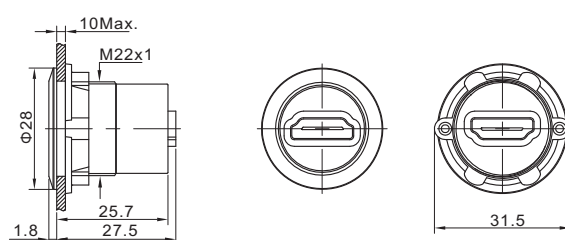


型号/Model : HDMI-03



型号/Model : HDMI-03-BK



产品描述 : 头部HDMI母/尾部HDMI公
Product Description: HDMI FEMALE/HDMI MALE
线长 : 约60cm
Wire Length : About 60cm

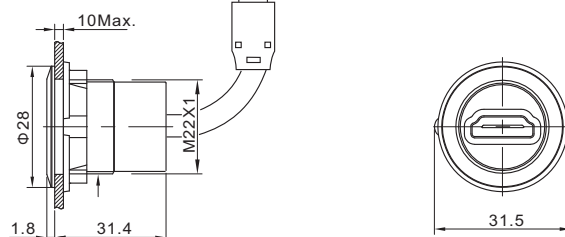


型号/Model : DP-01



型号/Model : DP-01-BK



产品描述 : 头部HDMI母/尾部HDMI母
Product Description: HDMI FEMALE/HDMI FEMALE

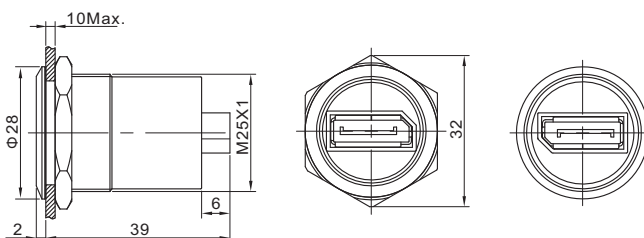

附件 Accessory

型号/Model : Protective 01



型号/Model : Protective 02

 



保护罩01用于USB-05 与 USB-05-BK


Protective 01 only for USB-05 and USB-05-BK Version

保护罩02用于USB-05 与 USB-05-BK以外的Φ22mm产品

Protective 02 for Φ22mm diameter products except USB-05 and USB-05-BK

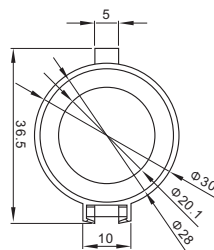

保护罩01 Protective 01

 

保护罩02 Protective 02

型号/Model : Protective 03



保护罩03用于所有Φ22mm产品

用于密封,可使产品达到IP65

Protective 03 for all Φ22mm diameter products

For sealing, the product can reach IP65.

