


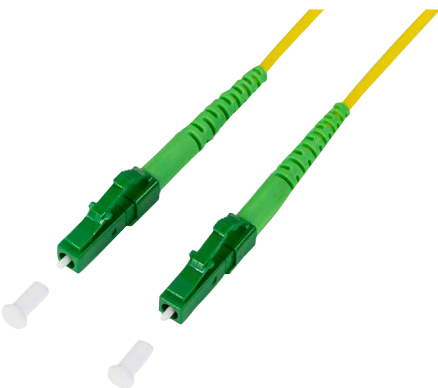


Fiber Simplex Patch Cable

LC/APC–LC/APC Polish

Technical Features

- LC/APC–LC/APC polish
- OS2 9/125 μm, compliant with G.657.A2
- Jacket: LSZH, yellow, Ø2 mm
- Test report included

Technical Drawings

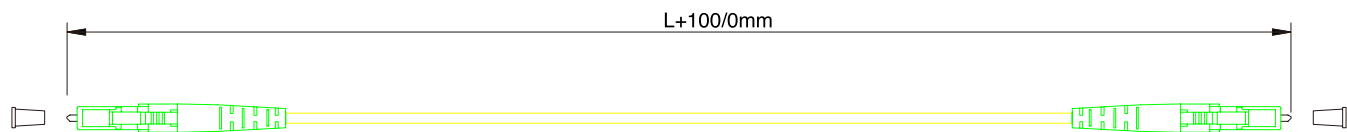

Test Grade Designation:Each to Reference		
Grade IL/RL	Standard	
Insertion Loss (IL)	≤0.3dB	IEC 61300-3-4
Return Loss(RL)	APC≥60dB	IEC 61300-3-6
Test Wavelength	1310nm	
End face inspection	×400	

Art. No.	Length	EAN Code	Art. No.	Length	EAN Code
FPSLC00	0.5 m	4052792066067	FPSLC25	25.0 m	4052792079777
FPSLC01	1.0 m	4052792066074	FPSLC30	30.0 m	4052792079784
FPSLC02	2.0 m	4052792066081	FPSLC40	40.0 m	4052792079791
FPSLC03	3.0 m	4052792066098	FPSLC50	50.0 m	4052792079807
FPSLC05	5.0 m	4052792066104	FPSLC11	100.0 m	4052792079814
FPSLC10	10.0 m	4052792066111			
FPSLC15	15.0 m	4052792066128			
FPSLC20	20.0 m	4052792066135			

Package Contents

1 x Fiber Simplex Patch Cable

Packaging Information

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
FPSLC00	18 x 18 x 2 mm	0.011 kg	450 x 250 x 235 mm	300 pcs	4.035 kg
FPSLC01	18 x 18 x 2 mm	0.013 kg	450 x 250 x 235 mm	250 pcs	3.92 kg
FPSLC02	18 x 18 x 4 mm	0.016 kg	450 x 250 x 235 mm	200 pcs	3.98 kg
FPSLC03	22 x 22 x 4 mm	0.02 kg	450 x 250 x 235 mm	160 pcs	3.89 kg
FPSLC05	22 x 22 x 6 mm	0.027 kg	450 x 250 x 235 mm	60 pcs	2.328 kg
FPSLC10	22 x 22 x 6 mm	0.044 kg	450 x 250 x 235 mm	60 pcs	3.378 kg
FPSLC15	22 x 22 x 8 mm	0.062 kg	450 x 250 x 235 mm	50 pcs	3.81 kg
FPSLC20	22 x 22 x 8 mm	0.079 kg	450 x 250 x 235 mm	40 pcs	3.892 kg
FPSLC25	mm	kg	mm	pcs	kg
FPSLC30	mm	kg	mm	pcs	kg
FPSLC40	mm	kg	mm	pcs	kg
FPSLC50	mm	kg	mm	pcs	kg
FPSLC11	mm	kg	mm	pcs	kg



Made in China

www.2direct.de 

*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.