


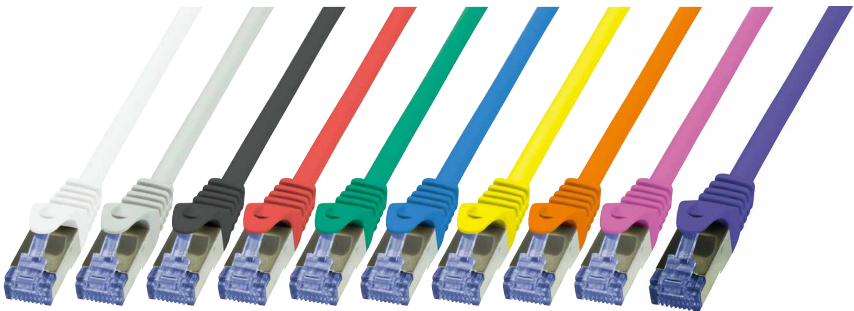

Cat.6A 10G S/FTP Patch Cable PrimeLine

Technical Features

Cat.6A ClassEA S/FTP RJ45 Patch Cord

Compliant to ISO/IEC 11801 & EN 50173

26/7 AWG copper wire


Shielded RJ45 plugs with gold plated pins

Shielded twisted pair cable, pairs in metal foil (PIMF) LSZH (low smoke zero halogen)

6.2±0.2 mm outer dimension

Fire resistance: IEC60332-1-2

Technical Drawings

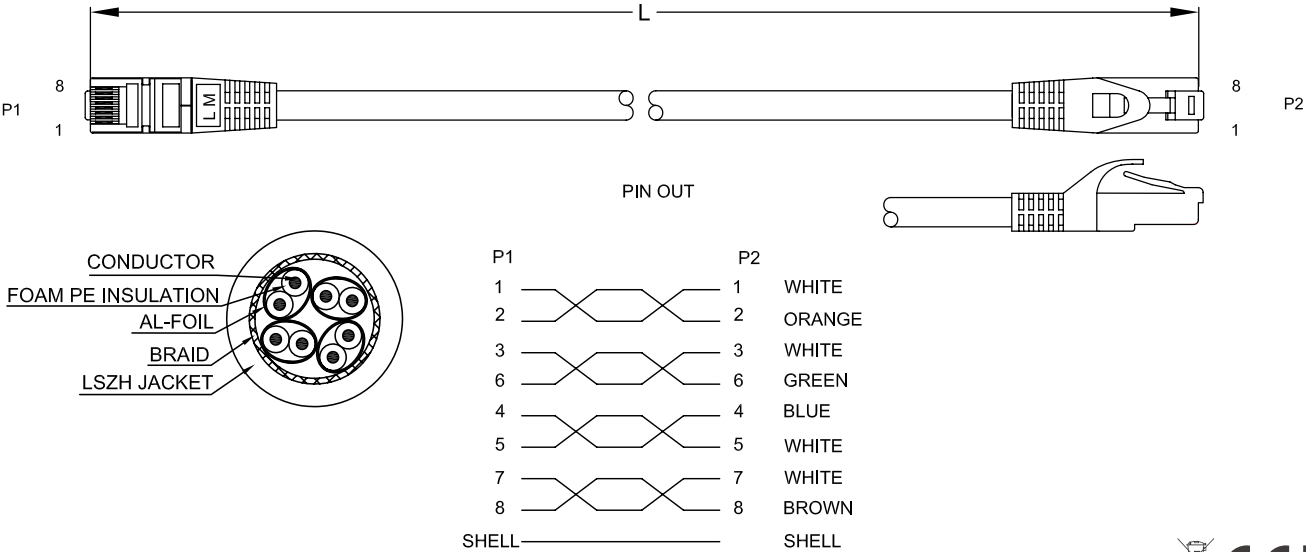

www.2direct.de




Length	White	EAN Code
0.25 m	CQ3011S	4052792020045
0.50 m	CQ3021S	4052792020052
1.00 m	CQ3031S	4052792020069
1.50 m	CQ3041S	4052792020076
2.00 m	CQ3051S	4052792020083
3.00 m	CQ3061S	4052792020090
5.00 m	CQ3071S	4052792020106
7.50 m	CQ3081S	4052792020113
10.00 m	CQ3091S	4052792020120
15.00 m	CQ3101S	4052792020137
20.00 m	CQ3111S	4052792020144
30.00 m	CQ3121S	4052792020151
40.00 m	CQ3131S	4052792070514
50.00 m	CQ3141S	4052792020168



Length	Grey	EAN Code	Black	EAN Code
0.25 m	CQ3012S	4052792020175	CQ3013S	4052792020267
0.50 m	CQ3022S	4052792020182	CQ3023S	4052792020274
1.00 m	CQ3032S	4052792020199	CQ3033S	4052792020281
1.50 m	CQ3042S	4052792020205	CQ3043S	4052792020298
2.00 m	CQ3052S	4052792020212	CQ3053S	4052792020304
3.00 m	CQ3062S	4052792020229	CQ3063S	4052792020311
5.00 m	CQ3072S	4052792020236	CQ3073S	4052792020328
7.50 m	CQ3082S	4052792020243	CQ3083S	4052792020335
10.00 m	CQ3092S	4052792020250	CQ3093S	4052792020342
15.00 m	CQ3102S	4052792029369	CQ3103S	4052792040579
20.00 m	CQ3112S	4052792029376	CQ3113S	4052792040586
30.00 m	CQ3122S	4052792029383	CQ3123S	4052792040593
40.00 m	CQ3132S	4052792070521	CQ3133S	4052792070538
50.00 m	CQ3142S	4052792029390	CQ3143S	4052792040609

Length	Red	EAN Code
0.25 m	CQ3014S	4052792020359
0.50 m	CQ3024S	4052792020366
1.00 m	CQ3034S	4052792020373
1.50 m	CQ3044S	4052792020380
2.00 m	CQ3054S	4052792020397
3.00 m	CQ3064S	4052792020403
5.00 m	CQ3074S	4052792020410
7.50 m	CQ3084S	4052792020427
10.00 m	CQ3094S	4052792020434

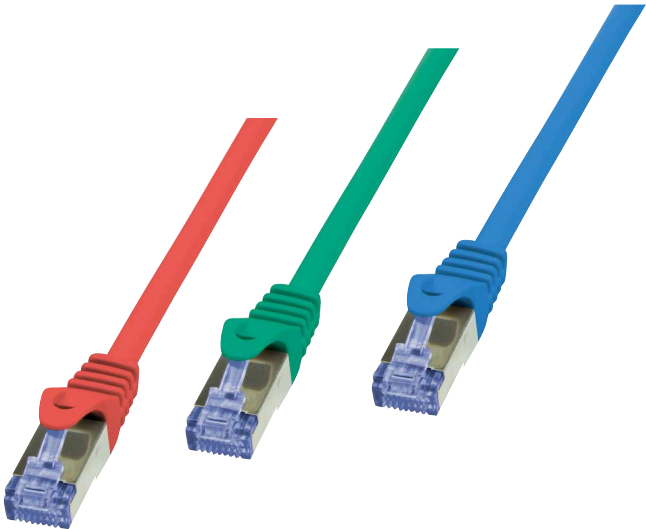

Length	Green	EAN Code	Blue	EAN Code
0.25 m	CQ3015S	4052792020441	CQ3016S	4052792020533
0.50 m	CQ3025S	4052792020458	CQ3026S	4052792020540
1.00 m	CQ3035S	4052792020465	CQ3036S	4052792020557
1.50 m	CQ3045S	4052792020472	CQ3046S	4052792020564
2.00 m	CQ3055S	4052792020489	CQ3056S	4052792020571
3.00 m	CQ3065S	4052792020496	CQ3066S	4052792020588
5.00 m	CQ3075S	4052792020502	CQ3076S	4052792020595
7.50 m	CQ3085S	4052792020519	CQ3086S	4052792020601
10.00 m	CQ3095S	4052792020526	CQ3096S	4052792020618

Length	Yellow	EAN Code	Violet	EAN Code
0.25 m	CQ3017S	4052792020625	CQ301VS	4052792043235
0.50 m	CQ3027S	4052792020632	CQ302VS	4052792043242
1.00 m	CQ3037S	4052792020649	CQ303VS	4052792043259
1.50 m	CQ3047S	4052792020656	CQ304VS	4052792043266
2.00 m	CQ3057S	4052792020663	CQ305VS	4052792043273
3.00 m	CQ3067S	4052792020670	CQ306VS	4052792043280
5.00 m	CQ3077S	4052792020687	CQ307VS	4052792043297
7.50 m	CQ3087S	4052792020694	CQ308VS	4052792043303
10.00 m	CQ3097S	4052792020700	CQ309VS	4052792043310

Length	Orange	EAN Code	Pink	EAN Code
0.25 m	CQ3018S	4052792020717	CQ3019S	4052792020809
0.50 m	CQ3028S	4052792020724	CQ3029S	4052792020816
1.00 m	CQ3038S	4052792020731	CQ3039S	4052792020823
1.50 m	CQ3048S	4052792020748	CQ3049S	4052792020830
2.00 m	CQ3058S	4052792020755	CQ3059S	4052792020847
3.00 m	CQ3068S	4052792020762	CQ3069S	4052792020854
5.00 m	CQ3078S	4052792020779	CQ3079S	4052792020861
7.50 m	CQ3088S	4052792020786	CQ3089S	4052792020878
10.00 m	CQ3098S	4052792020793	CQ3099S	4052792020885

Package Content

1x Cat.6A S/FTP Patch Cable

Packaging Information

Cable Length	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
0.25 m	120 x 160 mm	0.02 kg	400 x 300 x 220 mm	260 pcs	5.7 kg
0.50 m	120 x 160 mm	0.03 kg	450 x 300 x 290 mm	300 pcs	9.2 kg
1.00 m	140 x 180 mm	0.05 kg	450 x 300 x 250 mm	180 pcs	8.6 kg
1.50 m	140 x 180 mm	0.06 kg	450 x 300 x 230 mm	120 pcs	7.8 kg
2.00 m	160 x 200 mm	0.08 kg	450 x 300 x 250 mm	100 pcs	8 kg
3.00 m	160 x 200 mm	0.11 kg	450 x 300 x 250 mm	80 pcs	9.3 kg
5.00 m	180 x 230 mm	0.18 kg	450 x 300 x 270 mm	50 pcs	9.1 kg
7.50 m	180 x 230 mm	0.28 kg	360 x 360 x 300 mm	40 pcs	10.5 kg
10.00 m	200 x 240 mm	0.35 kg	450 x 300 x 270 mm	30 pcs	10.7 kg
15.00 m	200 x 240 mm	0.52 kg	400 x 300 x 220 mm	15 pcs	7.7 kg
20.00 m	220 x 260 mm	0.68 kg	400 x 300 x 200 mm	10 pcs	7.3 kg
30.00 m	220 x 260 mm	1.05 kg	400 x 300 x 230 mm	8 pcs	8.5 kg
40.00 m	300 x 330 mm	1.4 kg	400 x 300 x 250 mm	6 pcs	8.8 kg
50.00 m	300 x 330 mm	1.75 kg	400 x 300 x 300 mm	8 pcs	13 kg