
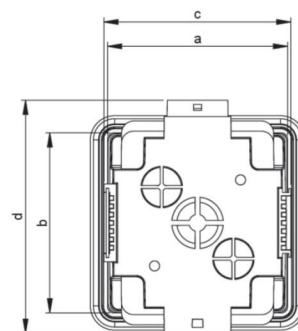


article#	883-6gv
article description	CEE-flush socket outlet incl. flush socket Design 16A 3p 6h IP44 (grey)
description long	CEE-flush socket outlet incl. flush socket Design 16A 3p 6h IP44 (grey) housing material: PC/ABS rated current: 16A number of poles: 3 (2P+PE) clock-position: 6h rated voltage/frequency: 200-250V~ / 50+60Hz contacts: brass nickel plated connection technology: screw terminals color: grey (similar to RAL 7035) flush mounting (incl. Flush socket) hinged lid with inscription field (optional: key lock) IP protection class: IP44
GTIN (EAN)	9003399677519
country of origin	AT
customs number	85366990
net weight	0.298 kg
packaging quantity	6
minimum order quantity	6

ETIM 9.0	EC001321
Model	Flush-mounted
IEC-ampereage	16 A
Number of poles	3
Voltage according to EN 60309-2	200-250 V (50+60 Hz) blue
Clock hour position	6 h
Identification colour	Blue
Degree of protection (IP)	IP44
Connection system	Screw terminal
Material	Plastic
Contact material	CuZn
Surface treatment contacts	Nickel-plated

a	90 mm
b	90 mm
c	92 mm
d	115 mm
e	64 mm
f	35 mm
wire flexible	1-2x2,5 mm ²
wire solid	1-2x4 mm ²
contact screws	100 Ncm
dismantling length	50 mm
stripping length	10-12 mm
ambient temperature	-25 – 40 °C
temperature resistance	-25 – 80 °C

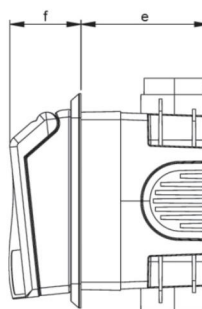

<https://www.pcelectric.at/shop/en/?func=detail&artnr=883-6gv>