

Hand Soldering, Desoldering, & Rework

 
 
 
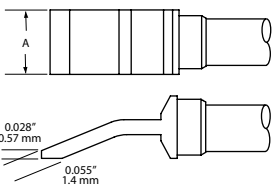
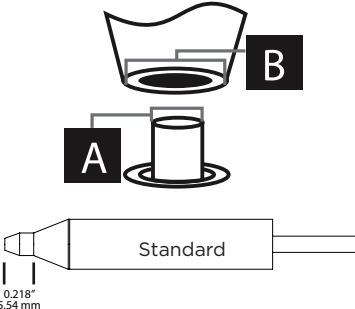
 
TxP Tweezer, DxP Desoldering Cartridges



Temperature Guide & Tip Specifications TxP & DxP-Series

Max Temperature	MFR-Series	Application
690°F/366°C	TTP & DTP	Temperature Sensitive
790°F/421°C	TFP & DFP	Fiberglass, Most Standard
880°F/471°C	TCP & DCP	Ceramic and High Thermal Demand
TxP Tweezer Cartridges compatible with: MFR-1140, MFR-2240, MFR2241 Systems and MFR-H4-TW Handpiece DxP Desoldering Tips compatible with: MFR-1150, MFR-1350, MFR-1351 systems with MFR-H5-DS Handpiece and previous MFR-DSX, -DSI, -SDX, -SDI Systems with MFR-HDS Handpiece. All dimensions shown are in mm (inches).		

Please note the above temperatures are the maximum temperatures of the heater. The idle temperature is dependent on the geometry of the cartridge (up to 15°C lower)

TxP - Rework Tweezer Cartridges - Conical		MFR Series					
		TFP-CNP1	(Ø x L), 0.4 mm x 19.1 mm (0.015" x 0.75"), sold per pair				
		TTP-CNP1					
		TCP-CNP1					
TxP - Rework Tweezer Cartridges - Blade		MFR Series					
		TFP-BLP1	(W x L), 1.0 mm x 14 mm (0.04" x 0.55"), sold per pair				
		TTP-BLP1					
		TCP-BLP1					
		TFP-BLP2	(W x L), 2.0 mm x 14 mm (0.08" x 0.55"), sold per pair				
		TTP-BLP2					
		TCP-BLP2					
TxP - Rework Tweezer Cartridges - Wide Blade		MFR Series		A			
		TFP-BLH40	6.35 mm (0.25"), sold per pair				
		TTP-BLH40					
		TCP-BLH40					
		TFP-BLH50	16 mm (0.62"), sold per pair				
		TTP-BLH50					
		TCP-BLH50					
		TFP-BLH60	20.5 mm (0.81"), sold per pair				
		TTP-BLH60					
		TCP-BLH60					
		TFP-BLH70	28 mm (1.1"), sold per pair				
		TTP-BLH70					
		TCP-BLH70					
DxP - Desoldering Tips		MFR Series		A	B	Type	
		DFP-CN2	0.64 (0.025)		1.78 (0.070)	Standard	
		DCP-CN2					
		DFP-CN3	0.76 (0.030)		2.03 (0.080)	Standard	
		DCP-CN3					
		DFP-CN4	1.02 (0.040)		2.28 (0.090)	Standard	
		DCP-CN4					
		DFP-CN5	1.27 (0.050)		2.64 (0.104)	Standard	
		DCP-CN5					
		DFP-CN6	1.52 (0.060)		2.84 (0.112)	Standard	
		DCP-CN6					
		DFP-CN7	2.41 (0.095)		3.63 (0.143)	Standard	
		DCP-CN7					
			DFP-CNL3	0.76 (0.030)		2.03 (0.080)	Long Reach
			DCP-CNL3				
		DFP-CNL4	1.02 (0.040)		2.28 (0.090)	Long Reach	
		DCP-CNL4					
		DFP-CNL5	1.27 (0.050)		2.64 (0.104)	Long Reach	
	DCP-CNL5						

All dimensions shown are in mm (inches)

For our complete selection of tips & cartridges, visit www.metcal.com