

PRODUCT DATA SHEET

3967

Receptacles insu. – 3967 Ms sn Pa gelb6.3x0.8



Product Overview

SKU	3967
Part description	Receptacles insulated with extra support-sleeve
Part designation	3967 Ms sn Pa gelb6.3x0.8

Material

Component	brass
Surface	Pure tin-plated
Insulation	PA

Technical Details


Net. weight kg/1000	2.010
Conductor cross-section	4.0 - 6.0 mm ² (AWG 12-10)
Temperatur resistance	105° C (600V)
Current load max. at 6mm ²	24A
Current load max. at 4mm ²	20A

Marking

Approved UL	E235796
colorcode	gelb
RoHS, REACH, DRC	compliant

Dimension

Size	6.3 x 0.8
øD [mm]	3.4
L [mm]	24

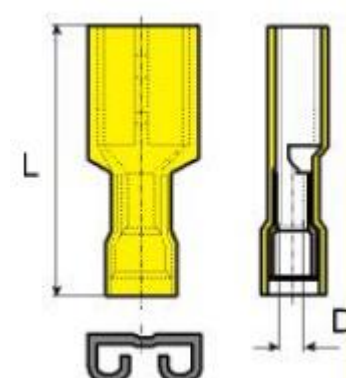

© 2020 / Vogt AG Verbindungstechnik

This leaflet is for general information about the base material only and is not subject to revision.

The data given are no warranty that the product is of a specified quality and they can not replace customer's own test and expert advice regarding the application of the manufactured component.