

„DESIGN” Surface-mounted through socket 16A 3P 250V IP44


Cat. No. **883108GV**



- with screw terminals
- housing material: PC/ABS
- contacts: nickel-plated contacts
- with pin
- Flange can be rotated by 180° - straight and sloping design all in one!
- one side entry with offset nipple, possible entry on the other with cutout
- with inscription field
- with integrated cover frame and a fix
- IP protection class: **IP44 splashproof**

Connection
to the future

DIMENSIONS:

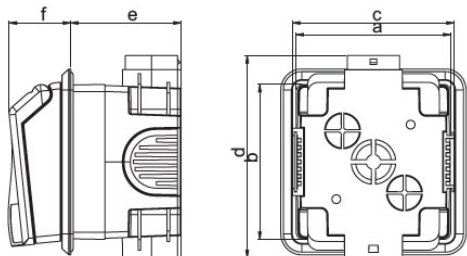

	16 Amp			32 Amp	SSD
Poles	3	4	5	5	2P+E
Flange a x b [mm]	90	90	90	90	90
Fixing center c [mm]	92	92	92	92	92
Fixing center d [mm]	115	115	115	115	115
e [mm]	64	64	64	64	64
f [mm]	35	35	35	35	35
Wire flexible [mm²]	1- 2x2,5			2,5- 2x6	1- 2x2,5
Wire solid [mm²]	1- 2x4			2,5- 2x10	1- 2x2,5
Contact screws [Ncm]	100			110	
Weight [g]	298	316	335	391	264

PCE Polska Sp. z o. o.

ul. Podwalna 8A
58-200 Dzierżoniów
TEL. +48 74 831 76 00
MAIL: pce@pce.pl
www.pce.pl