

7500 Rocker Switches

30A 250Vac




Key Features

- IP68 Rated
- Rated to 30A at 250V
- Available colours:
 - Transparent: Red, Green, Blue, Yellow, White,
 - Solid: Black
- Termination options: Screw Terminal, 6.3 X 0.8mm solder tab / Push fit
- Switch functions available: ON-OFF, ON-ON, ON-OFF-ON.
- Panel Cut Out - 30mm x 22mm

Approvals and specifications

UL = 30A 250Vac, 40T85, 1E4 (10,000 cycles)
 cUL = 30A 250Vac, 40T85, 1E4 (10,000 cycles)

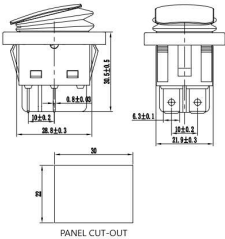

Terminal	Function	Rocker	Lamp Voltage	Rocker Colour
C 6.3 x 0.8mm	7510 ON - OFF	T Transparent 	000 No LED	Illuminated (DP) R Red G Green B Blue Y Yellow W White K Black Non-Illuminated (DP)
	7520 ON - ON	S Solid 	012 12V	
	7530 ON - OFF - ON		024 24V	
S Screw & Clamp			110 110V	
			250 250V	

General Specifications	
Electrical	
Voltage	250VAC
Current	30A
Insulation Resistance	$\geq 50\text{M}\Omega/500\text{VDC}$
Power-Frequency Withstand Voltage	AC1500v 10s
Durability	10,000
Operating Temperature	-40°C to 85°C
Switch Contact Configuration	Double Pole
Technical	
Panel Mount Cut-Out	22mm X 30mm Square
Max Panel Thickness	2.5mm
Max Panel Thickness	Copper Nickel plated
Body Material	PA66 Nylon
Terminal Material	Brass (Silver Plated)
Approvals	UL (File Number: E45221)
IP Rating	IP68