




A

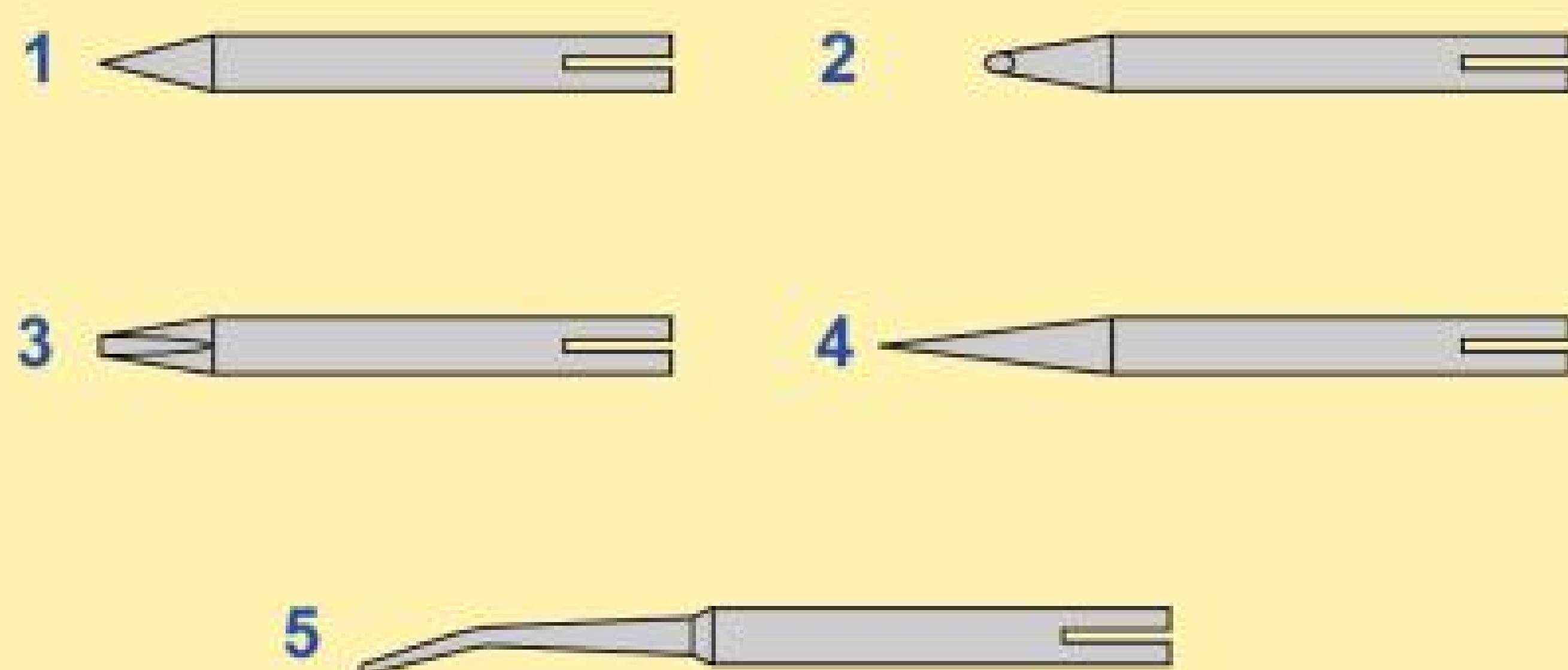


B

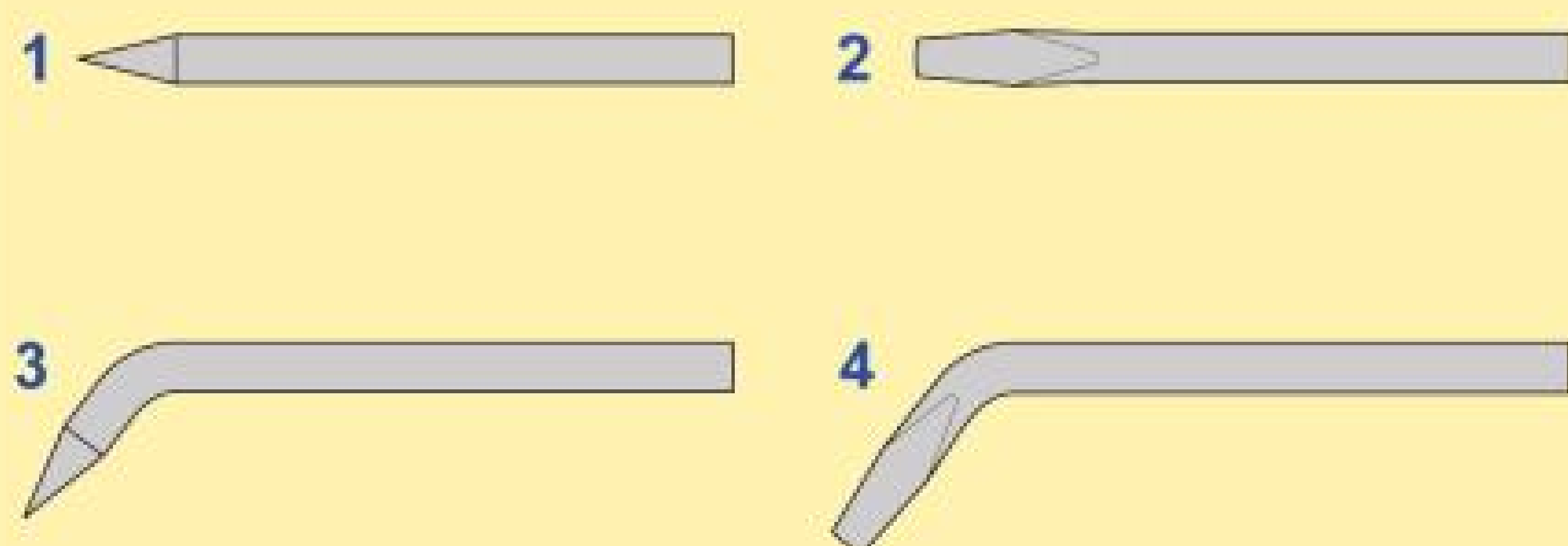


C

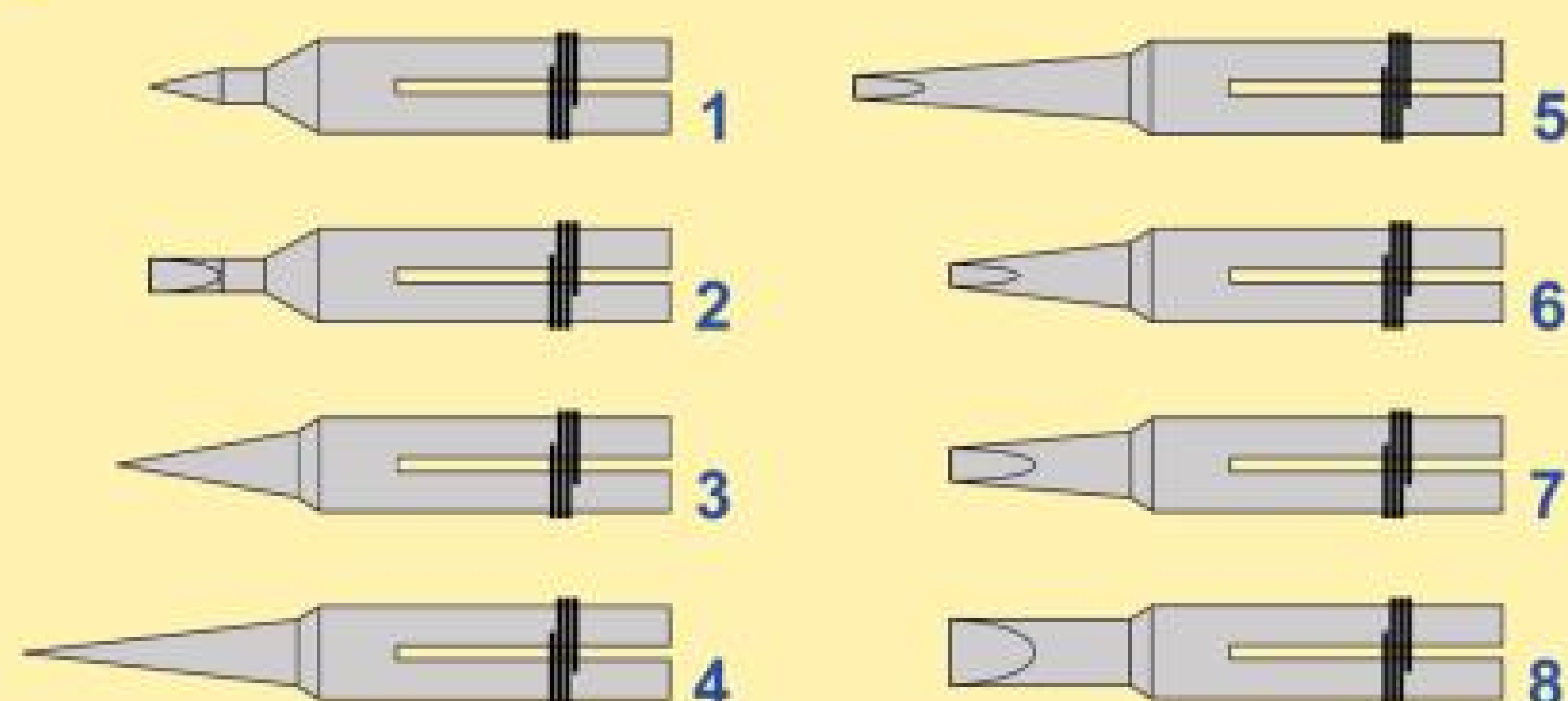

D

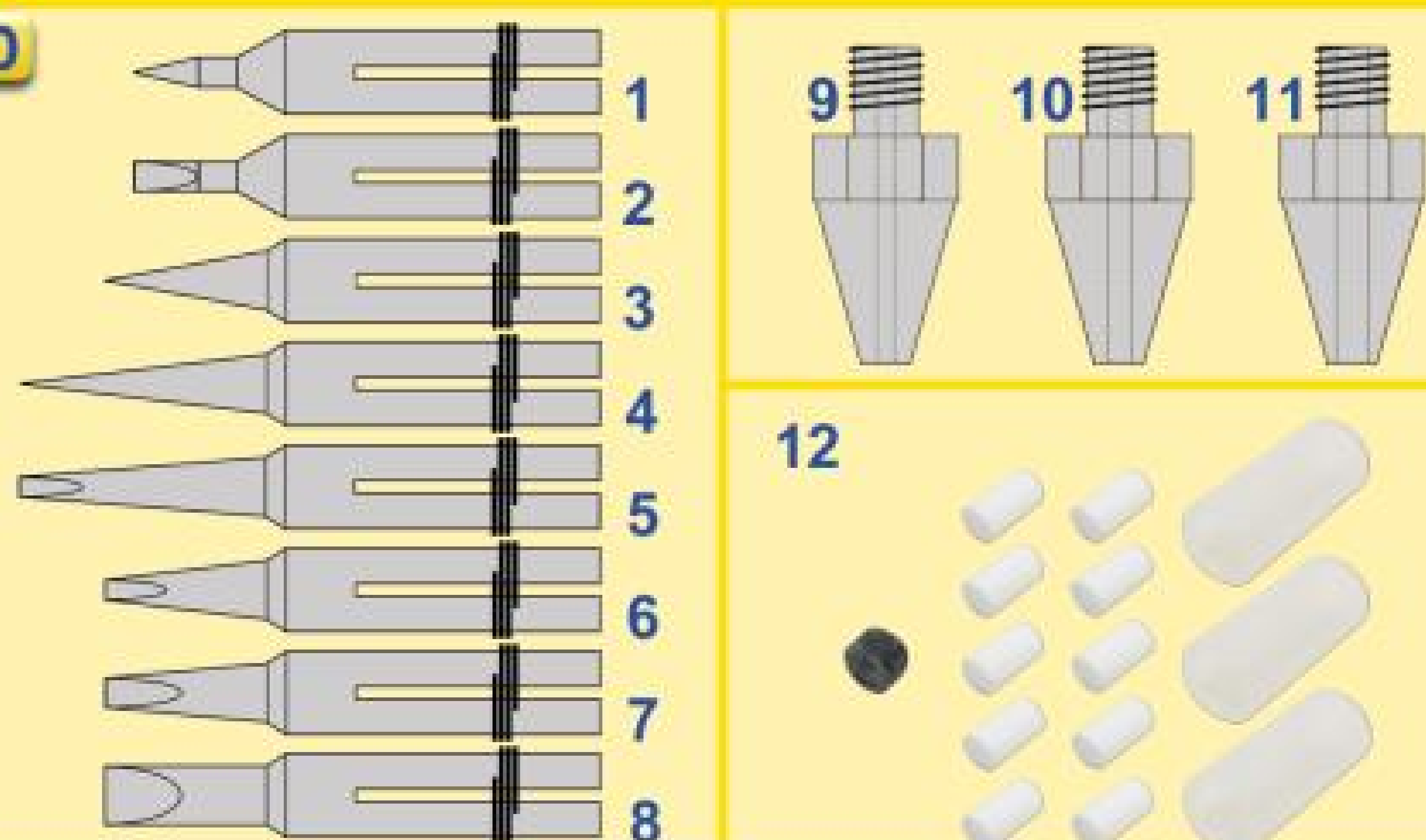

E

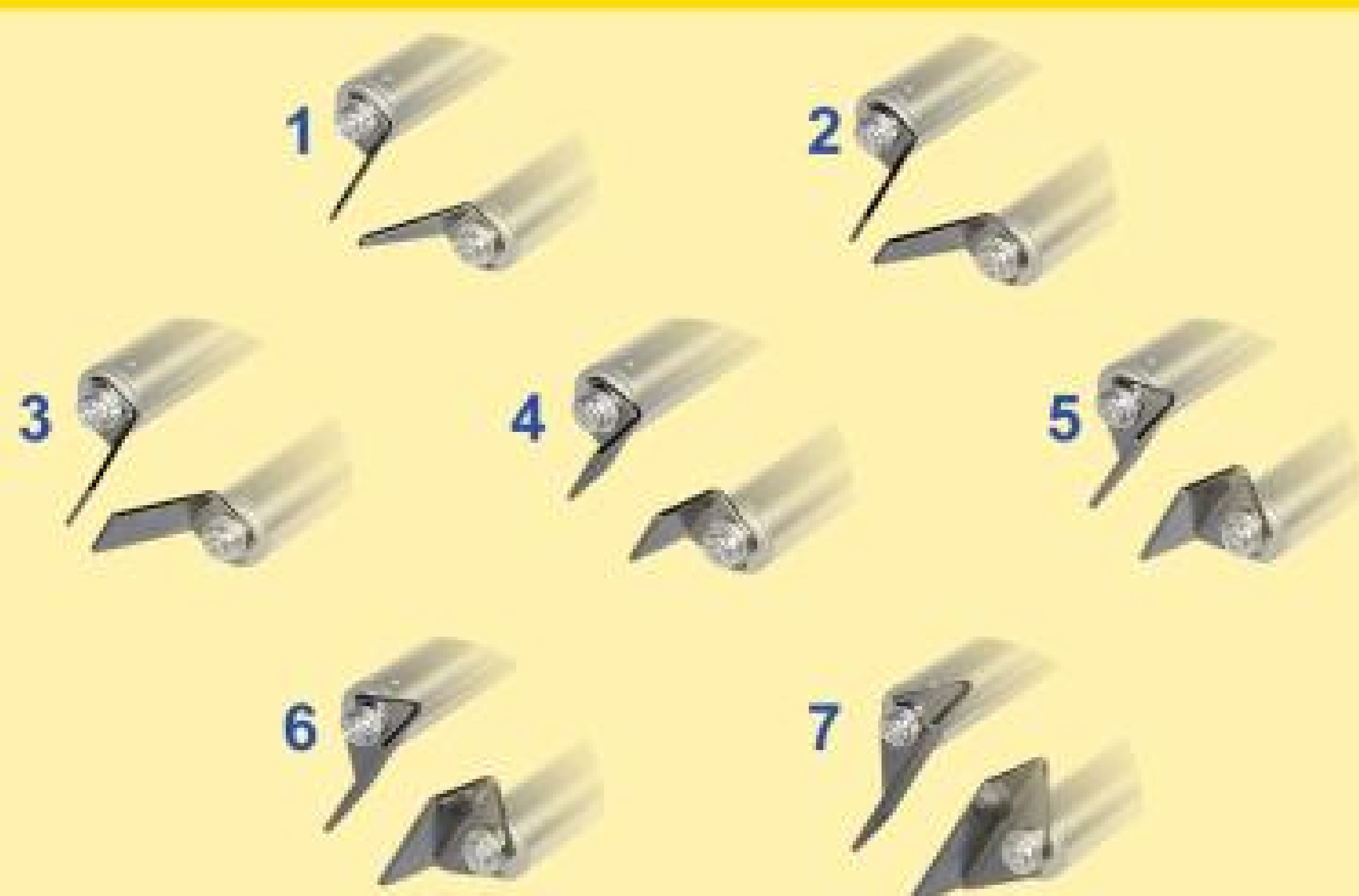

A

Lötspitzen / soldering iron tips

2 mm Lötspitzen für / 2 mm soldering tips for **B8 / ST081**

No. B8-160	2 mm Bleistiftform / 2 mm pencil	(Abb. A1)
No. B8-161	2 mm Keilform / 2 mm wedge	(Abb. A2)
No. B8-162	2 mm Meißelform / 2 mm chisel	(Abb. A3)
No. B8-166	„longlife“ 2 mm Bleistiftform SMD / 2 mm pencil SMD	(Abb. A4)
No. B8-171	2 mm Modellierahle + SMD / 2 mm modelling awl + SMD	(Abb. A5)

B

Lötspitzen / soldering iron tips

4 mm Lötspitzen für / 4 mm soldering tips for **LS30**

No. LS161	4 mm Bleistiftform gerade / 4 mm pencil straight	(Abb. B1)
No. LS163	4 mm Meißelform gerade / 4 mm chisel straight	(Abb. B2)
No. GS361	4 mm Bleistiftform gebogen / 4 mm pencil bent	(Abb. B3)
No. GS363	4 mm Meißelform gebogen / 4 mm chisel bent	(Abb. B4)
No. LS166	„longlife“ 4 mm Bleistiftform gerade / 4 mm pencil straight	(Abb. B1)
No. LS168	„longlife“ 4 mm Meißelform gerade / 4 mm chisel straight	(Abb. B2)
No. GS366	„longlife“ 4 mm Bleistiftform gebogen / 4 mm pencil bent	(Abb. B3)
No. GS368	„longlife“ 4 mm Meißelform gebogen / 4 mm chisel bent	(Abb. B4)

C

Lötspitzen / soldering iron tips

Lötspitzen innenbeheizt für / soldering tips internally heated for **ST501**

No. ST80151	Bleistiftform 0,7 mm / pencil straight 0.7 mm	(Abb. C1)
No. ST80153	Meißelform 2,8 mm / chisel 2.8 mm	(Abb. C2)
No. ST80154	Bleistiftform 1,0 mm / pencil straight 1.0 mm	(Abb. C3)
No. ST80155	Nadelform 0,8 mm für SMD / needle 0.8 mm for SMD	(Abb. C4)
No. ST80159	Nadelform 0,3 mm für SMD / needle 0.3 mm for SMD	(Abb. C4)
No. ST80158	Meißelform lang 2,2 mm / chisel long 2.2 mm	(Abb. C5)
No. ST80156	Meißelform 2,2 mm / chisel 2.2 mm	(Abb. C6)
No. ST80157	Meißelform 3,2 mm / chisel 3.2 mm	(Abb. C7)
No. ST80164	Meißelform 5,0 mm / chisel 5.0 mm	(Abb. C8)

D

Lötspitzen und Zubehör / soldering iron tips and spare parts

Lötspitzen innenbeheizt für / soldering tips internally heated for **ST504**

No. ST80151	Bleistiftform 0,7 mm / pencil straight 0.7 mm	(Abb. D1)
No. ST80153	Meißelform 2,8 mm / chisel 2.8 mm	(Abb. D2)
No. ST80154	Bleistiftform 1,0 mm / pencil straight 1.0 mm	(Abb. D3)
No. ST80155	Nadelform 0,8 mm für SMD / needle 0.8 mm for SMD	(Abb. D4)
No. ST80159	Nadelform 0,3 mm für SMD / needle 0.3 mm for SMD	(Abb. D4)
No. ST80158	Meißelform lang 2,2 mm / chisel long 2.2 mm	(Abb. D5)
No. ST80156	Meißelform 2,2 mm / chisel 2.2 mm	(Abb. D6)
No. ST80157	Meißelform 3,2 mm / chisel 3.2 mm	(Abb. D7)
No. ST80164	Meißelform 5,0 mm / chisel 5.0 mm	(Abb. D8)
No. ST90152	Entlötdüse 1,1 mm / desoldering nozzle 1.1 mm	(Abb. D9)
No. ST90153	Entlötdüse 1,5 mm / desoldering nozzle 1.5 mm	(Abb. D10)
No. ST90154	Entlötdüse 2,0 mm / desoldering nozzle 2.0 mm	(Abb. D11)
No. ST60171	Ersatzkit (1x Filzfilter / 3x Zinnauffangbehälter / 10x Luftfilter) Replacement kit (1x felt filter / 3x tin collecting container / 10x air filter)	(Abb. D12)

E

Lötspitzenpaare / soldering iron tip pairs

Lötspitzenpaare für / soldering tip pairs for **ST21508**

No. ST21431	Lötspitzenpaar 2 mm / soldering tip pair 2 mm	(Abb. E1)
No. ST21432	Lötspitzenpaar 5 mm / soldering tip pair 5 mm	(Abb. E2)
No. ST21433	Lötspitzenpaar 8 mm / soldering tip pair 8 mm	(Abb. E3)
No. ST21434	Lötspitzenpaar 10 mm / soldering tip pair 10 mm	(Abb. E4)
No. ST21435	Lötspitzenpaar 16 mm / soldering tip pair 16 mm	(Abb. E5)
No. ST21436	Lötspitzenpaar 20 mm / soldering tip pair 20 mm	(Abb. E6)
No. ST21437	Lötspitzenpaar 30 mm / soldering tip pair 30 mm	(Abb. E7)