

PRODUCT DATA SHEET

3425w

Tubular terminal – 3425 W Cu Sn 5-25

Product Overview

SKU	3425w
Part description	Tubular terminal
Part designation	3425 W Cu Sn 5-25

Material

Component	copper
Surface	Pure tin-plated

Technical Details


Net weight kg/1000	7.71
Conductor cross-section	25mm ² / AWG 4

Marking

RoHS	compliant
REACH	compliant

Dimensions

For stud-Ø [mm]	M5
øD [mm]	5.3 +0.3-0.2
øD1 [mm]	7 +/-0.6
ØD4 [mm]	9.5
B [mm]	14 +/-1.5
L [mm]	12
N [mm]	6 +/-1.5
M [mm]	6.5 +/-1.5
H [mm]	18
A [mm]	13 +/-1.0
S [mm]	2

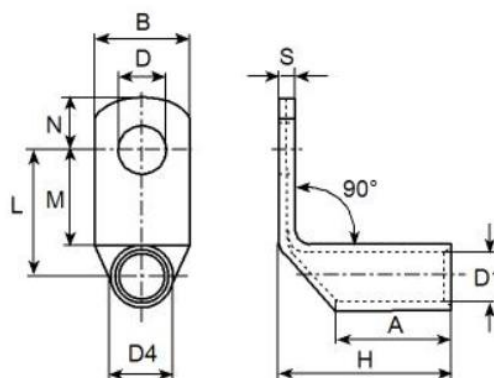

© 2021 | Vogt AG Verbindungstechnik

The general conditions of sale of Vogt AG apply to this product. See www.vogt.ch.

This data sheet is regularly revised but is not subject to any change service.

This article is a freely available article according to the above specification. The availability of certificates according to SN EN 10204, others acceptance test certificates and customer-specific part submission warrant are to be requested by the customer and, if available, can be obtained for a fee.