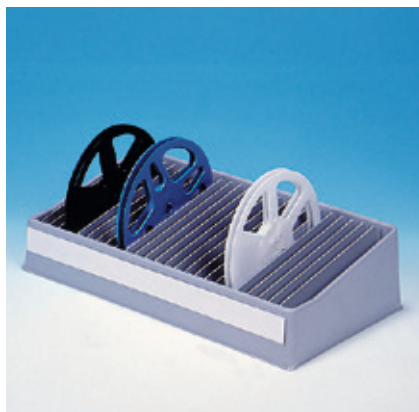


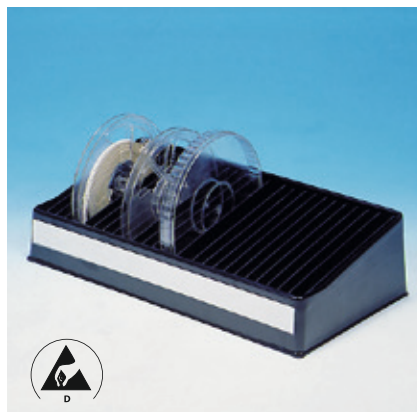
SMD SPOOL RACK

Art. No. **2426665** Designation **V 11-4**

with 25 variable partitions and
continuous identification rail
(for spools up to Ø 250)

Basic dimensions: 450 x 240

Colour ☐

Art. No. **2426666** (conductive)

Designation **V 11-4-6-10**

with 25 variable partitions and continuous
identification rail (for spools up to Ø 250)

Basic dimensions: 450 x 240

Colour ☒

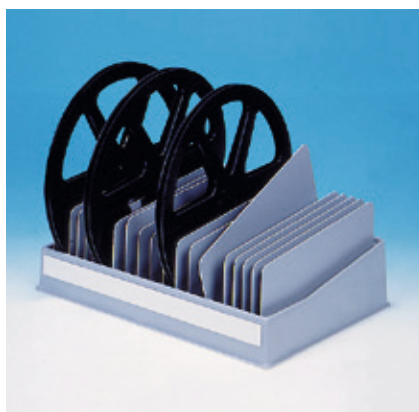
Art. No. **2426684** (conductive)

Designation **V 11-8-6-10**

Spool stands for horizontal storage of SMD spools
up to Ø 180 (First in / First out)

Outside dim.: 186 x 173 x 210

Inside dim.: 182 x 169 x 190 Colour ☒

Art. No. **2426680** Designation **V 11-7**

with 25 variable partitions and
continuous identification rail
(for spools up to Ø 330)

Basic dimensions: 455 x 315

Colour ☐

Art. No. **2426681** (conductive)

Designation **V 11-7-6-10**

with 25 variable partitions and continuous identi-
fication rail (for spools up to Ø 330)

Basic dimensions: 455 x 315

Colour ☒

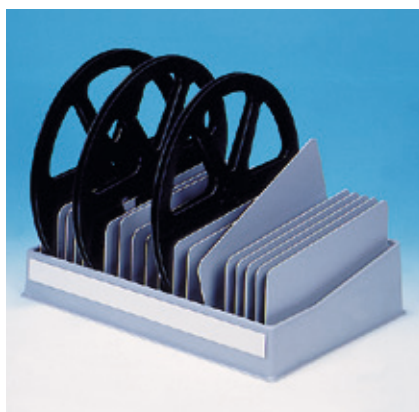
Art. No. **2426687** (conductive) Designation **V 11-9-6-10**

Spool stands for horizontal storage of
SMD spools up to Ø 330 (First in / First out)

Outside dim.: 339 x 319 x 210

Inside dim.: 335 x 315 x 190

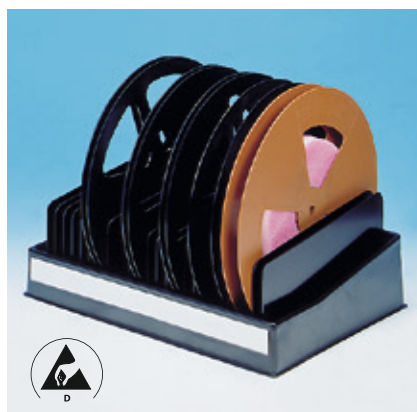
Colour ☒

Art. No. **2426629** Designation **V 11-14**

with 10 variable partitions and
continuous identification rail
(for spools up to Ø 380)

Basic dimensions: 455 x 360

Colour ☐

Art. No. **2426630** (conductive)

Designation **V 11-14-6-10**

with 10 variable partitions and continuous identifica-
tion rail (for spools up to Ø 380)

Basic dimensions: 455 x 360

Colour ☒

Art. No. **2426633** (conductive)

Designation **V 11-15-6-10** Spool stands for horizontal
storage of SMD spools up to Ø 380 (First in / First out)

Outside dim.: 390 x 373 x 250

Inside dim.: 385 x 365 x 230

Colour ☒