




Color: white

Similar to illustration

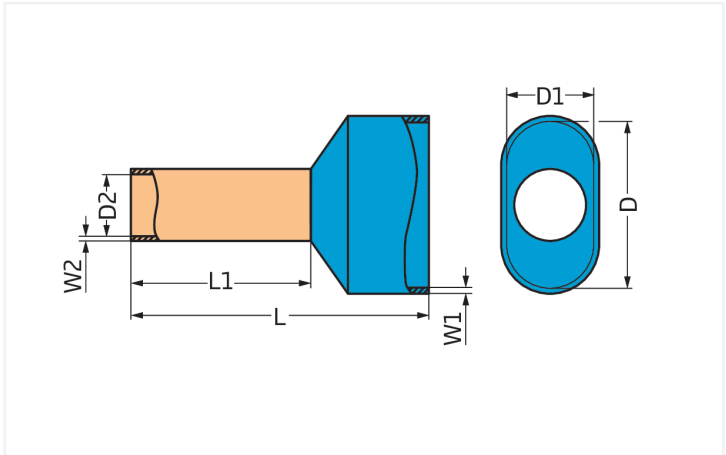

Connection data		
Strip length		12 ... 13 mm / 0.47 ... 0.51 inches
Metric cross-section of the twin ferrule		0.5 mm²
Cross-section (AWG) of twin ferrule		2 x 20 AWG

Physical data		
Total length		16 mm
Wall thickness of crimp sleeve		0.15 mm
Wall thickness (plastic collar)		0.3 mm
Inner dimension of small plastic collar		3 mm
Inner dimension plastic collar large		5 mm
Crimp length (length of sleeve)		10 mm
Diameter crimp sleeve inside		1.55 mm

Mechanical data		
Plastic collar		Standard collar

Material data		
Color		white
Fire load		0 MJ
Weight		0.6 g


Commercial data		
PU (SPU)		500 pcs
Packaging type		Box
Country of origin		DE
GTIN		4055143323819
Customs tariff number		85369010000



Product Classification	
UNSPSC	39121405
ETIM 9.0	EC000005
ETIM 8.0	EC000005
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Installation Notes

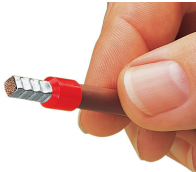

A perfect gas-tight crimp – both electrical-ly and mechanically reliable