

 
DUAL MONITOR DESK MOUNT 17" – 32"



2 × 17" – 32"
SCREEN SIZE



UP TO 2 × 9 KG
WEIGHT
CAPACITY



**75 × 75,
100 × 100**
VESA COMPATIBLE




**DUAL
ERGONOMIC
SCREEN
SETTING**



**CABLE
MANAGEMENT**

(EN) DUAL MONITOR DESK MOUNT 17" – 32"

Screen size compatibility:	17" – 32" (per screen)
Max weight capacity:	Up to 9 kg (per screen)
VESA compatibility:	75 × 75, 100 × 100
Tilt range:	+ 45° ~ - 45°
Swivel range:	+ 90° ~ - 90°
Screen rotation:	+ 180° ~ - 180°
Arm full extension:	403 mm
Material:	Steel, plastic
Surface finish:	Powder coating
Dimensions of product:	869 × 112 × 561 mm
Weight of product:	3.46 kg
Color:	Black
Installation:	Clamp, grommet
Desktop thickness for clamp:	10 – 85 mm
Desktop thickness for cables grommet:	10 – 40 mm
Package content:	Monitor desk mount, mounting elements, user manual

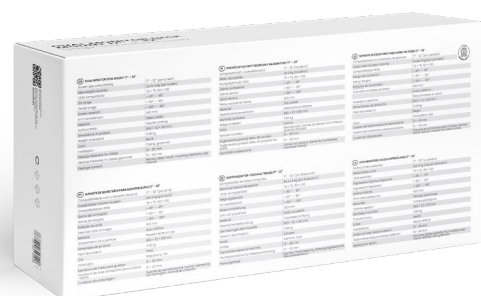

The Savio UM-03 dual monitor desk mount is a reliable and functional solution for multitaskers who use two screens simultaneously. It supports monitors from 17" to 32", each weighing up to 9 kg. A wide range of adjustments – tilt (+45°/-45°), swivel (+90°/-90°), and rotation (+180°/-180°) – allows you to precisely position your screens for enhanced comfort and ergonomic alignment.

Each arm can extend up to 403 mm, giving you great flexibility in arranging your monitors on the desk. The sturdy construction made of steel and durable plastic, coated with a scratch-resistant powder finish, ensures long-lasting stability and strength.

Installation is quick and non-invasive – you can choose between a desk clamp (for desktops 10–85 mm thick) or a grommet mount (for desktops 10–40 mm thick), depending on your preference. The mount is compatible with popular VESA standards 75×75 and 100×100, making it suitable for most monitors on the market.

Gain more workspace, keep your setup organized, and boost your productivity with the Savio UM-03.