



Qoltec Cable Patchcord FTP | CAT5e | 2 x RJ-45 | 3m | High speed | Gold | Shielded

Product code: 54528

Qoltec Patchcord FTP Cat5e cable with a length of 3m, terminated with two gold-plated RJ-45 type connectors in a sealed sheath. Used for Ethernet connections such as in offices, data centers, or even home computer networks. Allows data transfer at speeds of up to 10Gb/s. The cable have an additional protective shield.


HIGH-SPEED TRANSMISSION AND STABLE CONNECTION



Quickly transfer data at speeds of up to 10 G/s

Qoltec's FTP CAT5e cable is a 3m shielded cable designed to support data transfer speeds of up to 10 Gb/s on Ethernet networks. Suitable for high-speed data transfer applications such as file transfer, video streaming, video conferencing requiring high network bandwidth. Particularly used in data communication networks, computer networks, power transmission, data transmission and monitoring systems.


ACHIEVE A NEW LEVEL OF NETWORK EFFICIENCY

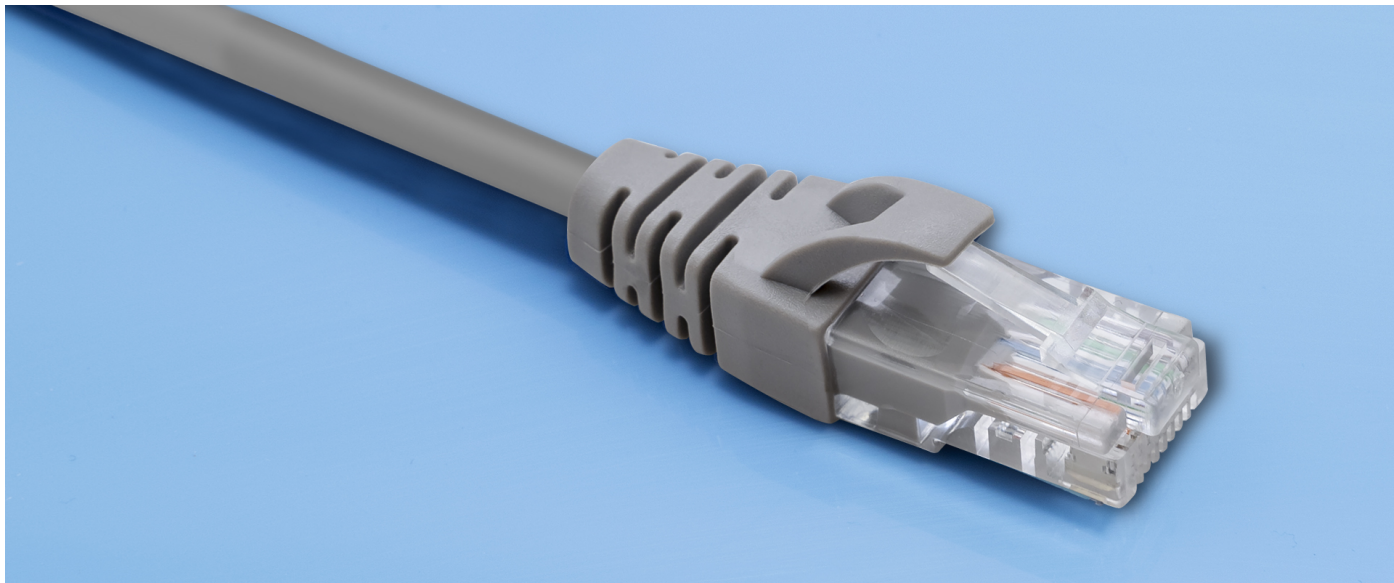

Eight pairs of twisted wires, gold-plated terminals covered with a plastic sheath

- It consists of eight twisted pairs of wires,
- The cable sheath is made of PVC,
- Each pair of wires is **covered with an insulating layer** to protect against interference,
- **Shielded** - does not have an additional protective screen,
- At both ends of the cable are **RJ-45 connectors** - standard modular connector equipped with **8 pins**,
- **The ends of the cables are gold-plated for better signal conduction**,
- The ends of the RJ-45 connectors are **covered with a plastic shield**, which helps protect the ends from mechanical damage and maintains a **stable connection**,
- **High quality** construction confirmed by warranty.

CONFIDENCE CONFIRMED BY A WARRANTY

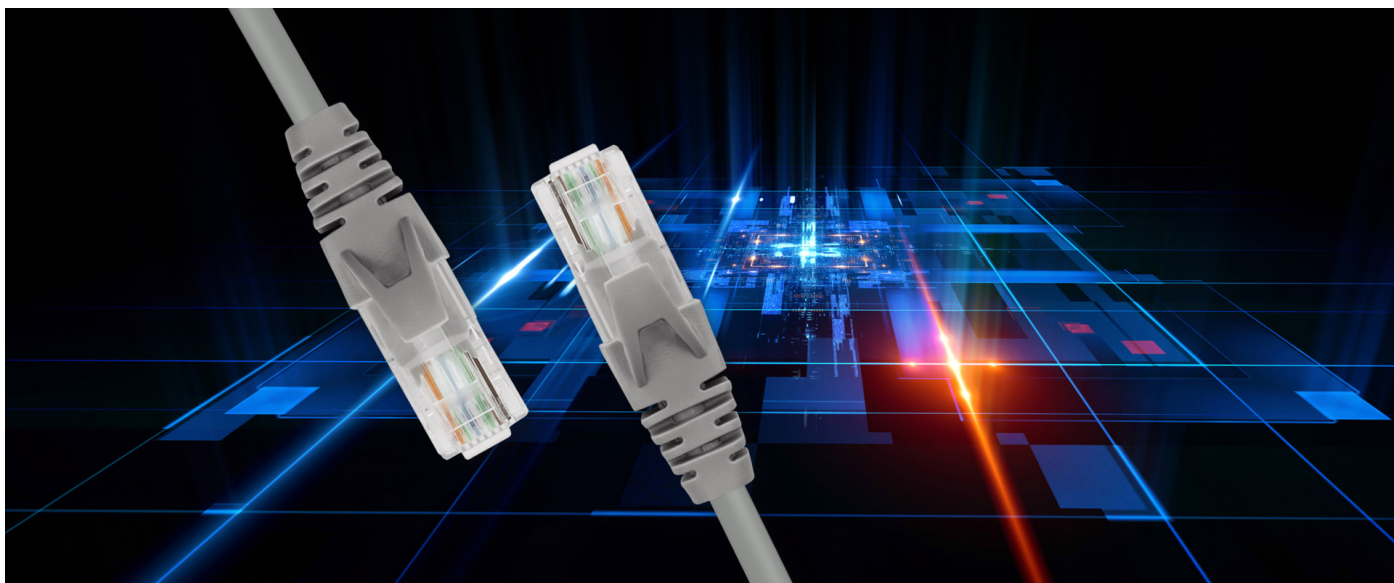

Quality Guarantee - Your Secure Connection

Do you care about the high quality of the product you are buying? Our solutions will meet your expectations. **Product is covered by a 24-month guarantee valid from the date of purchase.**

TECHNICAL DATA

Producer	Qoltec
Type patchcord	Shielded
Category	CAT5e
Class	FTP
Type connectors	2 x RJ-45
Transmission speed	10Gb/s
Coating	PCV
Conductor diameter	0.405 mm
Conductor cross-sectional area	0,129 mm
AWG cross section	26AWG
Cross-section of a vein	CU
Cable length	3m
Colour	Grey
Additional information	Gold-plated plugs
Package	Blister
Package contents	1 x Cable Patchcord
Package depth / length [mm]	246
Package width [mm]	205
Package height [mm]	10
Net weight [kg]	0.111
Gross weight [kg]	0.127
Warranty	24 month
EAN code	5901878545288