




USB Cable

Model: **AK-USB-68**

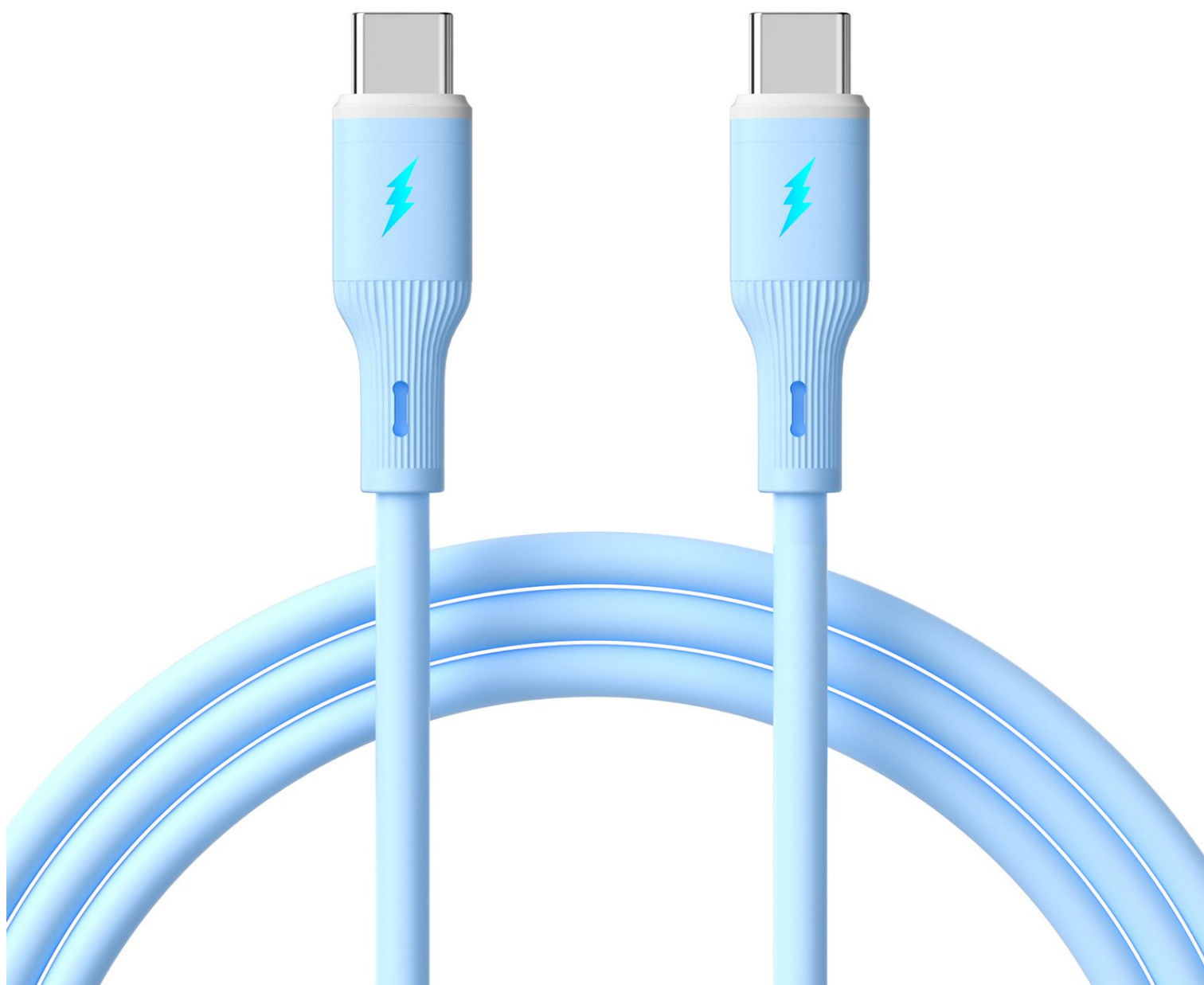

Product code	AK-USB-68
Product type	USB Cable
Responsible Entity	Akyga Europe Sp. z o.o., 52-200 Suchy Dwór, Wrocławska 1c, Polska/Poland, contact@akyga.com
Maximum power	60 W (20 V / 3 A)
Cable length	1 m
The cable plug #1	USB Male connector type C
The cable plug #2	USB Male connector type C
Data transmission	Yes
Version	USB 2.0
Plated plugs	Yes - nickel plated
Cable material	Copper
Material	Silicone
Product color	Blue
Package	UniBag
Package size (L x W x H)	120 x 40 x 20 mm
Net weight	29 g
Gross weight	32 g
CE compatibility	Yes
RoHS compatibility	Yes
REACH compatibility	Yes
EAN code	5906708750764
Warranty	24 months



Description

Akyga® AK-USB-68 is a modern **silicone USB-C - USB-C cable** that combines functionality with attractive design. The blue colour of the cable makes it easy to find in your bag or on your desk, while giving it a unique character.

Fast data transfer and charging

Thanks to its USB 2.0 compatibility, this cable supports data transfer speeds of up to 480 Mbps. You can easily sync photos, documents, or music between your smartphone and laptop. It also supports fast charging for devices with **up to 60 W of power**.

Silicone coating for comfort

The soft and flexible silicone coating makes the cable pleasant to the touch and resistant to kinks. The **1 m length** ensures comfort of use both at home and on the go.

Universal USB cable

USB-C connectors make the cable compatible with a wide range of devices — smartphones, tablets, power banks and modern laptops from various brands. With this cable, you can charge phone models such as Samsung Galaxy, Xiaomi Poco and iPhone 16.