

C 091 B

Male cable connector,
bayonet locking inside




Cable diameter 4-6 mm



Cable diameter 6-8 mm



Cable diameter 4-6 mm

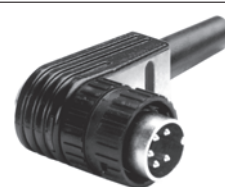

Right-angled

Description	Drawing	No. of cont.	Part Number solder termination		Part Number Crimp termination ¹⁾
			Contact plating silver	Contact plating gold ²⁾	
Male cable connector, for cable diameter 4-6 mm, termination: solder or crimp, contact plating: silver or gold, cable sleeve: black.		3 ³⁾	T 3274 501	T 3274 518	T 3274 551
		4 ³⁾	T 3324 501	T 3324 518	T 3324 551
		5	T 3374 501	T 3374 518	T 3374 551
		5 S ³⁾	T 3394 501	T 3394 518	T 3394 551
		6 ³⁾	T 3424 501	T 3424 518	T 3424 551
		7	T 3434 501	T 3434 518 ⁴⁾	T 3434 551
		7 ³⁾	T 3444 501	T 3444 518 ⁴⁾	T 3444 551 ⁴⁾
		8 ³⁾	T 3524 501	T 3524 518 ⁴⁾	T 3524 551
		12	T 3624 501	T 3624 518 ⁴⁾	-
		14	T 3644 501	T 3644 518	-
Male cable connector, for cable diameter 6-8 mm, termination: solder or crimp with clamping ring, contact plating: silver or gold.		3 ³⁾	T 3274 502	T 3274 528 ⁴⁾	T 3274 552
		4 ³⁾	T 3324 502	T 3324 528 ⁴⁾	T 3324 552
		5	T 3374 502	T 3374 528 ⁴⁾	T 3374 552
		5 S ³⁾	T 3394 502	T 3394 528 ⁴⁾	T 3394 552 ⁴⁾
		6 ³⁾	T 3424 502	T 3424 528 ⁴⁾	T 3424 552
		7	T 3434 502	T 3434 528 ⁴⁾	T 3434 552
		7 ³⁾	T 3444 502 ⁴⁾	T 3444 528 ⁴⁾	T 3444 552 ⁴⁾
		8 ³⁾	T 3524 502	T 3524 528	T 3524 552 ⁴⁾
		12	T 3624 502	T 3624 528 ⁴⁾	-
		14	T 3644 502	T 3644 528 ⁴⁾	-
Male cable connector, for cable diameter 4-6 mm, termination: solder or crimp, contact plating: silver or gold.		3 ³⁾	T 3274 504 ⁴⁾	T 3274 548 ⁴⁾	T 3274 554 ⁴⁾
		4 ³⁾	T 3324 504 ⁴⁾	T 3324 548 ⁴⁾	T 3324 554 ⁴⁾
		5	T 3374 504	T 3374 548 ⁴⁾	T 3374 554 ⁴⁾
		5 S ³⁾	T 3394 504 ⁴⁾	T 3394 548 ⁴⁾	T 3394 554 ⁴⁾
		6 ³⁾	T 3424 504 ⁴⁾	T 3424 548 ⁴⁾	T 3424 554 ⁴⁾
		7	T 3434 504 ⁴⁾	T 3434 548 ⁴⁾	T 3434 554 ⁴⁾
		7 ³⁾	T 3444 504 ⁴⁾	T 3444 548 ⁴⁾	T 3444 554 ⁴⁾
		8 ³⁾	T 3524 504 ⁴⁾	T 3524 548	T 3524 554 ⁴⁾
		12	T 3624 504 ⁴⁾	T 3624 548 ⁴⁾	-
		14	T 3644 504 ⁴⁾	T 3644 548 ⁴⁾	-
Male cable connector, right-angled, for cable diameter 4-6 mm, termination: solder or crimp, contact plating: silver or gold, cable sleeve: black.		3 ³⁾	T 3274 005	T 3274 058	T 3274 055 ⁴⁾
		4 ³⁾	T 3324 005	T 3324 058	T 3324 055 ⁴⁾
		5	T 3374 005	T 3374 058	T 3374 055
		5 S ³⁾	T 3394 005	T 3394 058 ⁴⁾	T 3394 055 ⁴⁾
		6 ³⁾	T 3424 005	T 3424 058 ⁴⁾	T 3424 055
		7	T 3434 005	T 3434 058 ⁴⁾	T 3434 055 ⁴⁾
		7 ³⁾	T 3444 005 ⁴⁾	T 3444 058 ⁴⁾	T 3444 055 ⁴⁾
		8 ³⁾		T 3524 058 ⁴⁾	T 3524 055 ⁴⁾
		12	T 3624 005	T 3624 058 ⁴⁾	-
		14	T 3644 005	T 3644 058 ⁴⁾	-

¹⁾ Please order crimp contacts separately, see page 43

²⁾ see remark page 20

³⁾ Contact order for DIN EN 60 130-9

⁴⁾ Available upon request.