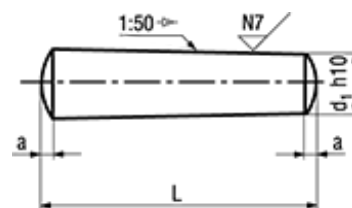


	ISO 2339 B	~DIN 1		
---	------------	--------	--	--

**BN 859****Taper pins**

unhardened, machined

Free-cutting steel

plain

- ~VSM 12770 B
- ~UNI 7283
- ~CSN 022153
- Tolerance: h10

Article#	d ₁	a~	L
1308203	2	0,25	10
1308262			20
1308319			30
1308343			40
1308378			50
1308599	3	0,4	12
1308602			14
1308610			16
1308637			20
1308653			25
1308696			30
1308726			35
1308734			40
1308742			45
1308750			50
1308858	4	0,5	16
1308874			20
1308890			25
1308920			30
1308947			35
1308955			40
1308963			45
1308971			50
1309005			60

Article#	d ₁	a~	L
1309013	4	0,5	70
1309021			80
1309099	5	0,63	16
1309110			20
1309137			25
1309161			30
1309196			35
1309218			40
1309226			45
1309234			50
1309250			60
1309269			70
1309277			80
1309293			100
1309307	6	0,8	16
1309315			20
1309331			25
1309374			30
1309390			35
1309404			40
1309412			45
1309420			50
1309447			60
1309455			70
1309463			80
1309471			90
1309498			100
1309501			120
1309544	8	1	25
1309579			30
1309595			35
1309609			40
1309617			45
1309625			50
1309633			55
1309641			60
1309668			70
1309676			80
1309684			90
1309692			100
1309714			120

Article#	d1	a~	L
1309803	10	1,2	60
1309811	10	1,2	70
1309838			80
1309846			90
1309854			100
1309870			120
1309935	12	1,6	60
1309943			70
1309951			80
1309978			90
1309986			100
1310003			120
1310046			160
1310070	16	2	60
1310089			70
1310097			80
1310100			90
1310119			100
1416618			120
1416626			140
1416634			160