


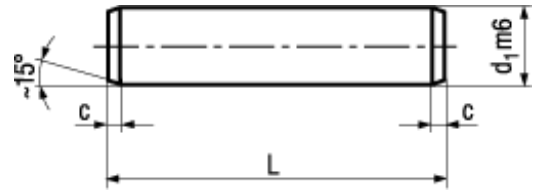

ISO 2338

**BN 31113****Parallel pins**

Stainless steel A4

- ~VSM 12771 B
- ~UNI 1707
- ~CSN 022150
- Tolerance: m6

Article#	d ₁	c~	L
5401805	1	0,2	5
5401806	1,5	0,3	5
5401807			6
5401808			8
5401811	2	0,35	5
5401812			6
5401813			8
5401814			10
5401815			12
5401816			14
5401817			16
5401818			18
5401819			20
5401820	2,5	0,4	10
5401821			20
5401822	3	0,5	5
5401823			6
5401824			8
5401825			10
5401826			12
5401827			16
5401828			20
5401829			30
5401830	4	0,63	6
5401831			8
5401832			10
5401833			12

Article#	d ₁	c~	L
5401834	4	0,63	14
5401835			16
5401836			20
5401837			30
5401838			32
5401839			40
5401840	5	0,8	10
5401841			12
5401842			16
5401843			20
5401844			30
5401845			40
5401846			50
5401847	6	1,2	10
5401848			16
5820780			20
5401849			28
5401850			32
5401851			40
5401852			50
5401853	8	1,6	20
3377863			25