



KEMET Part Number: FLLD3130AMHT6

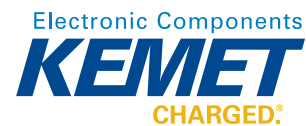

EMI Filters, Three Phase, FLLD3-MH, 530 VAC, 130 A, 240x90x150mm

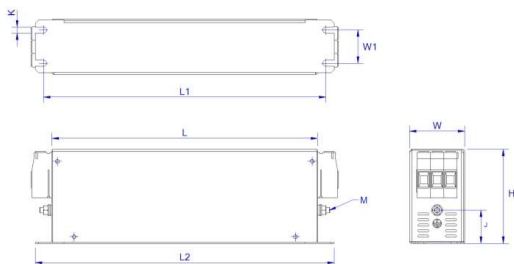

Dimensions

L	240mm NOM
W	90mm NOM
H	150mm NOM
L1	255mm NOM
L2	270mm NOM
W1	65mm NOM
J	64mm NOM
K	6.5mm NOM
M (Earth)	Threaded Studs M10

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	1
Weight:	4.5 kg

General Information

Style:	Chassis Mount
Series:	FLLD3-MH
Description:	EMI Filter, Chassis Mount, Motor Drives
Features:	High Performance
RoHS:	Yes

Specifications

Voltage AC:	530/305 VAC
Rated Frequency:	50-60 Hz
Current:	130 A (50C)
Rated Temperature:	50C
Temperature Range:	-25/+100C
Climate Category:	25/100/21
Test Voltage DC (P to P):	2250 VDC
Test Voltage DC (P to E):	3000 VDC
Power Loss:	40 W (25C 50 Hz)
Leakage Current:	4.7 mA

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.



© 2006 - 2017 IntelliData.net