


A detailed diagram of the front panel of the TMR-6000 digital scale. The panel features a large LCD display showing '0.0' in large digits and '0.0' in smaller digits below it. Above the display, there are two small rectangular windows. To the left of the display is a circular button with a power symbol, and to the right is a circular button with a checkmark. Below the display are four buttons: a circular button with a power symbol, a square button with a 'T' symbol, a circular button with a play symbol, and a square button with a checkmark. The panel is labeled 'TMR-6000' at the top right. Numbered callouts 1 through 15 point to various components: 1 points to the power button below the display; 2 points to the 'T' button below the display; 3 points to the play button below the display; 4 points to the checkmark button below the display; 5 points to the right side of the panel; 6 points to the right side of the panel; 7 points to the right side of the panel; 8 points to the top right corner; 9 points to the top right corner; 10 points to the top center; 11 points to the top left corner; 12 points to the top left corner; 13 points to the top left corner; 14 points to the top left corner; 15 points to the bottom left corner.

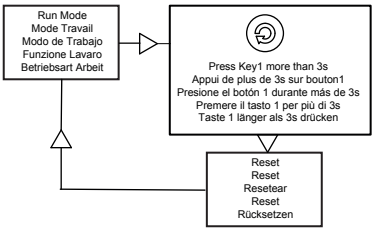


PROGRAMMING MODE / MODE DE PROGRAMMATION / MODO DE PROGRAMACION / MODO DI PROGRAMMAZIONE / PROGRAMMIERMODUS

Basic Prog Menu

Advanced Prog Menu

--	--

Dimensions and mounting

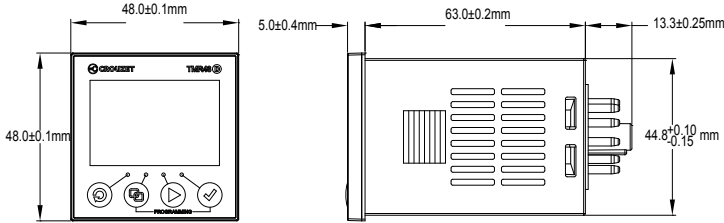

Wiring diagram / Schema de câblage / Diagrama de conexi3n / Schema di cablaggio / Schaltplan

