

DATA SHEET	53016610
SKINTOP® BS NPT	valid from : 26.02.2016

The SKINTOP® BS NPT with polyamide spiral strain relief, is particularly used for flexible cables a handheld equipment, moving machine parts and in many applications of the instrument industry.
The SKINTOP® BS NPT with spiral affords protection against conductor damage.



Components:

Gland body	Polyamide
Cap nut with integrated spiral	Polyamide
Sealing ring	CR

Technical features:

Connecting thread	NPT 3/8" up to NPT 3/4" acc. to ANSI/ASME B1.20.1-1983.
Functional thread	Multi-start trapezoidal thread
Protection class / NEMA Type Rating	IP68 - 5 bar, test acc. to EN 60529 NEMA Type 1 und Type 12
Strain relief	In accordance to DIN VDE 0619
Temperature range	-20 °C up to +80 °C
Colour	RAL 7001 silver-grey RAL 9005 black, UV-resistant

Approvals:




UL File Nr. E79903

Norm references:



For more information please see our current catalogue.

DATA SHEET	53016610
SKINTOP® BS NPT	valid from : 26.02.2016

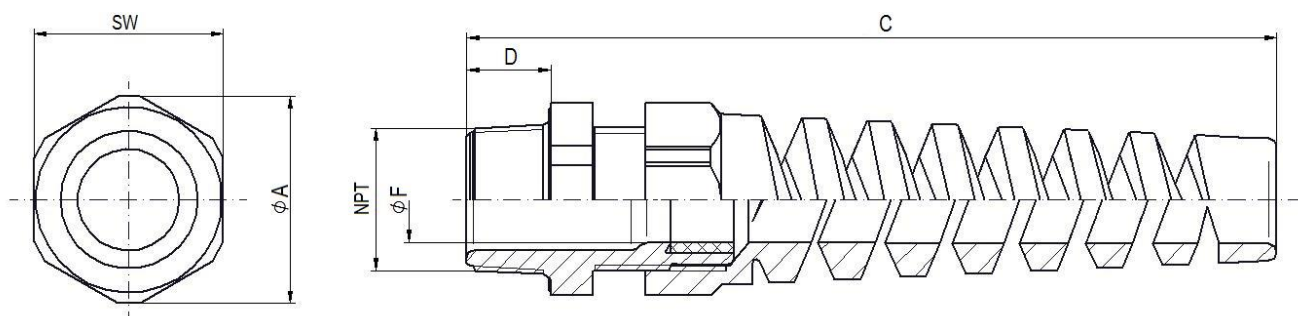

NPT	SW [mm]	Ø A [mm]	C [mm]		D [mm]	Ø F [mm] Clamping range	Article No.	
			min.	max.			RAL 7001	RAL 9005
NPT 3/8"	19	21,0	74,0	80,5	15	3,5–8	53016610	53016810
NPT 1/2"	24	26,5	96,5	104,0	15	5–12	53016630	53016830
NPT 3/4"	33	36,0	126,0	133,0	15	13–18	53016650	53016850