



DATA SHEET	55506305
SILVYN® FPAG-M	valid from : 25.04.2016

SILVYN® FPAG-M is a conduit gland with a fast fit for a safety assembling.
For the demounting we are recommending to use a screwdriver.
The gland is suitable for SILVYN® FPAS and can be used in the machine- and plant constructions.



Material:	PA 66
Features:	Fast assembly Anti-vibration Suitable for fine and coarse conduits High mechanical strength
Temperature range:	-50°C up to +135°C
Color:	Grey Black (UV-Resistant)

Norm Reference:



Note: Free of Halogen, Sulphur and Phosphorous

Protection class: IP 66

For more information please see our current catalogue.
Please do not hesitate to contact our laboratory if there any questions regarding
resistance against aggressive agents and special oil.


elaborated by: PDP: M. Wegerer	document: DB55506305_02EN	page 1 von 2
-----------------------------------	---------------------------	--------------

DATA SHEET

55506305

SILVYN® FPAG-M

valid from :
25.04.2016

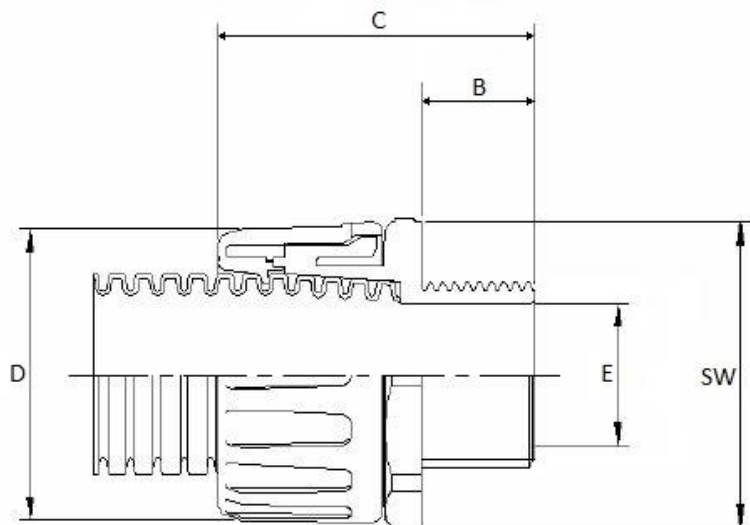

Dimension table:

Part No.	Part Name	NW	Length C mm	Thread Length B mm	Inner Ø E mm	Outer Ø D mm	SW
Grey							
5550 6300	SILVYN® FPAG M12x1,5 GY	10	33	9	7,5	19	19
5550 6310	SILVYN® FPAG M16x1,5/1 GY	13	37	11	11	24	23
5550 6320	SILVYN® FPAG M16x1,5/2 GY	16	41	11	11	29	28
5550 6330	SILVYN® FPAG M20x1,5/1 GY	16	44	14	14,5	29	28
5550 6340	SILVYN® FPAG M20x1,5/2 GY	18	44	14	14,5	32	30
5550 7050	SILVYN® FPAG M20x1,5/3 GY	21	44	14	14,5	32	30
5550 6350	SILVYN® FPAG M25x1,5 GY	28	49	15	19,5	44	42
5550 6360	SILVYN® FPAG M32x1,5 GY	34	53	16	26,5	51	49
5550 6370	SILVYN® FPAG M40x1,5 GY	42	60	16	32,5	63	60
5550 6380	SILVYN® FPAG M50x1,5/1 GY	42	60	16	40,5	63	60
5550 6390	SILVYN® FPAG M50x1,5/2 GY	54	65	16	42	76	73
5550 6400	SILVYN® FPAG M63x1,5/1 GY	54	65	16	53	76	73
5550 6470	SILVYN® FPAG M63x1,5/2 GY	67	70	16	56	90	87
Black							
5550 6305	SILVYN® FPAG M12x1,5 BK	10	33	9	7,5	19	19
5550 6315	SILVYN® FPAG M16x1,5/1 BK	13	37	11	11	24	23
5550 6325	SILVYN® FPAG M16x1,5/2 BK	16	41	11	11	29	28
5550 6335	SILVYN® FPAG M20x1,5/1 BK	16	44	14	14,5	29	28
5550 6345	SILVYN® FPAG M20x1,5/2 BK	18	44	14	14,5	32	30
5550 7055	SILVYN® FPAG M20x1,5/3 BK	21	44	14	14,5	32	30
5550 6355	SILVYN® FPAG M25x1,5 BK	28	49	15	19,5	44	42
5550 6365	SILVYN® FPAG M32x1,5 BK	34	53	16	26,5	51	49
5550 6375	SILVYN® FPAG M40x1,5 BK	42	60	16	32,5	63	60
5550 6385	SILVYN® FPAG M50x1,5/1 BK	42	60	16	40,5	63	60
5550 6395	SILVYN® FPAG M50x1,5/2 BK	54	65	16	42	76	73
5550 6405	SILVYN® FPAG M63x1,5/1 BK	54	65	16	53	76	73
5550 6475	SILVYN® FPAG M63x1,5/2 BK	67	70	16	56	90	87