

DATA SHEET	52003130
SILVYN® SCH	valid from: 10.01.2018

The SILVYN® SCH is a multirange hose clamp, with worm drive. The hose clamp is suitable for applications with higher mechanical stress.



Material

Body:	Stainless steel, blanc
Screw:	Steel, zinc plated
Band:	Stainless steel, blanc

Technical Features

Screw:	Worm drive with cross recess and width across flats 7
Clamping range:	10 up to 60 mm

Additional features

Corrosion resistance:	Yes
Belt tension force:	High
Breaking torque:	High

Approbation:



Norm Reference:

DIN 3017-1

Suitable glands:

SILVYN® SSV
SILVYN® SSV-M
SILVYN® SSVZ
SILVYN® SSVZ-M


Suitable conduit:

SILVYN® SI
SILVYN® SP
SILVYN® SP-PU

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Elaborated by: PDP: M. Wegerer	Document: DB52003130EN	Page 1 of 2
-----------------------------------	------------------------	-------------

DATA SHEET	52003130
SILVYN® SCH	valid from: 10.01.2018

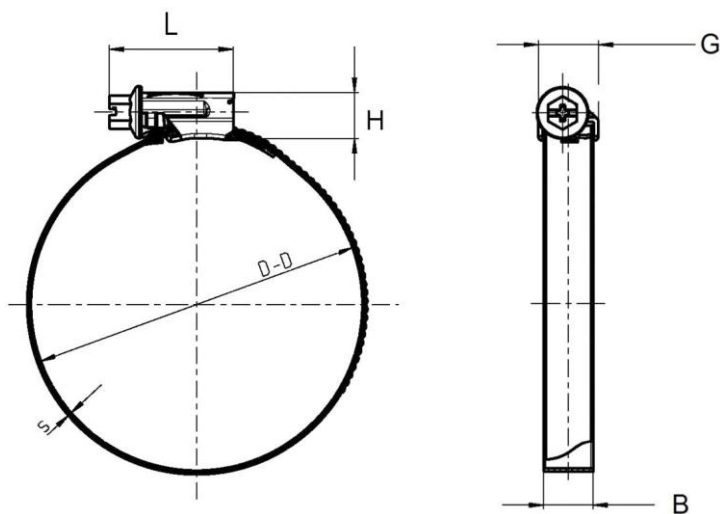

Dimension table:

Part No.	Clamping range D-D mm	Belt thickness S mm	Belt range B mm	Body length L mm	Body high H mm	Body width G mm
52003130	10 – 16	0,6	7,5	17	9	11,5
52003140	12 – 20	0,65	9	24	11	13
52003160	16 – 25	0,65	9	24	11	13
52003170	20 – 32	0,65	9	24	11	13
52009050	25 – 40	0,65	9	26	11	13
52009061	35 – 50	0,8	12	30	11	14,6
52009040	40 – 60	0,8	12	30	11	14,6