


SILVYN® BRAID PA6

SILVYN® BRAID PA6 is a braided sleeving to protect cables from abrasion

Info

Simple, fast cable bundling

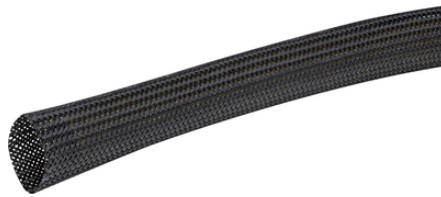

UV-resistant



Temperature-resistant



Reliability



Low weight



Wide clamping range

Benefits

Can be cut without the need for a thermo-cutting tool

Cut into length without frizzle on the conduit's end

Abrasion protection

Simple, fast cable bundling

Protection against dust

Application range

Easy cable protection

Additional insulation

Bundling and guiding of cables and wires

Low rodent-protection

Product features

Abrasion-resistant

Flexible

Can be cut at cold temperatures

Last Update (09.04.2018)

©2018 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SILVYN® BRAID PA6

Product Make-up

Polyamide 6.6 - halogen-free

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001182

ETIM 5.0 Class-Description: Braided hose

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001182

ETIM 6.0 Class-Description: Braided hose

On request:

Bulk containers on rolls

More sizes available

Note:

Halogen and cadmium-free

Fire behaviour according to UL94 V-2

Colour delivered:

Black (RAL 9005), UV-resistant

Material:

Polyamide 6.6 - halogen-free

Temperature range:

-55°C to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.



SILVYN® BRAID PA6

Article number	Nominal size	Clamping range in mm	Colour
SILVYN® BRAID PA6			
61721260	6	4 - 10	black
61721261	12	10 - 14	black
61721262	16	14 - 24	black
61721263	20	18 - 26	black
61721264	30	26 - 34	black
61721265	40	32.0 - 42.0	black

Last Update (09.04.2018)

©2018 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16