

Part number

MZOW 15 L25



Brief description:

hoods for single lever, size "49.16", side entry, M25, aggressive environments, IP66

Product description	
Version	W-TYPE version for aggressive environments
Series	hoods for single lever
Product type	with 2 pegs
Variant	side entry
Family	CLASS enclosures
Size	size "49.16"
Technical data	
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Cable entry	M25
Further technical details	
Weight	104,00 g

Approvals / Standards	
Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE
General ordering information	
EAN13 code	8015747115377
Tariff number	85369095
Packaging Information	
Packaging weight	1,04 kg
Packaging volume	0,01 dm³
Packaging description	Carton box
Packaging quantity	10 Pcs
Packaging EAN code	8015747171762
Sub-packaging length	120,00 mm
Sub-packaging height	105,00 mm
Sub-packaging width	160,00 mm
Sub-packaging weight	0,52 kg
Sub-packaging volume	2,02 dm³
Sub-packaging description	Plastic packaging
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747171779


Part number

MZOW 15 L25




Catalogue drawings


CZOW L MZOW L

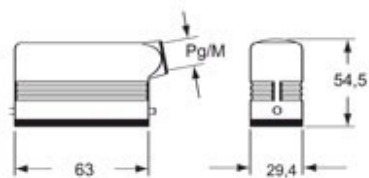

CZAOW L - MZAOW L CZAVW L - MZAVW L

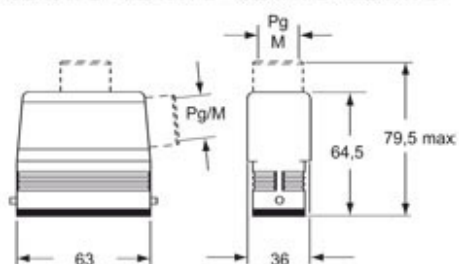

CZVW L MZVW L

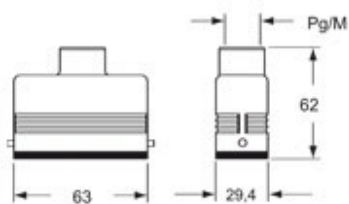

CZCW LG

