



TECHNICAL DOCUMENTATION/ DOKUMENTACJA TECHNICZNA

Customer	BTO			Version NO Wersja	Change date	Change Content	Change Reason	(introducer)
Product	Male and Female connector with two caps Męskie i żeńskie złącze z osłonami	P/N	BT180411	00	2018.04.23	according to 3D and 2D drawings.	Customer's request	Customer
Customer's Approval		Approval date Data zatwierdzenia		01	2018.06.14	According to customer requirements, add the new standards of ★ Nowe standardy, zgodne z wymaganiami klienta	Customer's request	Customer


Female connector
Złącze żeńskie

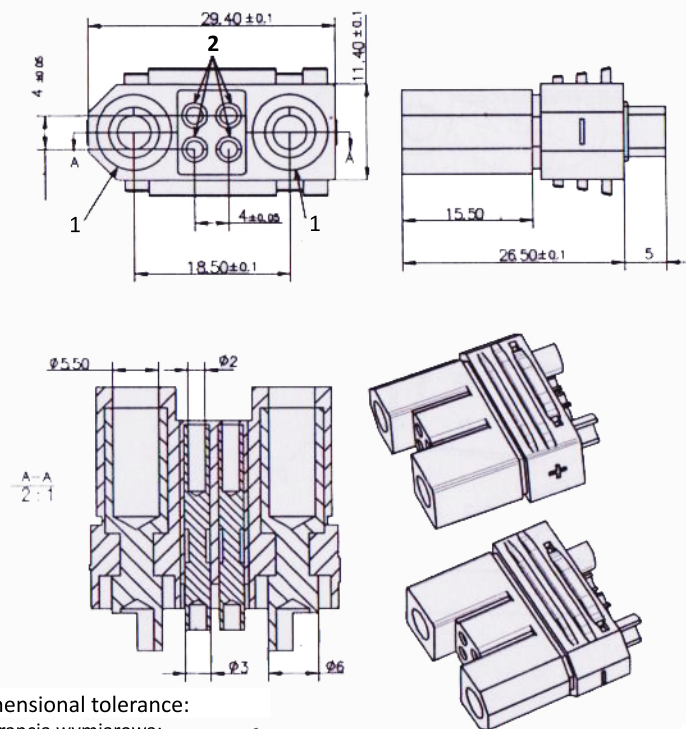

Male connector
Złącze męskie

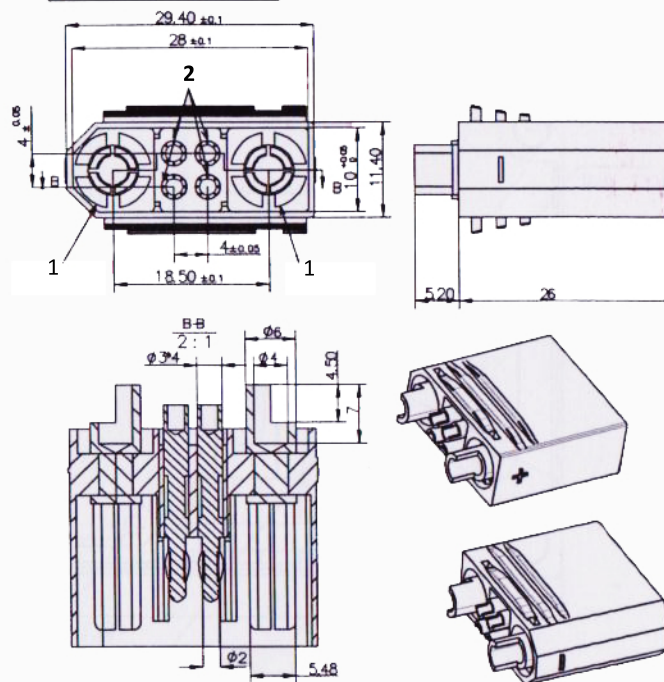

Caps
Osłony

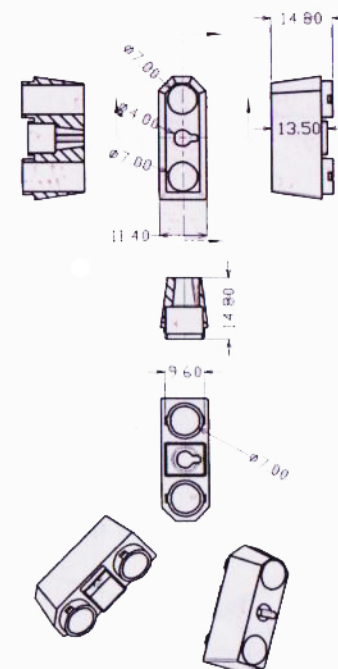

1. Dimensional tolerance:

Tolerancja wymiarowa:

x. x: ± 0.15
x. xx: ± 0.10
x. xxx: ± 0.05

2. Unlabeled angle

tolerance: ± 0.5
Nieoznaczona tolerancja
kątów: ± 0.5

★ Operating temperature: -10°C - 180°C ; Temperatura robocza: -10°C - 180°C

Recommended number of plug and pull usage: 1000 times

Zalecana liczba złączeń/rozłączeń: 1000 razy

Hardware 1: Rated current: 80A; Instantaneous current: 120A
Styk 1: Prąd maksymalny: 80A; Prąd chwilowy: 120A
Hardware 2: Rated current: 15A; Instantaneous current: 30A
Styk 2: Prąd maksymalny: 15A; Prąd chwilowy: 30A

SHENZHEN TECHNOLOGY Co., Ltd.

No	Product/Color	Produkt/Kolor	NUMBER	ENVIRONMENTAL MATERIAL	SUPPLIER	Drawing	Sales confirmation	Engineer check	General manager approval	Market department	View pos	Unit	Proportion
3	Caps/Yellow	Osłony/Żółty	2PCS	ROHS									
2	Male connector/Yellow	Złącze męskie/Żółty	1	ROHS									
1	Female connector /Yellow	Złącze żeńskie/Żółty	1	ROHS									
No	Product/Color	Produkt/Kolor	NUMBER	ENVIRONMENTAL MATERIAL	SUPPLIER	LJL	Charli		雷艳霞	Wu		mm	1:1