




Technical Datasheet

tasker® TSK1171 – 4x0,50 mm²

Flat Divisible LED Cable

FirestoP®

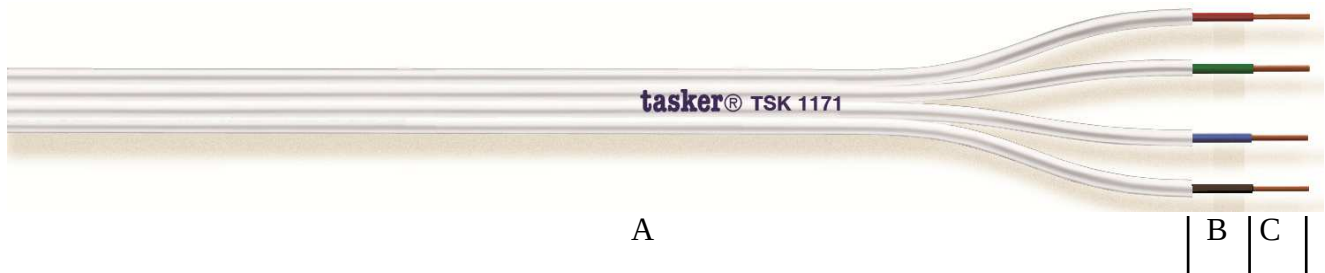

CATEGORY Flat Divisible LED Cable (See Electronics Catalogue)
APPLICATIONS Electronics and LED alimentation

- A:** White Soft **Flame Retardant PVC** – RAL 9010.
 Outer cable dimension: 2,60x10,30 (± 0,20) mm.
B: **Flame Retardant PVC** insulation on each conductor.
 Color Code: Red, Green, Blue, Black.
 Outer cable Diam. Ø 1,50 (±0,20) mm.
C: Stranded O.F.C. red copper wire formation 16x0.20 mm.
 Nom. Cross section 4x0,50 mm².

MARKING CUSTOM PRODUCTION

tasker® TSK1171 4x0,50 mm² O.F.C. Double Sheath Rgb-Led Strip Cable FirestoP®
 This product may be custom produced also in **L.S.Z.H.** polymer, **PE**, **PUR**.

Properties

Conductor Resistance	38,00 Ω/Km
Rating Voltage	49 V
Operative Temperature	-20/+70°C

USE	X	Indoor	Interno Edificio	INSTALLATION	X	Fixed	Fissa	INFORMATION	X	RoHS2 Compliant
Impiego		Outdoor Limited	Esterno Limitato	Posa	X	Restricted Mobile	Mobile Limitata	Informazioni	X	Ver. A / 15.02.18
		Outdoor	Esterno			Mobile	Mobile			
		Outdoor Direct Burial	Esterno Interrato			Mobile in Drag Chain	Mobile in Catena			10% measurement tolerance, unless otherwise indicated