




Price\* : 86.70 GBP

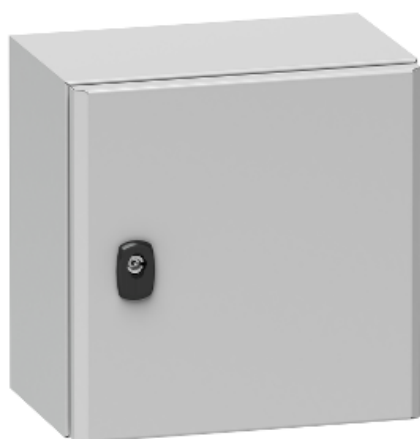

## Main

|                             |                                                                       |
|-----------------------------|-----------------------------------------------------------------------|
| Range                       | Spacial                                                               |
| Product name                | Spacial S3D                                                           |
| Application                 | Multi-purpose                                                         |
| Category                    | Compact enclosure                                                     |
| Enclosure nominal height    | 500 mm                                                                |
| Enclosure nominal width     | 300 mm                                                                |
| Enclosure nominal depth     | 200 mm                                                                |
| Door type                   | Plain                                                                 |
| Mounting plate description  | Plain                                                                 |
| Type of gland plate         | Standard                                                              |
| Installation accessory type | Wall-mounting                                                         |
| Device composition          | Body 1<br>Mounting plate 1<br>Door with lock 1<br>Cable gland plate 1 |

## Complementary

|                             |                                                                                   |
|-----------------------------|-----------------------------------------------------------------------------------|
| Body type                   | Single piece body<br>Gutter-shaped front rail double sheet thickness              |
| Number of doors             | 1 front face                                                                      |
| Door opening side           | Reversible 120 °                                                                  |
| Lock type                   | 3 mm double-bar lock                                                              |
| Accessibility for operation | Front                                                                             |
| Removable parts             | Door by hinges<br>Cable gland plate by screws<br>Mounting plate by fixing element |
| Material                    | Galvanised steel for mounting plate<br>Steel for enclosure                        |
| Surface finish              | Epoxy-polyester powder enclosure                                                  |

|                        |                                    |
|------------------------|------------------------------------|
| Colour                 | Grey RAL 7035 enclosure :          |
| Standards              | IEC 62208                          |
| Product certifications | UL<br>LR<br>DNV<br>BV<br>GL<br>CUL |
| Product weight         | 8.662 kg                           |

## Environment

|                         |                              |
|-------------------------|------------------------------|
| IP degree of protection | IP66 conforming to IEC 60529 |
| IK degree of protection | IK10 conforming to IEC 62262 |

## Offer Sustainability

|                                  |                                                                                                                                       |
|----------------------------------|---------------------------------------------------------------------------------------------------------------------------------------|
| Sustainable offer status         | Green Premium product                                                                                                                 |
| RoHS (date code: YYWW)           | Compliant - since 0810 - Schneider Electric declaration of conformity<br><a href="#">Schneider Electric declaration of conformity</a> |
| REACH                            | Reference not containing SVHC above the threshold<br><a href="#">Reference not containing SVHC above the threshold</a>                |
| Product environmental profile    | Available<br><a href="#">Product Environmental Profile</a>                                                                            |
| Product end of life instructions | Need no specific recycling operations                                                                                                 |

## Contractual warranty

|                 |                     |
|-----------------|---------------------|
| Warranty period | 18 months 18 months |
|-----------------|---------------------|