




Electric Components > Products > Circular Connectors > Circular Connectors Signal M 23 >
M 23 Signal Straight Connector, Female Thread > [Straight Connector, Female Thread, for cable 11-17 mm](#) 7.106.600.000

Straight Connector, Female Thread, for cable 11-17 mm 7.106.600.000

cable diameter	11 – 17 mm
Housing material	Copper-Zinc alloy, Die Cast
Operating-Temperature	-40 – 125 °C
Protection category	IP67 / IP69K plugged
Seals / O-Rings	Buna-N standard
Surface material	Nickel

Additional information

// [Assembly instruction Straight Connector](#)

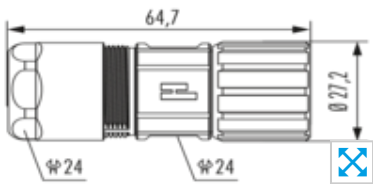

Certificates

