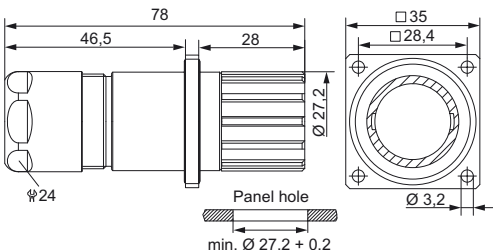
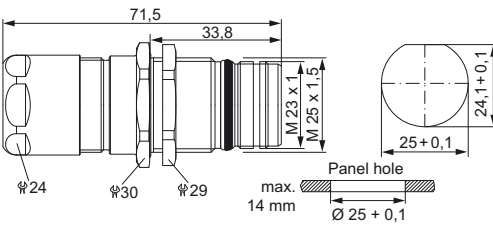
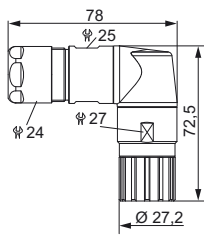
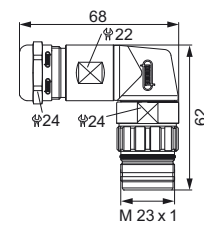


Power Connectors M 23 / Housing

Cable-Ø	Part Number	Panel Connector, Female Thread, with Strain Relief
4 holes Ø 3,2 mm (.13"), front or rear mounting 7 – 12 mm (.27 – .47").....7.681.500.000 11 – 17 mm (.43 – .67").....7.681.600.000		
		
Contacts and inserts page 113 • Assembly instructions page 121		

Cable-Ø	Part Number	Panel Connector, Male Thread, with Strain Relief
Single hole mounted, rear mounting, thread M 25 x 1,5 7 – 12 mm (.27 – .47").....7.653.500.000 11 – 17 mm (.43 – .67").....7.653.600.000		
Including jam nut M 25 x 1,5		
		
Contacts and inserts page 113 • Assembly instructions page 121		

Cable-Ø	Part Number	Right Angle Connector, Female Thread, rotating
7 – 12 mm (.27 – .47").....7.576.500.000 11 – 17 mm (.43 – .67").....7.576.600.000		
		
Contacts and inserts page 113 • Assembly instructions page 124		

Cable-Ø	Part Number	Right Angle Connector, Male Thread, rotating
7 – 12 mm (.27 – .47").....7.580.500.000 10 – 14 mm (.39 – .55").....7.580.600.000		
		
Contacts and inserts page 113 • Assembly instructions page 124		