

Cable ties with identification tag

Special ties with steel locking barb

36

Characteristics

- Identification ties with incorporated label for durable marking and tying
- Label forms onto the bundle
- 5 different versions, up to 4 straps, in bulk and small packaging
- 4 versions (up to 3 straps) are Mil-specified
- Trouble free installation
- Labelling of bundles up to 102 mm diameter
- All edges are rounded and surfaces smoothed to make installation easier

Technical Information

Material - Moulding	Polyamide 6.6
Material - Locking barb	316 grade stainless steel
Temperature range	-40°C to +85°C
Colour	Natural
Approvals	MIL: MS-3368 -1, -2, -3, -4
Flammability rating	UL 94 V-2
Other properties	Halogen free, Silicone free



Product Ref.	MIL Spec.	Length L [mm]	Width W [mm]	Thick-ness [mm]	Bundle ø from ... to [mm]	Min. tensile strenght [N]	Label dimensions [mm]	Quantity [pieces]	Tooling
TY48M	MS-3368-2	360	4.8	1.1	19 - 102	220	13.1 x 57.2	1000	
TY548M	MS-3368-2	360	4.8	1.1	19 - 102	220	13.1 x 57.2	100	
TY46M	MS-3368-1	184	4.8	1.1	9.5 - 45	220	13.1 x 27.0	1000	ERG50
TY546M	MS-3368-1	184	4.8	1.1	9.5 - 45	220	13.1 x 27.0	100	ERG120
TY46MD	MS-3368-3	184	4.8	1.1	9.5 - 45	220 x 2	29.7 x 27.0	500	WT193A
TY546MD	MS-3368-3	184	4.8	1.1	9.5 - 45	220 x 2	29.7 x 27.0	50	
TY46MT	MS-3368-4	184	4.8	1.1	9.5 - 45	220 x 3	46.0 x 27.0	500	
TY546MT	MS-3368-4	184	4.8	1.1	9.5 - 45	220 x 3	46.0 x 27.0	100	
TY46MF	-	184	4.8	1.1	9.5 - 45	220 x 4	63.1 x 27.0	250	
TY546MF	-	184	4.8	1.1	9.5 - 45	220 x 4	63.1 x 27.0	50	

 
For other materials and colours contact your Sales Office

Description of product reference structure: see page 8


Description of materials and properties: see pages 140 to 151

For tooling specifications: see pages 126 to 139


TY46MT, TY546MT




696-41563

 


696-41563

 

696-41563

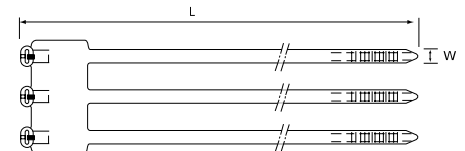

696-41563

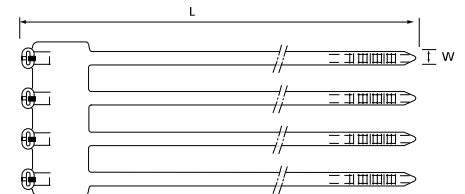

E49405