


Features:


- Integrally molded polarization
- Material: UL 94V-2
- Friction lock
- Standard color: Nature
- Recommended panel thickness: .030" ~ .090"(0.762 ~ 2.286mm)

Specifications:

- Current rating: 13A
- Voltage rating: 600V
- Insulation resistance: 1000M Ω Min.
- Dielectric withstanding voltage: 5000V AC/minute
- Ambient temperature range: -55°C ~ 105°C

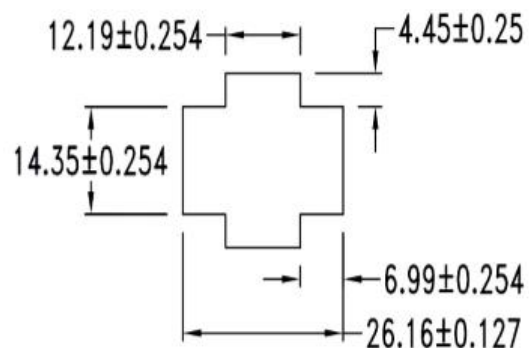

&& Panel must be punched so that housing enters panel in same direction as the punch.

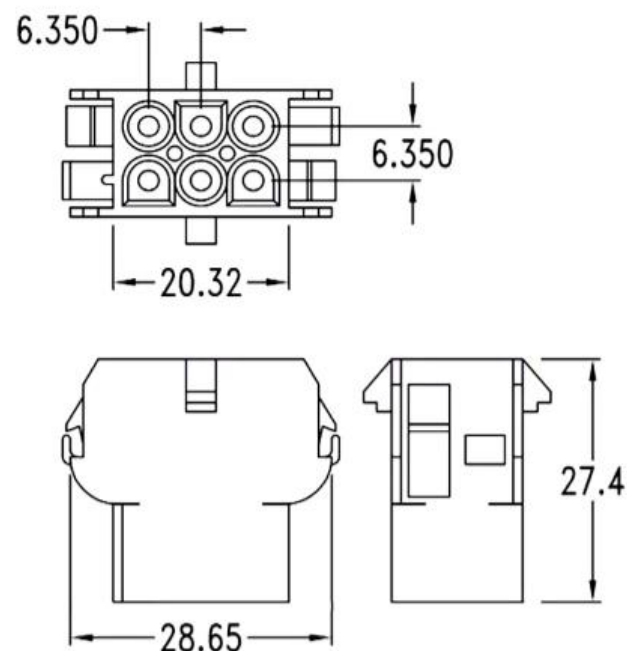

RoHS
Compliant

NINIGI

APPRO.
核准
DWG.
製圖
DATE
2014/8/20

SCALE
比例
UNIT
單位
PAGE
張數
1 OF 1

TOLERANCE
容許公差
PART NAME 品名
6.35mm FEMALE HOUSING 2X3P
NYLON66 WHITE INSULATOR ROHS
PART NO.
料號
NLSG-2X3