

REVISION RECORD			
REV	ECN	DESCRIPTION	DATE

Technical characteristics:

Specifications

DIN EN 60 664
DIN EN 61 984





Inserts

01. Number of contacts :12+PE
02. Rated Current :10A
03. Rated Voltage :400V
04. Pollution degree :3
05. Rated impulse voltage :6kv¹⁰
06. Insulation resistance :≥10¹⁰Ω
07. Material:Polycarbonate
08. Limiting temperatures : -40℃~+125℃
09. Flammability acc. to UL94:V0
10. Mechanical working life (mating cycles) : ≥500

Contacts

01. Material:Copper alloy
02. Surface:hard-Silver plated
 :hard-Gold plated
03. Contact resistance : ≤3mΩ
04. Terminal :Crimp terminal
05. Wire gauge :0.14-2.5mm² (AWG 26-14)
06. Stripping length :6-8mm
07. Rohs Compliance

Note:Crimp contact pins should
order separately

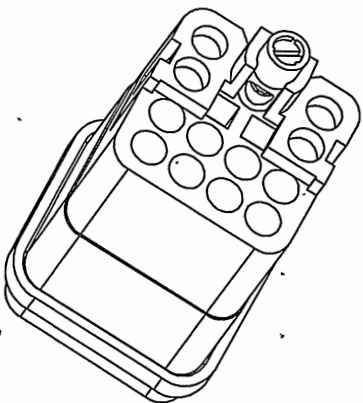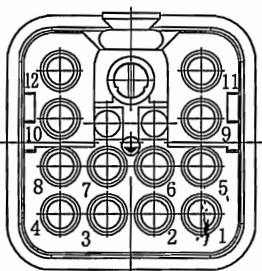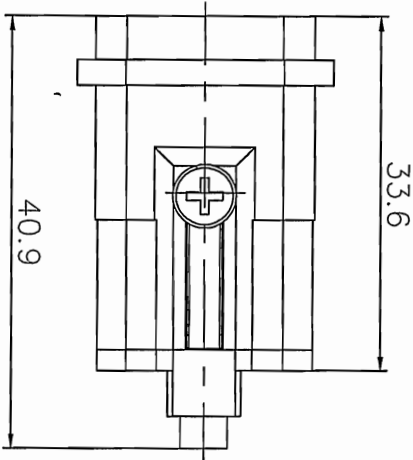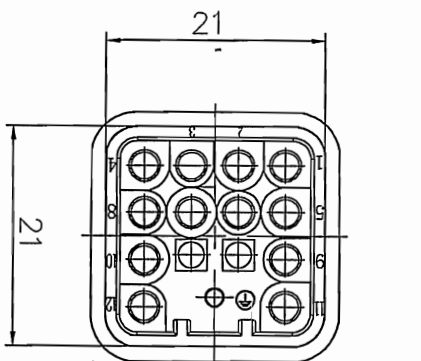

DETACHED LISTS

PART NO.:	/	NAME:	DEGSON® NINGBO DEGSON ELECTRICAL CO., LTD
APPR:	MSS 2016-10-24	DRAWING NO.:	DO-012-MC
CHKD:	LJM 2016.10.18	REV	DO-1
DFT:	Mr. Yang 2016.09.25	SHEET	1/1
THIRD ANGLE PROJECTION		DO NOT SCALE DRAWING	SCALE 1.5:1