
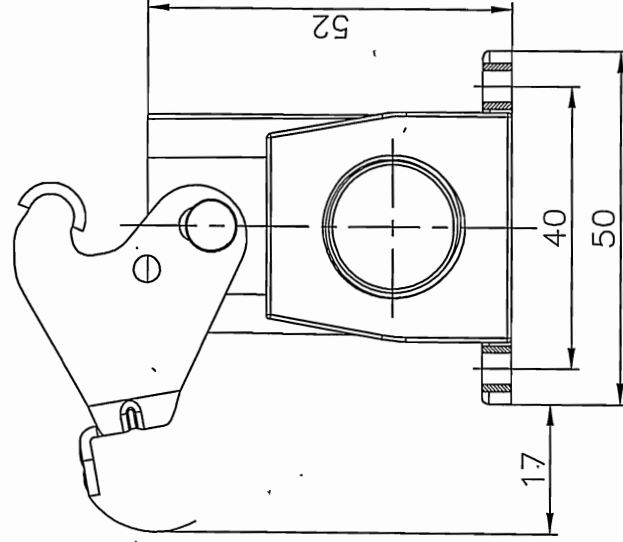
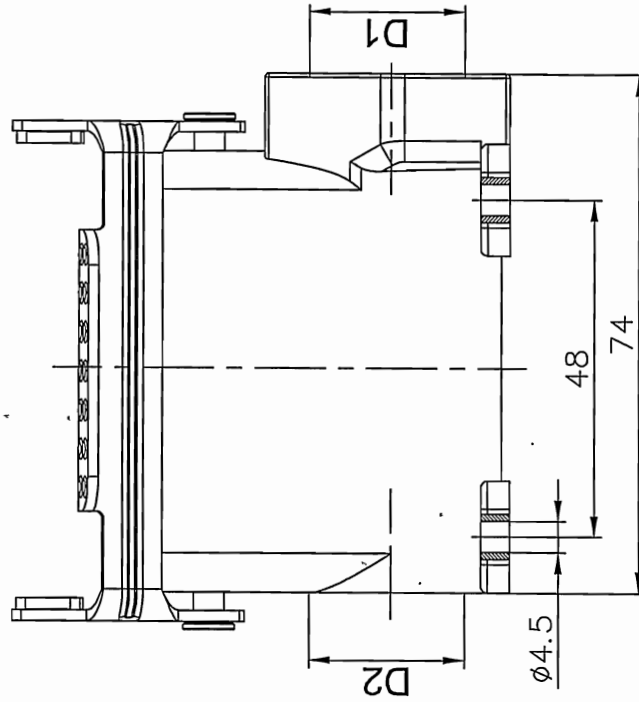


TYPE	Thread		Selection
	D1	D2	
D10A-SF-1L-M20	M20	—	
D10A-SF-1L-2M20	M20	M20	
D10A-SF-1L-M25	M25	—	
D10A-SF-1L-PG16	PG16	—	
D10A-SF-1L-2PG16	PG16	PG16	
D10A-SF-1L-PG21	PG21	—	

TYPE	Thread		Selection
	D1	D2	
D10A-SF-1L-M20	M20	—	
D10A-SF-1L-2M20	M20	M20	
D10A-SF-1L-M25	M25	—	
D10A-SF-1L-PG16	PG16	—	
D10A-SF-1L-2PG16	PG16	PG16	
D10A-SF-1L-PG21	PG21	—	

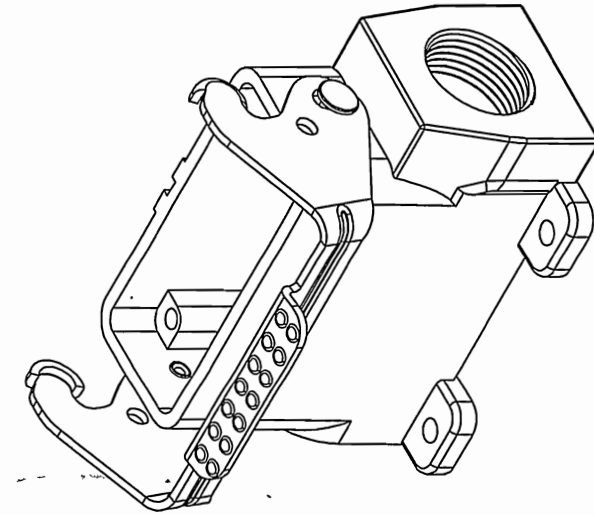

Housings Feature

01. Material: Aluminium die-cast
02. Surface: Powder-coated
03. Color: grey (RAL 7037)
04. Material: Metal zinc-plated (Lever)
05. Limiting temperatures: -40 °C ~ +125 °C
06. Flammability acc to UL94: V0
07. Degree of protection acc. to EN60529 for coupled connector: IP65
08. Rohs Compliance

REVISION RECORD

REV	ECN	DESCRIPTION	DRFT	DATE
-----	-----	-------------	------	------

PART NO.:	NINGBO DEGSON ELECTRICAL CO., LTD
APPROD:	NAME: D10A-SF-1L-M/PG
CHKD:	TITLE: CUSTOMER DRAWING
DRFT: Mr. yang	REV DO-1
2016.08.15	1/1
2016.9.1	SCALE 1:1
THIRD ANGLE PROJECTION	DO NOT SCALE DRAWING