


D16A-TEH-2g-M25	M25
D16A-TEH-2g-PG16	PG16
D16A-TEH-2g-PG21	PG21

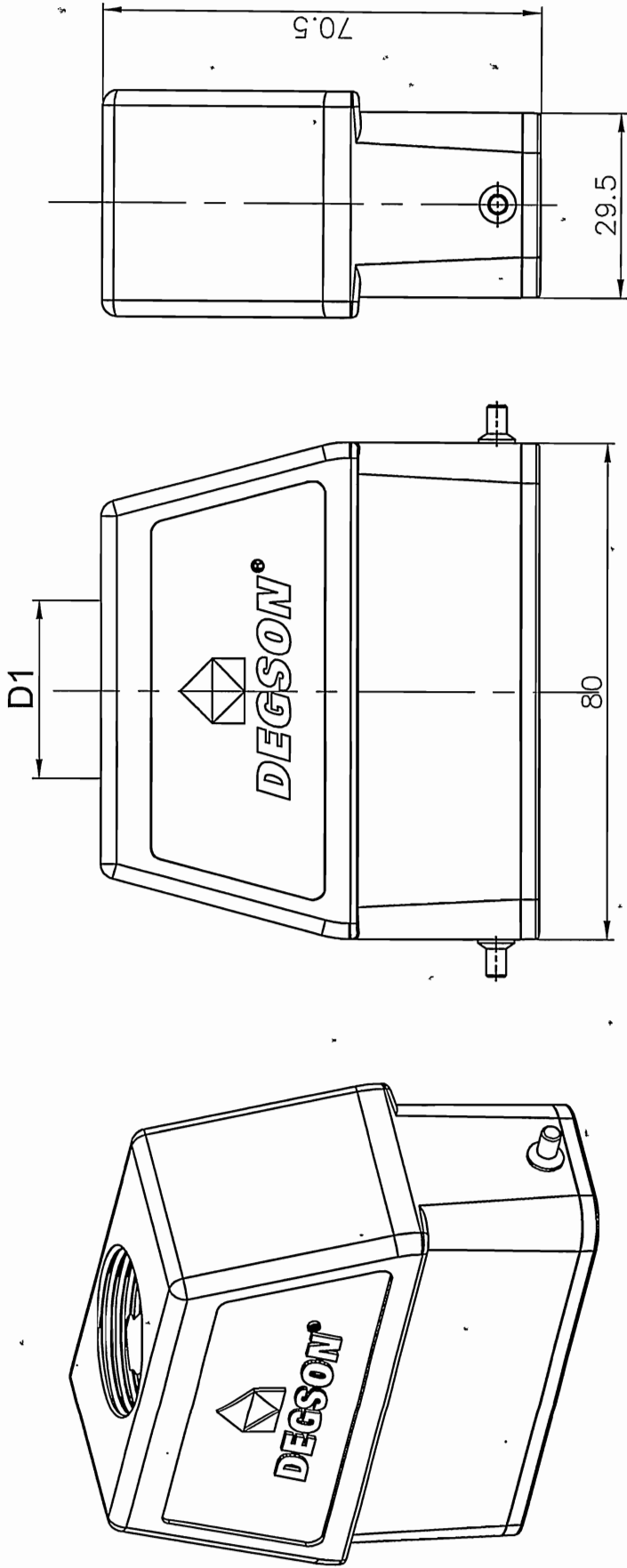

- Hoods Feature
- 01. Material: Aluminium die-cast
 - 02. Surface: Powder-coated
 - 03. Color: grey (RAL 7037)
 - 04. Limiting temperatures: -40 °C ~ +125 °C
 - 05. Sealing: NBR
 - 06. Flammability acc to UL94: V0
 - 07. Degree of protection acc. to EN60529 for coupled connector: IP65
 - 08. Rohs Compliance

PART NO.:	NINGBO DEGSON ELECTRICAL CO., LTD
APPD: HYS 2016.9.8	NAME: D16A-TEH-2g-M/PG
CHKD: CHK 2016.9.1	TITLE: CUSTOMER DRAWING
DRFT: Mr. yang 2016.08.15	REV DO-1
THIRD ANGLE PROJECTION	DRAWING NO. SHEET 1/1
	DO NOT SCALE DRAWING SCALE 1:1