


TYPE	Thread		Selection
	D1	D2	
D16A-SF-1L-CV-M20	M20	—	
D16A-SF-1L-CV-2M20	M20	M20	
D16A-SF-1L-CV-M25	M25	—	
D16A-SF-1L-CV-2M25	M25	M25	
D16A-SF-1L-CV-PG16	PG16	—	
D16A-SF-1L-CV-2PG16	PG16	PG16	
D16A-SF-1L-CV-PG21	PG21	—	

Thread

Selection

Housings Feature

01. Material:Aluminium die-cast
02. Surface:Powder-coated
03. Color:grey (RAL 7037)
04. Covers:Plastic
05. Material:Metal (Lever)
06. Limiting temperatures: -40℃~+125℃
07. Flammability acc to UL94:V0
08. Degree of protection acc.to
EN60529 for coupled connector:IP65
09. Rohs Compliance

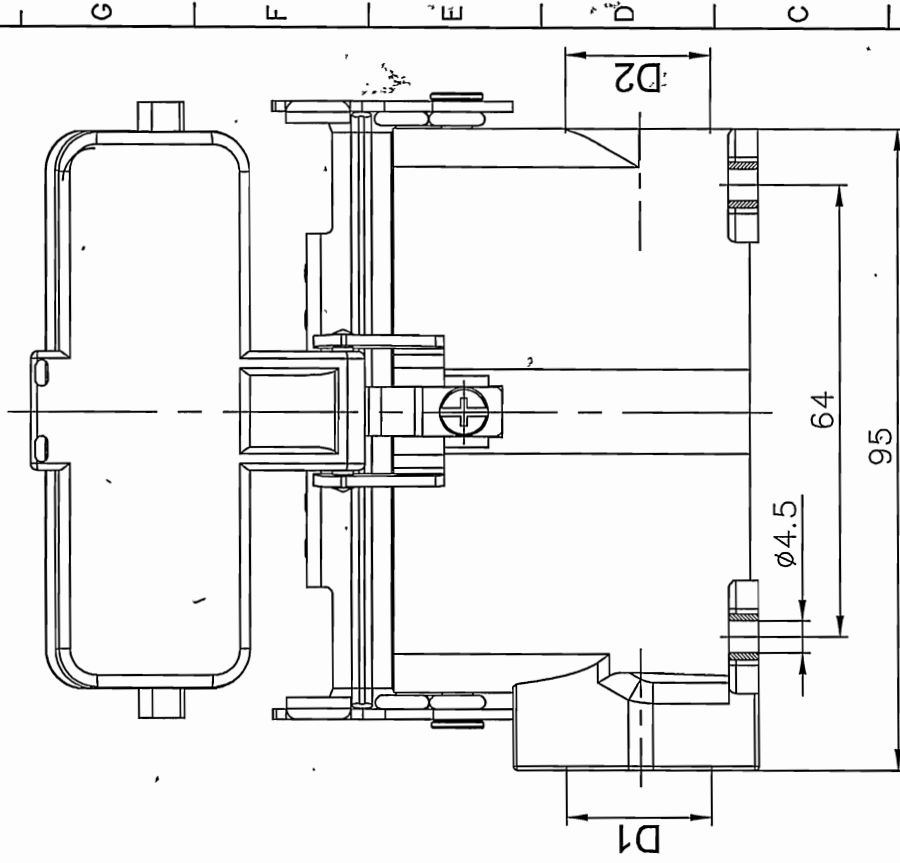

REVISION RECORD

REV	ECN	DESCRIPTION	DRFT	DATE
-----	-----	-------------	------	------

PART NO.:

APPD: HJS 2016.8.5

CHKD: CLK 2016.8.1

DRFT: Mr. Yang 2016.08.15



NINGBO DEGSON ELECTRICAL CO., LTD

NAME:

D16A-SF-1L-CV-MPG

TITLE: CUSTOMER DRAWING

REV DO-1

DRAWING NO.:

SHEET 1/1

DO NOT SCALE DRAWING

SCALE 1:1

THIRD ANGLE PROJECTION

