

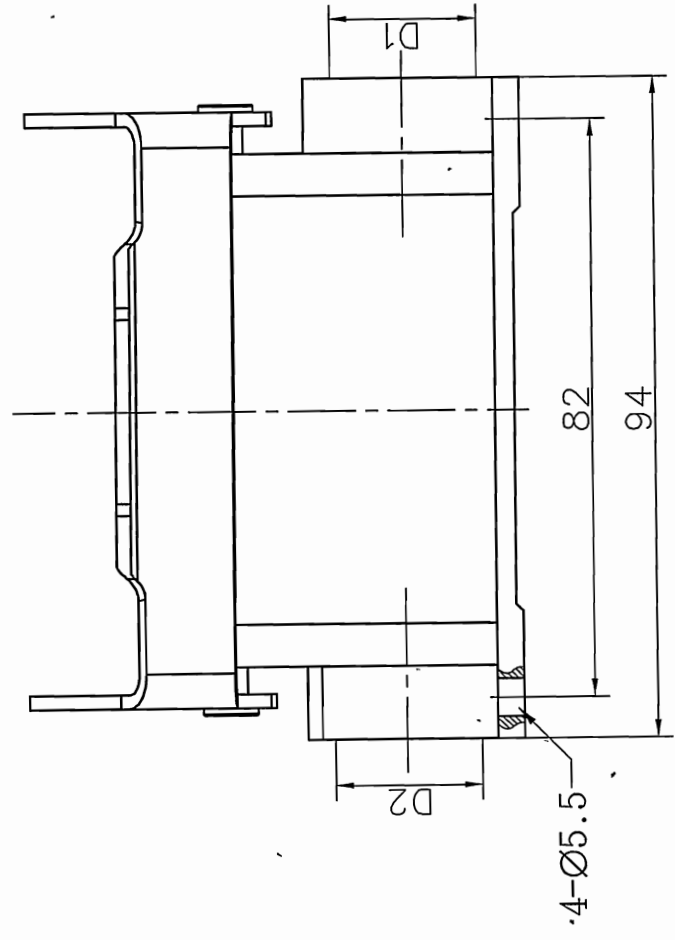


TYPE	Thread		Selection
	D1	D2	
D10B-SF-1L-M20	M20	—	
D10B-SF-1L-2M20	M20	M20	
D10B-SF-1L-M25	M25	—	
D10B-SF-1L-2M25	M25	M25	
D10B-SF-1L-PG16	PG16	—	
D10B-SF-1L-2PG16	PG16	PG16	

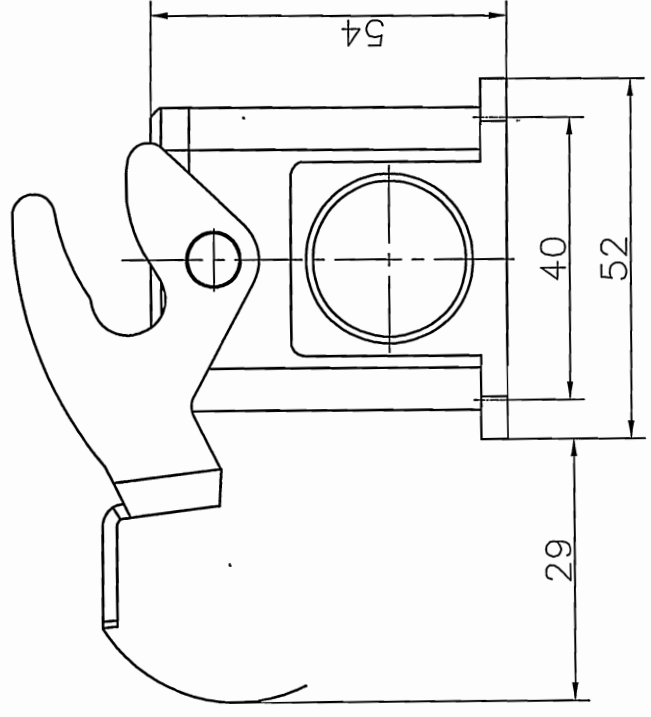

- Housings Feature
- 01. Material: aluminium die-cast
 - 02. Surface: Powder-coated
 - 03. Color: grey (RAL 7037)
 - 04. Material: Metal (Lever)
 - 05. Sealing: NBR
 - 06. Limiting temperatures: -40°C ~ +125°C
 - 07. Flammability acc to UL94: V0
 - 08. Degree of protection acc. to EN60529 for coupled connector: IP65
 - 09. Rohs compliance

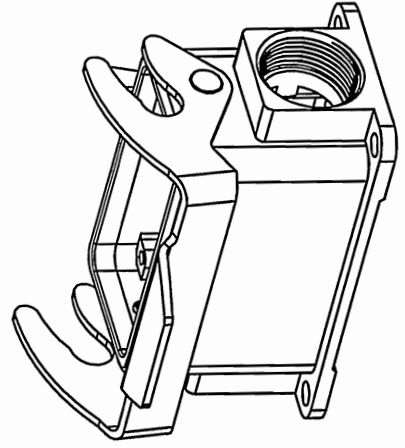

REVISION RECORD			
REV	ECN	DESCRIPTION	DATE

PART NO.: /	NINGBO DEGSON ELECTRICAL CO., LTD	
	NAME: D10B-SF-1L-M/PG	
	APPD: HYS 2017.7.1	REV: D0-1
	CHKD: CHK 2017.7.1	SHEET: 1/1
DRFT: Mr. yang 2017/06/28		DO NOT SCALE
DRAWING NO.: 111		SCALE: 1:1
THIRD ANGLE PROJECTION		