
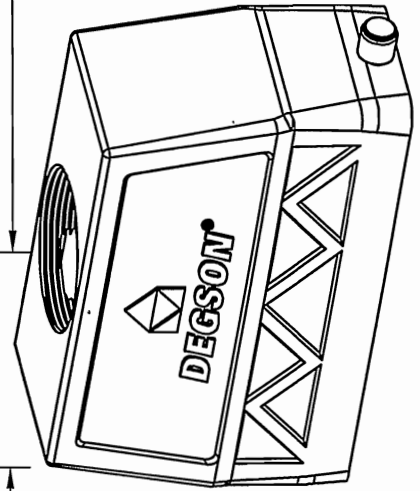
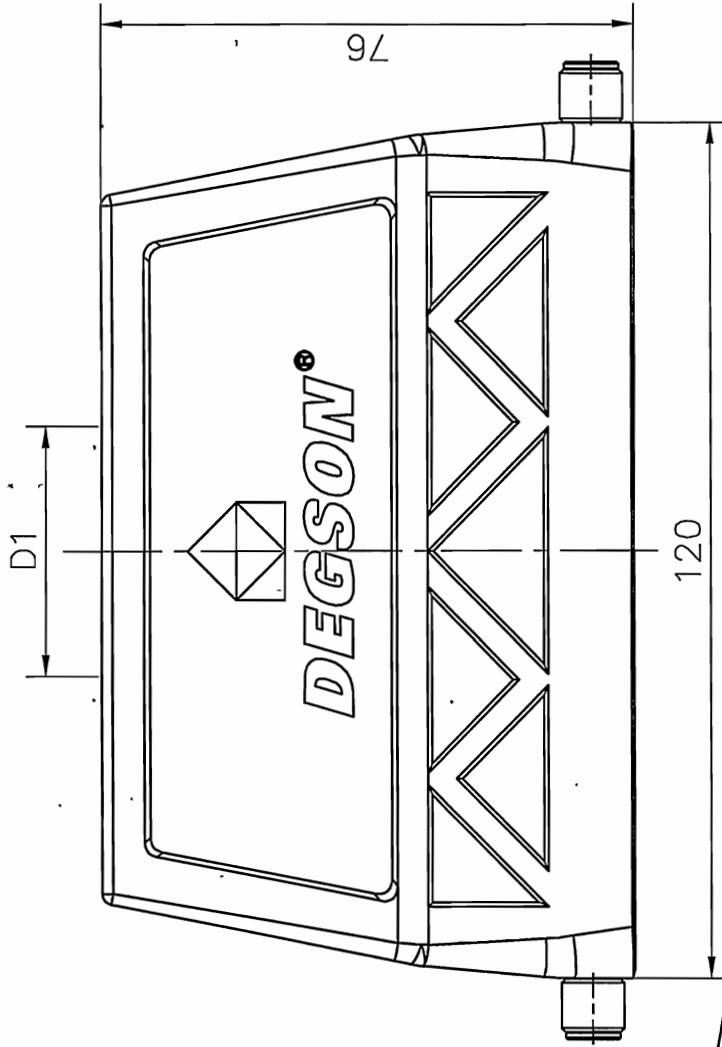


TYPE

Thread(D1) Selection

D24B-TEH-2g-M32	M32
D24B-TEH-2g-M40	M40
D24B-TEH-2g-PG21	PG21
D24B-TEH-2g-PG29	PG29

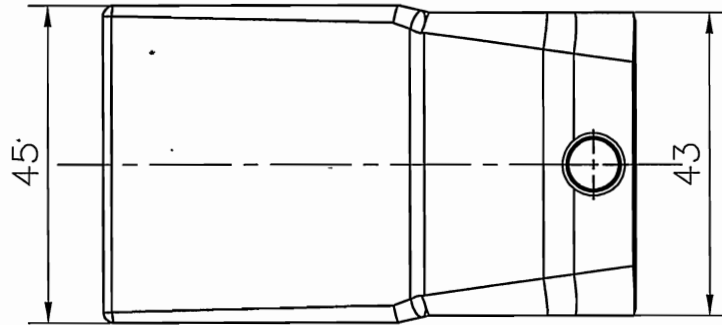

Hoods Feature

- 1.Material: aluminium die-cast
- 2.Surface: Powder-coated
- 3.Color: grey(RAL 7037)
- 4.Limiting temperatures: $-40^{\circ}\text{C} \sim +125^{\circ}\text{C}$
- 5.Flammability acc to UL94:V0
- 6.Degree of protection acc.to EN60529 for coupled connector :IP65
- 7.Rohs compliance

REVISION RECORD

REV	ECN	DESCRIPTION	DRFT	DATE

PART NO.: /	NINGBO DEGSON ELECTRICAL CO., LTD
APPD: HJS 2017.7.6	NAME: D24B-TEH-2g-M/PG
CHKD: CJK 2017.7.1	TITLE: CUSTOMER DRAWING
DRFT: Mr.yang	REV DO-1
2017/06/28	SHEET 1/1
DRAWING NO.: 2017/06/28	SCALE 1:1
THIRD ANGLE PROJECTION	DO NOT SCALE