

Technical data sheet

Cable and pipe spacer clip 732 with threaded connection

Art.-Nr. 1360264




St	Steel
GTP	Electrogalvanised, transparently passivated

Mounting with screw-in spacer clips. Spacer clips and screw-in spacer clips are available in various materials: in V2A stainless steel, in electrogalvanised, hot-dip galvanised steel or in aluminium. Fastening can take place with bolt ties or angler anchors and Sprint screws. Depending on the design, the clips can be "shot" using a bolt-firing tool or nail device.

Master data

Item No.	1360264
Type	732 26 GTP
Description 1	Distance saddle
Description 2	with threaded connection M6
Dimension	24-26mm
Material	Steel
Material symbol	St
Surface finish	Electrogalvanised, transparently passivated
Interface symbol	GTP
Smallest sales unit	50,00 pcs
Weight	1,92 kg/100 pcs.

Technical specifications

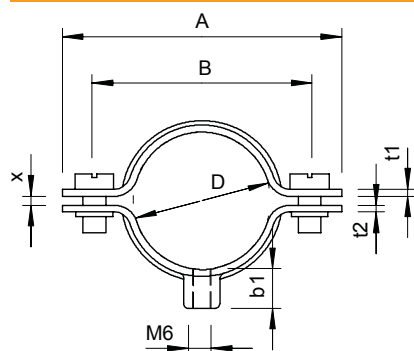

Length	52,00 mm
Dimension A	52,00 mm
Dimension B	40,00 mm
Dimension b1	8,50 mm
Dimension t1	1,00 mm
Dimension t2	1,25 mm
Dimension x	2,00 mm
Distance to the wall	☒
Number of cables/pipes	1,00
Version	Closed
Fastening type	Threaded connection
For diameter	24,00 - 26,00 mm
Suitable in fire protection area	☒
Size	M25
Halogen-free	☒
Plastic coated	☒
Hole size	M6 mm
Material thickness	1,00 mm
Bolt	M5 x 12
Clamping range D	24,00 - 26,00 mm
UV-resistant	☒