

Technical data sheet

Cable and pipe spacer clip 733

Art.-Nr. 1361198



* Size M16 is not suitable for nail device

* Sizes M16 - PG16 are not suitable for bolt-firing tool




St	Steel
G	Electrogalvanised

Master data

Item No.	1361198
Type	733 19 G
Description 1	Distance saddle
Description 2	with slot
Dimension	17-19mm
Material	Steel
Material symbol	St
Surface finish	Electrogalvanised
Interface to DIN	DIN EN 12329
Interface symbol	G
Smallest sales unit	50,00 pcs
Weight	2,50 kg/100 pcs.

Technical specifications

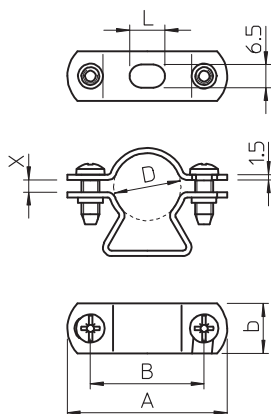

Length	45,00 mm
Dimension A	45,00 mm
Dimension B	32,00 mm
Dimension b	14,00 mm
Dimension D	19,00 mm
Dimension L	10,00 mm
Dimension x	10,25 mm
Distance to the wall	☒
Number of cables/pipes	1,00
Version	Closed
Fastening type	Screw hole
For diameter	19 mm
Suitable in fire protection area	☒
Size	Pg11
Halogen-free	☒
Plastic coated	☒
Hole size	6,5 x 10 mm
	6,5 x 10 mm
Material thickness	1,50 mm
Bolt	M5 x 14


Technical data sheet

Cable and pipe spacer clip 733

Art.-Nr. 1361198



Technical specifications

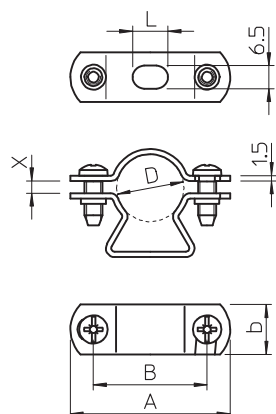

Clamping range D	17,00 - 19,00 mm
UV-resistant	☒